



RKP Series Enhanced Version LCD Console Drawers

- 17" and 19" LCD Enhanced Console Drawer
- Enhanced aesthetics with molded front panel and two point locking system
- Optional Integrated KVM

Further enhancing the design boundaries for cost efficient 1U rack mount LCD keyboard drawer solutions Austin Hughes provides enhanced 17" and 19" LCD keyboard drawer with optional integrated KVM switch.

17" and 19" TFT Colour LCD 1280x1024 display pixels.

The enhanced **RKP series** offers its users increased functionality with a full keyboard and numerical pad with centralised mouse and either touchpad or trackball as standard, new enhanced aesthetics with molded front panel and two point locking system, one-man installation slides.

Full range of integrated KVM solutions up to 32 ports of Matrix CAT6 KVM.

Options:

- AV / DVI-D / HDMI / Audio
- DC power: 12V/24V/48V/125V/250V



Full range of integrated KVM solutions:

- Matrix Cat6 KVM
- Combo Cat6 KVM
- Matrix DB-15 KVM
- Combo DB-15 KVM
- DVI-D KVM
- USB Hub DB-15 KVM



[Check out the CyberView KVM video](#)



Part Code Builder - RKP Series

Example Configuration: RKP119 Series with 8 Port Combo, Single User KVM, Touchpad and UK Layout Keyboard = RKP119-S801e-EU

Series		KVM Type		Mouse Options		Keyboard Layout Languages	
RKP117	17" Enhanced Single Console Drawer	No KVM	Single VGA Input	e	Touchpad	_EU	UK
RKP119	19" Enhanced Single Console Drawer	-801	8 Port PS2 Only	b	Trackball	_DE	German
		-S801	8 Port Combo, Single User			_ES	Spanish
		-S1601	16 Port Combo, Single User			_FR	French
		-802	8 Port combo, 2 User			_IT	Italian
		-1602	16 Port Combo, 2 User			_NL	Dutch
		-IP802	8 Port Combo, 2 User, 1 IP			_NO	Norwegian
		-IP1602	16 Port Combo, 2 User, 1 IP			_PT	Portuguese
		-M802	8 Port Combo, Matrix 2 User			_RU	Russian
		-M803	8 Port Combo, Matrix 3 User			_CH	Swiss
		-M804	8 Port Combo, Matrix 4 User			_US	USA
		-M1602	16 Port Combo, Matrix 2 User			_AR	Arabic
		-M1603	16 Port Combo, Matrix 3 User			_TR	Turkish
		-M1604	16 Port Combo, Matrix 4 User				
		-MIP813	8 Port Combo, Matrix 3 User, 1 IP				
		-MIP824	8 Port Combo, Matrix 4 User, 2 IP				
		-MIP1613	16 Port Combo, Matrix 3 User, 1 IP				
		-MIP1624	16 Port Combo, Matrix 4 User, 2 IP				
		-801H	USB HUB 8 Port KVM				
		-1601H	USB HUB 16 Port KVM				
		-802H	USB HUB 8 Port KVM, 2 Users				
		-1602H	USB HUB 16 Port KVM, 2 Users				
		-IP802H	USB HUB 8 Port KVM, 2 Users, 1IP				
		-IP1602H	USB HUB 16 Port KVM, 2 Users, 1IP				




Screen Specification	RKP117	RKP119
Size	17" TFT	19" TFT
Max. Resolution	1280 x 1024	1280 x 1024
Brightness (cd/m ²)	300	210
Backlight	CCFL	LED
Colours	16.7M	16.7M
Contrast Ratio (typ)	1000 : 1	1000 : 1
Viewing Angle H/V	160 x 160	170 x 160
Active Area (mm)	338 x 270	376 x 301
MTBF (hrs)	50,000	30,000




[Request a Quotation](#)

Keyboard and Mouse Layout

e keyboard integrated with touchpad

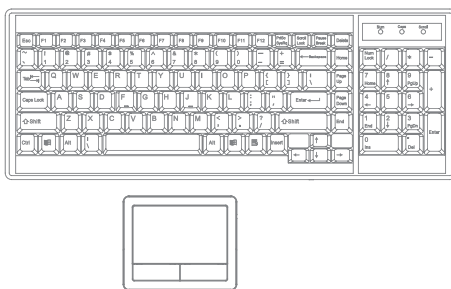

b keyboard integrated with trackball

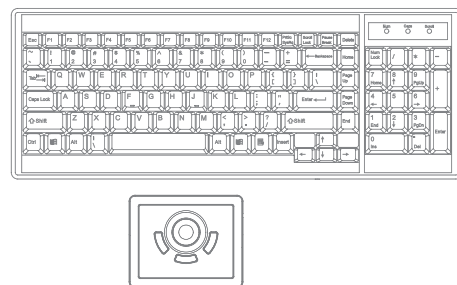

America

EMEA



American



English



German



French



Spanish



Norwegian



Italian



Russian



Swiss



Dutch



Portuguese



Turkish



Arabic

Design. Manufacturing. Global Services