



Date: July 12, 2017
Memo To: Axis Distribution Partners
From: Axis Communications
Subject: **Axis Communications announces the new AXIS Q8641-E and AXIS Q8642-E Thermal Network Cameras!**

Axis Communications is pleased to announce the launch of the new AXIS Q8641-E and AXIS Q8642-E Thermal Network Cameras!

Purpose of the products

Beyond detection with Axis thermal camera detection. Responsive AXIS Q8641-E and AXIS Q8642-E PT Thermal Network Cameras set the pace for unobstructed and far-reaching thermal detection of expansive outdoor areas. Easy and sturdy installation - The positioning cameras integrate an SFP slot, so they support cost-effective and long-distance fiber-optics connection. Both models can withstand high winds over 60-meter per second (135 mph) when they're in motion and without sunshield and withstands high winds when it's in motion of up to 47-meter per second (106 mph). The thermal imaging allows for a long-distance detection. Thanks to a 360 degree pan and a 135 degree tilt, the cameras allow to cover a wide area.

Pricing and Availability

The AXIS Q8641-E and AXIS Q8642-E are orderable now and expected to start shipping in connection with its external launch beginning of September.

Part No	Product Name	MSRP	EAN Code
01119-001	AXIS Q8641-E 35MM 30FPS 24V	\$5,799	7331021060777
01120-001	AXIS Q8641-E 35MM 8.3FPS 24V	\$5,799	7331021060784
01121-001	AXIS Q8642-E 60MM 30FPS 24V	\$9,499	7331021060791
01122-001	AXIS Q8642-E 60MM 8.3FPS 24V	\$9,499	7331021060807

Product Descriptions

AXIS Q8641-E Thermal Network Camera - Unobstructed views and long-distance detection

AXIS Q8641-E PT Thermal Network Camera offers outstanding thermal contrast and 10° field of view, which together with analytics, enables long-range detection and immediate visual confirmation for the operator. Highly responsive and reliable positioning camera, designed for continuous and jerk-free pan and tilt movements (360° endless and 135° from ground to sky). When column-mounted, it enables 360° unobstructed field of view, covering a wide area and reducing the cost for additional cameras. AXIS Q8641-E provides 384x288 thermal resolution, Zipstream and electronic image stabilization. Features both RJ45 and SFP interfaces, enabling a long-distance fiber connection with a failover network link.

AXIS Q8642-E Thermal Network Camera - Unobstructed views and long-distance VGA detection

AXIS Q8642-E PT Thermal Network Camera offers outstanding thermal contrast and 10° field of view, which together with analytics, enables long-range detection and immediate visual confirmation for the operator. Highly responsive and reliable positioning camera, designed for continuous and jerk-free pan and tilt movements (360° endless and 135° from ground to sky). When column-mounted, it enables 360° unobstructed field of view, covering a wide area and reducing the cost for additional cameras. AXIS Q8642-E provides 640x480 thermal resolution, Zipstream and electronic image stabilization. Features both RJ45 and SFP interfaces, enabling a long-distance fiber connection with a failover network link.

Key Features

- Reliable thermal detection
- Outstanding thermal contrast
 - AXIS Q8641-E – 384x288 resolution
 - AXIS Q8642-E – 640x480 resolution
- Responsive positioning with quick, smooth pan and tilt capabilities
- Save bandwidth with Zipstream
- Electronic image stabilization

Pricelist Text

AXIS Q8641-E 35MM 30FPS 24V Thermal Network Camera

High accuracy outdoor PT positioning thermal camera. 384x288 resolution, 30 fps and 35 mm lens with 10.5° angle of view. It supports Electronic Image Stabilization, Zipstream, ONVIF, H.264 and local storage. It includes Video motion detection, shock detection and support for AXIS Camera Application Platform enabling installation of AXIS Perimeter Defender and third-party applications. Responsive absolute positioning with high-speed and ultra-smooth pan and tilt capabilities. Integrated SFP slot for long-distance fiber connection. IP66, NEMA 4X rated and UL listed. Ready for column-mount. Powered by 24 V AC/DC. This product is subject to export control regulations. You should always consult and comply with the regulations of the appropriate local export control authorities.

AXIS Q8642-E 60MM 30FPS 24V Thermal Network Camera


High accuracy outdoor PT positioning thermal camera. 640x480 resolution, 30 fps and 60 mm lens with 10° angle of view. It supports Electronic Image Stabilization, Zipstream, ONVIF, H.264 and local storage. It includes Video motion detection, shock detection and support for AXIS Camera Application Platform enabling installation of AXIS Perimeter Defender and third-party applications. Responsive absolute positioning with high-speed and ultra-smooth pan and tilt capabilities. Integrated SFP slot for long-distance fiber connection. IP66, NEMA 4X rated and UL listed. Ready for column-mount. Powered by 24 V AC/DC. This product is subject to export control regulations. You should always consult and comply with the regulations of the appropriate local export control authorities.



AXIS Q8641-E



AXIS Q8642-E

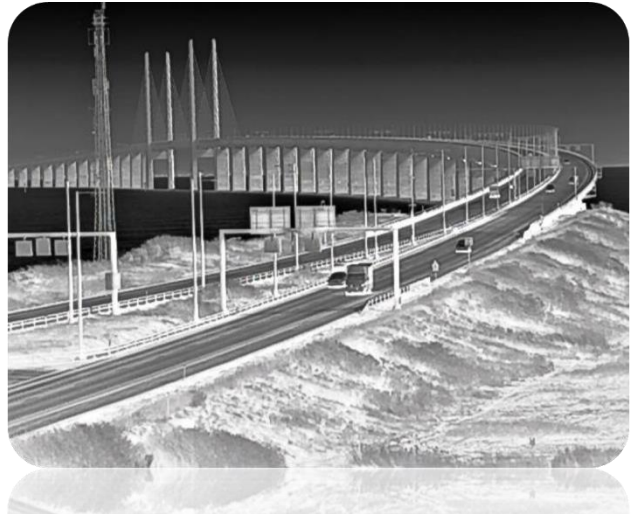

Warranty

The AXIS Q8641-E and AXIS Q8642-E Thermal Network cameras are covered by a 2-year warranty. For AXIS Extended Warranty option, see www.axis.com/warranty

Warranty	Part #	MSRP
AXIS Q8641-E 35MM 30FPS 24V – 2-year extended warranty	01119-600	\$469
AXIS Q8642-E 60MM 30FPS 24V – 2-year extended warranty	01121-600	\$759

Please feel free to contact your Axis Distribution Manager or Account Executive with any questions.