

RCI 910TC Touchless Switch

dormakaba 



910TC



910TC-HC

Features

- Available in two designs
- Unique low-profile touchless actuator plate utilizing capacitive technology for the activation of automatic doors.
- Aesthetically pleasing design.
- Hands-free – helps reduce the spread of germs and bacteria.
- Adjustable detection zone to reduce unwanted activations.
- When the device is activated, the indicator light (waving hand) will change color.
- Secondary Normally Open (NO) mechanical switch in the event of a power loss.
- Selectable unlock times (1-63 seconds).
- Mounts on single-gang electrical box.
- Available remote control to trigger switch remotely.
- FCC compliant.
- ISED compliant.
- May be purchased as a kit (910TC-WRM-WRB). Includes 910TC Switch, 910TC-WRM Remote Receiver Module and 910TC-WRB Remote Transmitter.
- Meets ADA compliance to ANSI/BHMA A156.19. (Always check local building codes for compliance in your area)

 Energy 12-24VDC 50/25mA	 Range 1" to 2" (30mm - 50mm)	 Warranty 2 Year Limited Warranty
 Switch Mode Momentary	 Switch Configuration SPDT	



Accessories

- 910TC-WRM - 433MHz Remote Receiver Module
- 910TC-WRB - 433MHz Remote Transmitter




910TC-WRM
433MHz Remote
Receiver Module



910TC-WRB
433MHz Remote
Transmitter

Dimensions

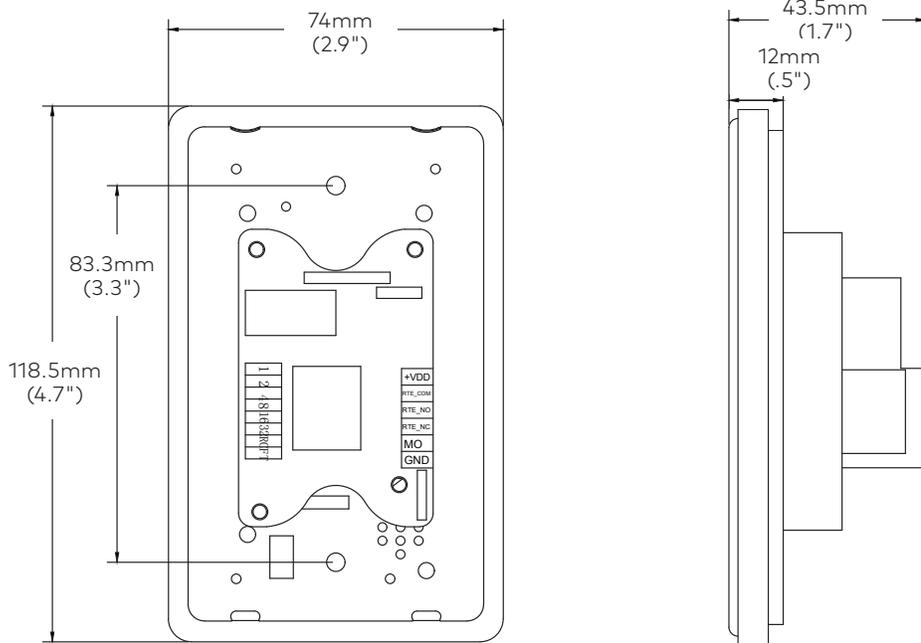

Specifications

Technology Type	Capacitive sensing
Detection Mode	Proximity
Detection Zone	Maximum detection zone of up to 2" (50mm)
Current	50mA (typical)/ 115mA (activated)
Voltage	12-24VDC
Temperature Range	-4° F to 140° F (-20°C to +60°C)
Relay	Form C SPDT 24VDC @ 100mA
Certification & Listings	FCC compliant ISED compliant ADA compliant

© dormakaba 2020 Information on this sheet is intended for general use only. dormakaba reserves the right to alter designs and specifications without notice or obligation.

dormakaba USA Inc.
6161 E. 75th St.
Indianapolis, IN 46250
800.523.8483

dormakaba Canada Inc.
65 Struck Court
Cambridge, ON N1R 8L2
800.387.4938