


# XTL™ Labels

## Laminated Wire/Cable Wrap Sheet Labels

- Pre-sized wire/cable wraps with laminated overwrap protect printed areas from oil, chemicals, moisture, abrasion and fading
- Laminated wire/cable wraps protect text against smearing
- In sheet label formats for high-volume installations
- Get the job done fast – print up to five sheets at one time\*
- Simply take them with you, peel and apply
- RoHS Compliant

\*Results may vary based on printer

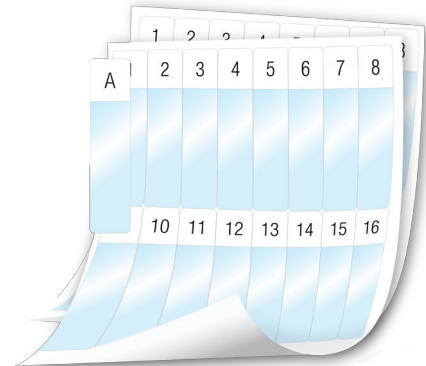

### Quick Specs

Label Widths	1", 1 1/2", 2"
Tape Platform	XTL
Printer Compatibility	Laser Printer
Printing System	Thermal Transfer
Temperature Rating	-40°F to 140°F
UL Recognized	Component to UL 969
Country of Origin	Belgium
Material	Polyester

Item Number	Width (in)	Length (in)	List Price (ea)	Labels/ Pack	ECCN Number		Length (in)	Width (in)	Height (in)	Weight (lbs)	QTY	Ti	Hi	UPC
1908552	1"	7/8"	\$119.99	2592	EAR99	Unit	12.80	10.04	0.28	0.57	1	-	-	071701002730
						Shelf	10.75	13.15	1.18	2	3	-	-	30071701002731
						Case	13.35	10.43	10.43	17.06	24	-	-	50071701002735
						Pallet	48.03	40.16	48.15	805.92	44	11	4	-
1908553	1"	1 5/8"	\$179.99	2544	EAR99	Unit	12.80	10.04	0.39	1.04	1	-	-	071701002747
						Shelf	10.75	13.15	1.18	2.35	2	-	-	30071701002748
						Case	13.35	10.43	10.43	19.89	16	-	-	50071701002742
						Pallet	48.03	40.16	48.15	930.09	44	11	4	-
1908554	1"	4"	\$179.99	1008	EAR99	Unit	12.80	10.04	0.51	1.54	1	-	-	071701002754
						Shelf	10.75	13.15	1.18	3.36	2	-	-	30071701002755
						Case	13.35	10.43	10.43	28	16	-	-	50071701002759
						Pallet	48.03	40.16	48.15	1287.06	44	11	4	-

DISTRIBUTED BY:  
DYMO, ATLANTA, GA 30328  
800-426-7827: WWW.DYMO.COM

INTERNAL USE ONLY. NOT FOR DISTRIBUTION.



A *NewellRubbermaid* Brand

# XTL™ Labels



Item Number	Width (in)	Length (in)	List	Total count	ECCN Number		Length (in)	Width (in)	Height (in)	Weight (lbs)	QTY	Ti	Hi	UPC
1908555	1 ½"	¾"	\$229.99	2040	EAR99	<b>Unit</b>	12.80	10.04	0.35	0.88	1	-	-	071701002761
						<b>Shelf</b>	10.75	13.15	1.18	2.04	2	-	-	30071701002762
						<b>Case</b>	13.35	10.43	10.43	17.42	16	-	-	50071701002766
						<b>Pallet</b>	48.03	40.16	48.15	821.44	44	11	4	-
1908556	1 ½"	1 ⅝"	\$179.99	1020	EAR99	<b>Unit</b>	12.80	10.04	0.30	0.66	1	-	-	071701002778
						<b>Shelf</b>	10.75	13.15	1.18	2.26	3	-	-	30071701002779
						<b>Case</b>	13.35	10.43	10.43	19.18	24	-	-	50071701002773
						<b>Pallet</b>	48.03	40.16	48.15	899.05	44	11	4	-
1908557	2"	¾"	\$139.99	1008	EAR99	<b>Unit</b>	12.80	10.04	0.28	0.60	1	-	-	071701002785
						<b>Shelf</b>	10.75	13.15	1.18	2.06	3	-	-	30071701002786
						<b>Case</b>	13.35	10.43	10.43	17.59	24	-	-	50071701002780
						<b>Pallet</b>	48.03	40.16	48.15	829.20	44	11	4	-
1908558	2"	1 ⅝"	\$229.99	1008	EAR99	<b>Unit</b>	12.80	10.04	0.43	1.10	1	-	-	071701002792
						<b>Shelf</b>	10.75	13.15	1.18	2.48	2	-	-	30071701002793
						<b>Case</b>	13.35	10.43	10.43	20.94	16	-	-	50071701002797
						<b>Pallet</b>	48.03	40.16	48.15	976.65	44	11	4	-

**DISTRIBUTED BY:**  
 DYMO, ATLANTA, GA 30328  
 800-426-7827: WWW.DYMO.COM

INTERNAL USE ONLY. NOT FOR DISTRIBUTION.

This information is being provided for general information purposes and the compliance standards and certifications referenced herein are based on current standards which are subject to change.

150836



A *NewellRubbermaid* Brand

©2015 SANFORD, L.P.