




# exacqVision virtual

## Virtual VMS Software

### Powerful Surveillance VMS Software for Virtual Machine Environments

#### Key Features & Benefits:

- **Reliable Virtual Server**— Allows you to leverage VMware® high availability to provide minimal system downtime in the event of a server failure. VMware® automatically shifts the exacqVision virtual appliance to an operating server. exacqVision virtual is supported on systems with exacqVision Enterprise licenses.
- **Pre-Configured for Easy Deployment** — Install the exacqVision Enterprise software on a VMware® host server in a matter of minutes. exacqVision Virtual is pre-configured by Exacq and certified by VMware® for interoperability and stability.
- **VMWare® Compatible** — Supported on VMware® hosts with Vcenter and ESX 4 and greater.
- **Access to Technical Support** — The Exacq technical support team is available to assist you during the installation and answer any questions throughout use of exacqVision Virtual.
- **One-Year Software Subscription Agreement (SSA)** — Receive quarterly software updates for all the latest advancements as they are released.

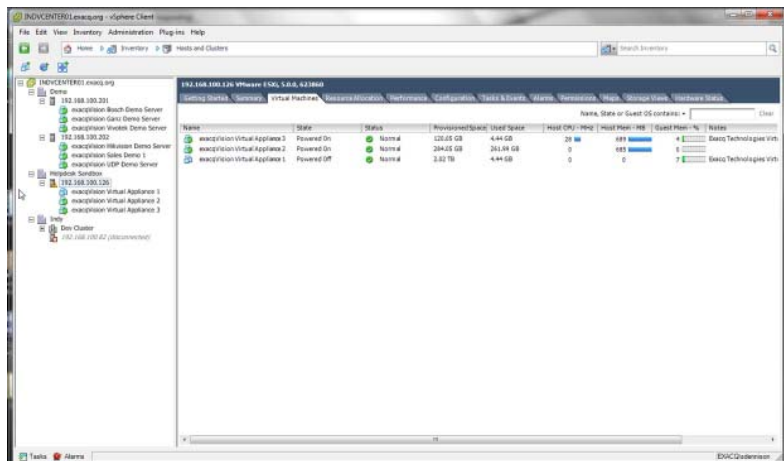

## Minimum Provisions

Supported on VMware vSphere 4 or 5 ESX Hypervisor

2 virtual cores with a reservation of 2000MHz

2 GB virtual RAM

120 GB of disk space (100 GB allocated to video storage)

Disk I/O capacity of 125% the storage data rate calculated at: <https://exacq.com/config/>

Sufficient network bandwidth to support incoming video streams

exacqVision Enterprise Server license version 5.0 or later

## Recommended Provisions

4 virtual cores with a reservation of 6000MHz

6 GB of virtual RAM

Additional video storage space to meet video storage requirements

Disk I/O capacity of 150% the storage data rate calculated at: <https://exacq.com/config/>

Sufficient network bandwidth to support incoming video streams

Two independent subnets for cameras and exacqVision Client connections (four maximum)

