


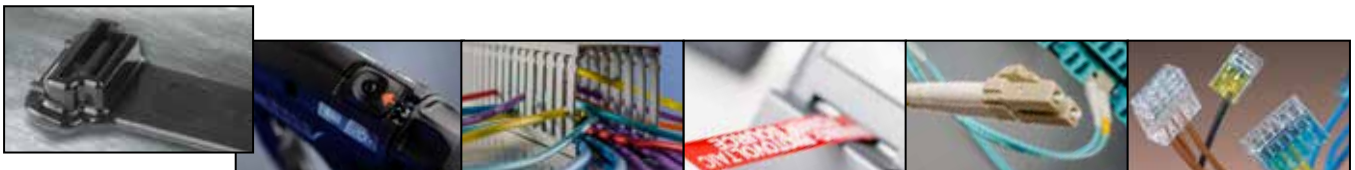

Adhesive Mounts



# Bundling & Securing

## Adhesive Mounts

### Wide Strap Cable Tie Mounting Base/Very High Bond

#### MB-Series Self-Adhesive Mounting Bases


HellermannTyton's Wide Strap Adhesive Mount pairs with our exclusive line of Wide Strap Cable Ties and is ideal for extreme-duty applications. The mount features 3M™ VHB™ (Very High Bond) adhesive, which actually builds strength over time and holds securely to difficult materials such as aluminum, steel, plastics and painted and powder-coated surfaces.

#### Features and Benefits

- Wide slot extends the versatility of our Wide Strap Cable Ties.
- Extremely durable adhesive achieves high pull-off force and is unaffected by vibration.
- Mount made of proprietary, impact-modified PA66 material for extraordinary durability, and is heat stabilized and UV resistant for extended life outdoors.
- Peel and stick for quick, convenient use in extreme-duty applications.



<b>MATERIAL</b>	<b>Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)</b>
Operating Temperature	-40°F to +176°F (-40°C to +80°C)
Flammability	UL 94 V2 (excluding adhesive)

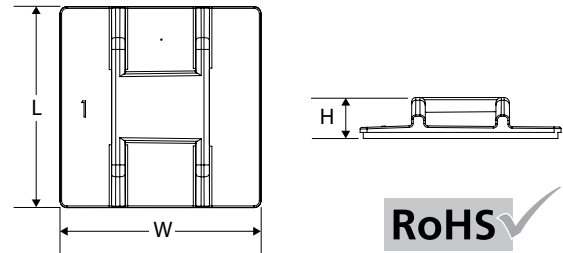

PART NO.	Article No.	Type	Cable Tie Width Max.		Adhesive	Length (L)		Width (W)		Height (H)		Color	Pkg Qty
			in.	(mm)		in.	(mm)	in.	(mm)	in.	(mm)		(pk)
<b>For use with 120 pound wide-strap cable ties to provide stability when securing bundles</b>													
<b>151-01857</b>	151-01857	WSMB5AHB	0.5	(12.7)	Acrylic foam	1.49	(37.7)	1.49	(37.7)	0.30	(7.7)	Black	100

Use Type for ordering and specification purposes.

### Instructions for use

1. Mounting surface must be thoroughly cleaned prior to applying adhesive pad. Use a 50/50 mix of isopropanol and water for best results, as commercial cleaners may leave residue.



2. Allow surface to completely dry before proceeding to next step.



3. Taking care not to touch adhesive, peel off protective backing.


### Cable Tie Mounting Base/Very High Bond

#### MB-Series Self-Adhesive Screwable Mounting Bases


HellermannTyton offers adhesive mounts in a variety of sizes to match your cable tie size and extreme-duty application needs. The mount features 3M™ VHB™ (Very High Bond) adhesive, which actually builds strength over time and holds securely to difficult materials such as aluminum, steel, plastics and painted and powder-coated surfaces.

#### Features and Benefits

- Extremely durable adhesive achieves high pull-off force and is unaffected by vibration.
- Multiple sizes accommodate a range of cable ties.
- 4-way opening allows cable ties to be installed parallel or perpendicular to wire bundles.
- Predrilled holes extend mounting options and security.
- Mount made of proprietary, impact-modified PA66 material for extraordinary durability, and is heat stabilized and UV resistant for extended life outdoors.
- Peel and stick for quick, convenient use in extreme-duty applications.

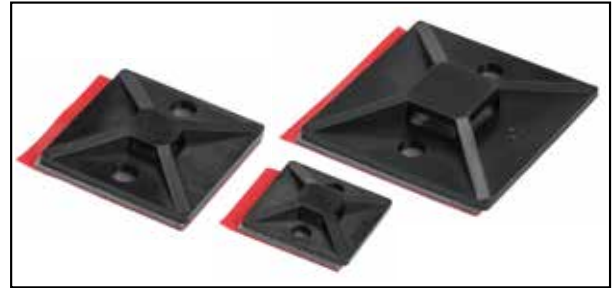


<b>MATERIAL</b>	<b>Polyamide 6.6 high impact modified, heat and UV stabilized (PA66HIRHSUV)</b>
Operating Temperature	-40°F to +176°F (-40°C to +80°C)
Flammability	UL 94 V2 (excluding adhesive)

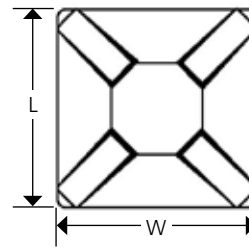


PART NO.	Article No.	Type	Cable Tie Width Max.		Adhesive	Length (L)		Width (W)		Height (H)		Color	Pkg Qty
			in.	(mm)		in.	(mm)	in.	(mm)	in.	(mm)		(pk)
<b>For use with 18 and 30 pound HellermannTyton cable ties</b>													
151-01629	151-01629	MB3A	0.14	(3.6)	Acrylic foam	0.75	(19.0)	0.75	(19.0)	0.19	(4.8)	Black	100
151-01630	151-01630	MB3A	0.14	(3.6)	Acrylic foam	0.75	(19.0)	0.75	(19.0)	0.19	(4.8)	Black	500
<b>For use with 18 through 50 pound HellermannTyton cable ties</b>													
151-01631	151-01631	MB4A	0.18	(4.6)	Acrylic foam	1.12	(28.5)	1.12	(28.5)	0.22	(5.6)	Black	100
151-01632	151-01632	MB4A	0.18	(4.6)	Acrylic foam	1.12	(28.5)	1.12	(28.5)	0.22	(5.6)	Black	500
<b>For use with 18 through 150 pound HellermannTyton cable ties</b>													
151-01633	151-01633	MB5A	0.35	(8.9)	Acrylic foam	1.49	(37.7)	1.49	(37.7)	0.28	(7.1)	Black	100
151-01634	151-01634	MB5A	0.35	(8.9)	Acrylic foam	1.49	(37.7)	1.49	(37.7)	0.28	(7.1)	Black	250


Use Type for ordering and specification purposes.

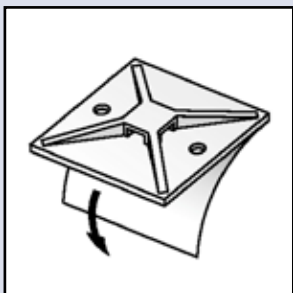

4. Press your thumb firmly against the mount for several seconds.

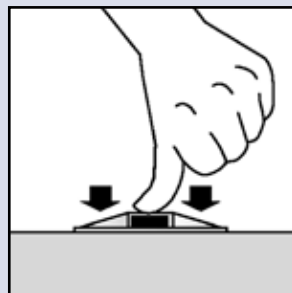

5. Wait several hours to allow the adhesive to fully bond with the surface.

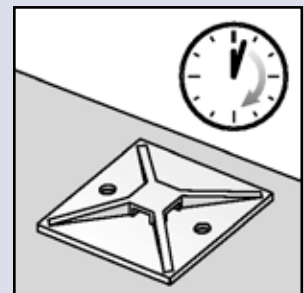



**HellermannTyton North American  
Corporate Headquarters**

7930 N. Faulkner Rd, PO Box 245017  
Milwaukee, WI 53224-9517  
Phone: (414) 355-1130, (800) 537-1512  
Fax: (414) 355-7341, (800) 848-9866  
email: corp@htamericas.com  
www.hellermann.tyton.com

***TS16949, ISO 9001, and ISO14001 certified***

**HellermannTyton Canada**

Unit #4, 205 Industrial Parkway North  
Aurora, Ontario L4G 4C4 Canada  
Phone: (800) 661-2461  
Fax: (800) 390-3904  
email: sales@hellermanntyton.ca

**HellermannTyton Mexico**

Anillo Periferico Sur 7980 Edificio 6A  
Parque Industrial Tecnologico II  
Santa María Tequepexpan  
Tlaquepaque, Jalisco, Mexico 45601  
Phone: 011-52-33-3-133-9880  
Fax: 011-52-33-3-133-9861  
email: info@htamericas.com.mx

***ISO 9001 certified***