

HEAD, FACE & WELDING



Hard Hats

Wherever there is a potential for falling objects, flying objects, impacts or bumps, hard hats should be there. Adjustable, imprintable and dependable, Honeywell has the hard hat to meet your needs. North® and Fibre-Metal® hard hats and accessories provide comfortable, reliable head protection your employees will want to wear, featuring stylish, lightweight shell designs, suspension height adjustment and comfortable padding. Our pin lock, quick fit and ratchet adjustment suspensions all make use of the natural shape of the head, providing workers with comfort all day long. Greater compliance and worker safety are an active part of our ongoing commitment to quality, innovation and the enhancement of head protection in the workplace.

Welding Helmets

Workers worldwide depend on Honeywell products for quality and rugged protection that helps reduce injuries, increases productivity and improves the quality of work life. All workers who find themselves in harm's way on the job deserve top performing protective equipment. That's why every product we make is focused on quality that performs – the kind of quality that results from using only the best grade raw materials, advanced product design and the latest technology. Each model is designed to have a full complement of exclusive performance and comfort features to satisfy the needs of today's high-production workers and ensure a safer, more productive workplace.





S9500 with S9555 visor

Uvex Turboshield™ Faceshield

- Patented head-cushioning suspension cradle
- Patent-pending push-button visor attachment and release system
- Toric-shaped visor provides 50% more chin coverage compared to traditional visors
- Large, ergonomically designed control knobs are easy to adjust
- Patented hard hat adapter design enables visor to slide back
- Dual-hinge adapter design increases clearance by as much as four inches
- Meets ANSI Z87.1-2010 and is certified to CSA Z94.3 standards

SKU	Description	Lens Coating
S9500	Ratchet Headgear, Black	n/a
S9510	Hard Hat Adapter, Black	n/a
S9550	Clear, PC Visor	Uncoated
S9555	Clear, PC Visor	Hardcoat, Anti-fog
S9570	Gray, PC Visor	Uncoated
S9575	Gray, PC Visor	Hardcoat, Anti-fog
S9560	UV/IR Shade 3.0, PC Visor	Uncoated
S9565	UV/IR Shade 5.0, PC Visor	Uncoated



S8500

Uvex Bionic® Faceshield

- Full shield design provides built-in chin protection and extended top-of-head coverage
- Excellent optics provide increased visibility
- Comfortably worn with most goggles and respirators
- Lightweight, balanced, ergonomic design for extended use
- Dual position headgear provides a customizable fit
- 100% dielectric – no metal parts
- Hard hat accessory (dielectric) expands face shield use and is compatible with multiple hard hats

SKU	Description	Lens Coating
S8500	Faceshield with Clear PC Visor	Uncoated
S8505	Faceshield & HH Adapter with Clear PC Visor (No Suspension)	Uncoated
S8510	Faceshield with Clear PC Visor	Hardcoat, Anti-fog
S8515	Faceshield & HH Adapter with Clear PC Visor (No Suspension)	Hardcoat, Anti-fog



KHG4001

North® Large Crown Headgear

- Universal mounting pattern accepts a wide range of available windows
- Large crown protector offers outstanding spark and debris protection
- Available in pinlock (PHG series) and SmoothLok™ ratcheting (KHG series) headgear
- 4000 series allows for fastest possible window exchange
- 5000 series designed with protected mounting system, preventing liquid from entering behind the window

SKU	Colors	Description
PHG4000	Black	Pinlock quick exchange
KHG4001	Black	SmoothLok quick exchange
PHG5000	Black	Pinlock protected mount
KHG5001	Black	SmoothLok protected mount

FACE SHIELDS



F300 with 4118CL window

Fibre-Metal® Heat-Resistant Headgear

- Crown made of tough, heat-resistant Noryl® material, the same as used in our welding helmets
- Available in 3 different crown depths (3," 4" and 7")
- Comfortable and proven 3C headgear is strip-proof and is guaranteed for the life of the headgear
- Simple window mounting pattern for a secure fit
- Accepts all F-M Quick-Lok® and Speedy® Loop accessories
- Available in ANSI Z87.1 and CSA Z94.3 certified models. SEI certified

SKU	Description
F300	3" Noryl crown
F400	4" Noryl crown
F500	7" Noryl crown



FM400DCCLC

Fibre-Metal® Dual-Crown Face Shields

- The ultimate in full face protection with 4" deep chin protectors in clear polycarbonate and tough Noryl materials
- Available with 4" and 7" deep crowns
- Choose from models with 3-C headgear or hardhat adapter
- Accepts all Quick-Lok® and Speedy® Loop accessories
- Available in ANSI Z87.1 and CSA Z94.3 certified models. SEI certified

SKU	Description
FM400DCCL	4" 3C crown with Noryl chin protector
FM400DCCLC	4" 3C crown with clear chin protector
FM70DCCL	4" crown, FM70 hardhat adapter with Noryl chin protector
FM5400DCCLC	7" Quick-Lok crown with clear chin protector



FM70

Fibre-Metal® Hard Hat Adapters

- Compatible with all Fibre-Metal®, North® and many competitive hard hat systems
- Available in heat-resistant aluminum or dielectric thermo-plastic construction
- Models for standard caps and full brim hard hats
- Window mounting system matches Fibre-Metal® headgear

SKU	Description
FM70	Dielectric thermo-plastic for caps
FH66	Aluminum for caps
FM71	Dielectric thermo-plastic for full brim hard hats



4178CL

Fibre-Metal® Impact-Resistant Replacement Windows

- Available in 3 sizes (standard, wide and extended view)
- Made of durable propionate for impact and chemical resistance (high heat-resistant gold-coated polycarbonate window also available)
- All windows are 0.060" thick
- Clear, welding shades 3 and 5, true-view gray, and gold coated
- Available in ANSI Z87.1 and CSA Z94.3 certified models. SEI certified

SKU	Description
4178CL	Wide clear
4199CL	Extended view clear
4118CL	Standard clear
4178DGN	Wide dark green
4199IRUV3	Extended view shade 3
4199IRUV5	Extended view shade 5



CP5005

North® Face Shield Hard Hat Adapters

- Aluminum heat-resistant and nylon brackets available
- Designed to fit all North® and Fibre-Metal® hardhats, as well as many competitive hardhats
- Accepts windows with universal mounting patterns
- Models available for cap-style and full brim hardhats

SKU	Description
CP5004	Aluminum Cap Style (fits A29, A59, A69, A79, A89 hard hats)
CP5005	Plastic Dielectric Cap Style (fits A29, A59, A69, A79, A89, A99 hard hats)
CP5007	Heat-Resistant Plastic Cap Style (fits A29, A59, A69, A79, A89, A99 hard hats)
CP5006	Plastic Dielectric Full Brim Style (fits A49, A119 hard hats)



A8152

North® Universal Mounting Replacement Windows

- Universal mounting pattern fits a wide range of available headgear
- 2 material choices: PETG and polycarbonate
- Flat and formed windows in 8 different widths for customized protection
- 2 thicknesses of material available: 0.040" and 0.060", lets you dial in weight and protection specific to your need

SKU	Tint	Material	Dimension
A8150/40, A8150/60	Clear	PETG	8" x 15.5" x 0.040" or 0.060" flat
A8152/40, A8152/60	Clear	Polycarbonate	8" x 15.5" x 0.040" or 0.060" flat
A0150/40	Clear	PETG	10" x 15.5" x 0.040" flat
A8154	Clear	Polycarbonate	8" x 15.5" x 0.040" curved
A8154G	Green	Polycarbonate	8" x 15.5" x 0.040" curved
A8155	Clear	Polycarbonate	6.25" x 15.5" x 0.040" curved
A8156	Clear	Polycarbonate	8" x 15.5" x 0.060" curved



N10R150000



North® Zone Hard Hat

- Sleek, modern shell design is low profile
- Four large areas for custom logo imprinting
- Multiple adjustment points allow for personalized comfortable fit
- One size/SKU fits vast majority of heads (no need to stock multiple SKUs)
- In both forward and reverse donning
- Available in 17 vibrant colors with 4-point Ratchet or Quick-Fit Pinlock suspension options
- ANSI Z89.1-2014 Type 1, Class E and CSA Z94.1-2015 Type 1, Class E

Quick Fit Style (Cap and Suspension Assembly)

SKU	Color
N10010000	White
N10020000	Yellow
N10030000	Orange
N10040000	Green
N10050000	Hi Viz Red
N10070000	Sky Blue
N10080000	Navy Blue
N10090000	Gray
N10100000	Tan
N10110000	Black
N10120000	Brown
N10130000	Gold
N10150000	Red
N10170000	Royal Blue
N10200000	Hot Pink
N10440000	Hi-Viz Strong Yellow
N10460000	Hi-Viz Strong Orange

Ratchet Style (Cap and Suspension Assembly)

SKU	Color
N10R010000	White
N10R020000	Yellow
N10R030000	Orange
N10R040000	Green
N10R050000	Hi Viz Red
N10R070000	Sky Blue
N10R080000	Navy Blue
N10R090000	Gray
N10R100000	Tan
N10R110000	Black
N10R120000	Brown
N10R130000	Gold
N10R150000	Red
N10R170000	Royal Blue
N10R200000	Hot Pink
N10R440000	Hi-Viz Strong Yellow
N10R460000	Hi-Viz Strong Orange

Replacement Parts

SKU	Description
N10S	Quick-Fit Replacement Suspension for N10
N10RS	Ratchet Replacement Suspension for N10
N10SB	Sweatband Replacement for N10
N10RC	Cradle Replacement for N10
N10CS	Chin Strap for N10




E1RW

Fibre-Metal® E1 Thermoplastic Full Brim Hard Hat

- Thermoplastic full brim hard hat with Fibre-Metal® smooth crown design
- The technically-advanced SuperEight® suspension balances and spreads weight over a wide area for added comfort and impact protection
- Available with the famous Fibre-Metal® non-slip/non-strip ratchet, SwingStrap™ or TabLok™ headgear
- Full brim adds an extra margin of protection from harmful UV rays, rain, and falling debris
- Available in a wide range of popular colors and full graphic designs
- Meets ANSI Z89.1-2009 Type 1, Class E, G, or C

SKU	Suspension
E1W	TabLok
E1RW	Ratchet
E1SW	SwingStrap

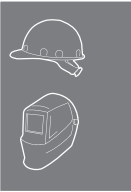

E2QRW

Fibre-Metal® E2 Smooth Crown Cap Style Hard Hat

- Thermoplastic cap style hard hat with Fibre-Metal® smooth crown design
- The technically-advanced SuperEight suspension balances and spreads weight over a wide area for added comfort and impact protection
- Available with the famous Fibre-Metal® non-slip/non-strip ratchet, SwingStrap or TabLok headgear
- Available in a wide range of popular colors and full graphic designs
- Meets ANSI Z89.1-2009 Type 1, Class E, G, or C in both forward and reverse donning

SKU	Suspension
E2W	TabLok
E2RW	Ratchet
E2SW	SwingStrap
E2QW	TabLok, Quick-Lok
E2QRW	Ratchet, Quick-Lok
E2QSW	SwingStrap, Quick-Lok



P2ARW

Fibre-Metal® P2A Fiberglass Cap Style Hard Hat

- Proprietary injection-molded fiberglass compound offers exceptional impact and crack resistance
- Solid-color resin provides a permanent, no-chip, no-peel finish.
- SuperEight® suspension balances and spreads weight over a wide area for added comfort and impact protection
- Available with non-slip/non-strip ratchet, SwingStrap or TabLok headgear
- Meets ANSI Z89.1-2009 Type I Class G (including Quick-Lok® model) and CSA Z94.1-2005 Type I Class G or C (Class C for Quick-Lok® model) in both forward and reverse donning

SKU	Suspension
P2AW	TabLok
P2ARW	Ratchet
P2ASW	SwingStrap
P2AQRW	Ratchet, Quick-Lok
P2AQSW	SwingStrap, Quick-Lok



HARD HATS



A49R01

North® The Everest A49 Full Brim Hard Hat

- Full brim HDPE shell with accessory slots
- Protects from the sun's UV rays, rain and falling debris
- 4-point or 6-point nylon suspension with 2-level height adjustment
- Meets ANSIZ89.1-2009 and CSAZ94.1-2005 Type 1 Class E

SKU	Suspension	Color
A4901	Pin Lock	White
A49R01	Ratchet	White
A4902	Pin Lock	Yellow
A49R02	Ratchet	Yellow
A4903	Pin Lock	Orange
A49R03	Ratchet	Orange



BC8607

North® BC86 Lightweight Bump Cap

- Low hazard bump cap
- Well ventilated and lightweight
- Ideal for food industry, mechanics, and truck drivers
- Not approved; do not use where ANSI or CSA head protection is required

SKU	Suspension	Color
BC8601	Pin Lock	White
BC8602	Pin Lock	Yellow
BC8607	Pin Lock	Sky Blue
BC8615	Pin Lock	Red

For additional models and colors, please visit www.honeywellsafety.com

HARD HATS



SE2

Fibre-Metal® SE2 Smooth Crown Cap Style Hard Hat

- Smooth crown design contains a technically advanced suspension
- SuperEight® impact energy control system dissipates force
- A lateral impact activates the patented attenuator band, which provides protection for the periphery of the cap
- E-2 Air-Flow design provides air circulation within shell
- Meets ANSI Z89.1-2009 Type 2, Class E and CSAZ94.1-2005 Type 2, Class E

SKU	Suspension
SE2	Ratchet
SE2QC	Ratchet, Model 4000 Quick-Lok



2999BV913SR

Fibre-Metal Tigerhood Futura® XXL with WAVE Plus ADA Technology Welding Helmet

- Wide View (110mm x 110mm), variable shade 9-13, solar-powered ADF
- Featured Angular Dependence Compensation (ADC) Plus Technology
- Highest optical quality available with a perfect DIN rating of 1/1/1/1
- Selectable shade 9-13 with Sensitivity and Delay adjustability
- Profile allows for the use of required safety eyewear and respirators
- Classic 3-C free-floating headgear balances and stabilizes helmet for unmatched comfort

SKU	Description
2999FMADF913	Tigerhood Futura (Silver) with 90mm x 110mm ADF Lens
2090XXL913W	Tigerhood Futura XXL (Silver) with 110mm x 110mm ADF Lens w/ ADC Plus



906GY

Fibre-Metal Tigerhood® Classic Extended Throat Protection Welding Helmet

- Flip-up Model 906 features a molded-in glass holder with a telescoping lid
- Unique helmet shell design provides extended throat protection
- Shell molded from Noryl®
- Exclusive 3-C headgear features multiple adjustments

SKU	Color
906BE	Blue
906BK	Black
906GY	Gray
906SR	Silver



110

Fibre-Metal Compact Pipeliner® Welding Helmet

- Molded from SuperGlas Plus™, the Pipeliner welding helmet is lightweight, strong, impervious to moisture and impact resistant
- Compact design

SKU	Description
110PWE	Pipeliner with 1-CP rubber headgear
110WH	Pipeliner with 1-CR ratchet headgear



HW200

Honeywell ADF Welding Helmets

- HW100 and HW200 welding helmets are available with solar-powered Shade 10 or variable Shade 9-13 ADF technology
- HW200 features sensitivity and delay adjustments, and grind mode functionality
- Meets ANSI Z87.1-2010 and is certified to the requirements of the CSA Z94.3 standards

SKU	Description	Color
HW100	Shade 10 ADF. 6.5" Window	Black
HW200	Variable Shade 9-13 ADF. 7.2" Window	Black