


Network Switches IFS® network switches from Interlogix are designed for high-bandwidth, real-time IP video performance for enterprise and industrial environments. They offer simple, powerful, built-in Web Services, full-power isolated PoE, built-in diagnostics and complete multicasting operation to reduce network bandwidth.

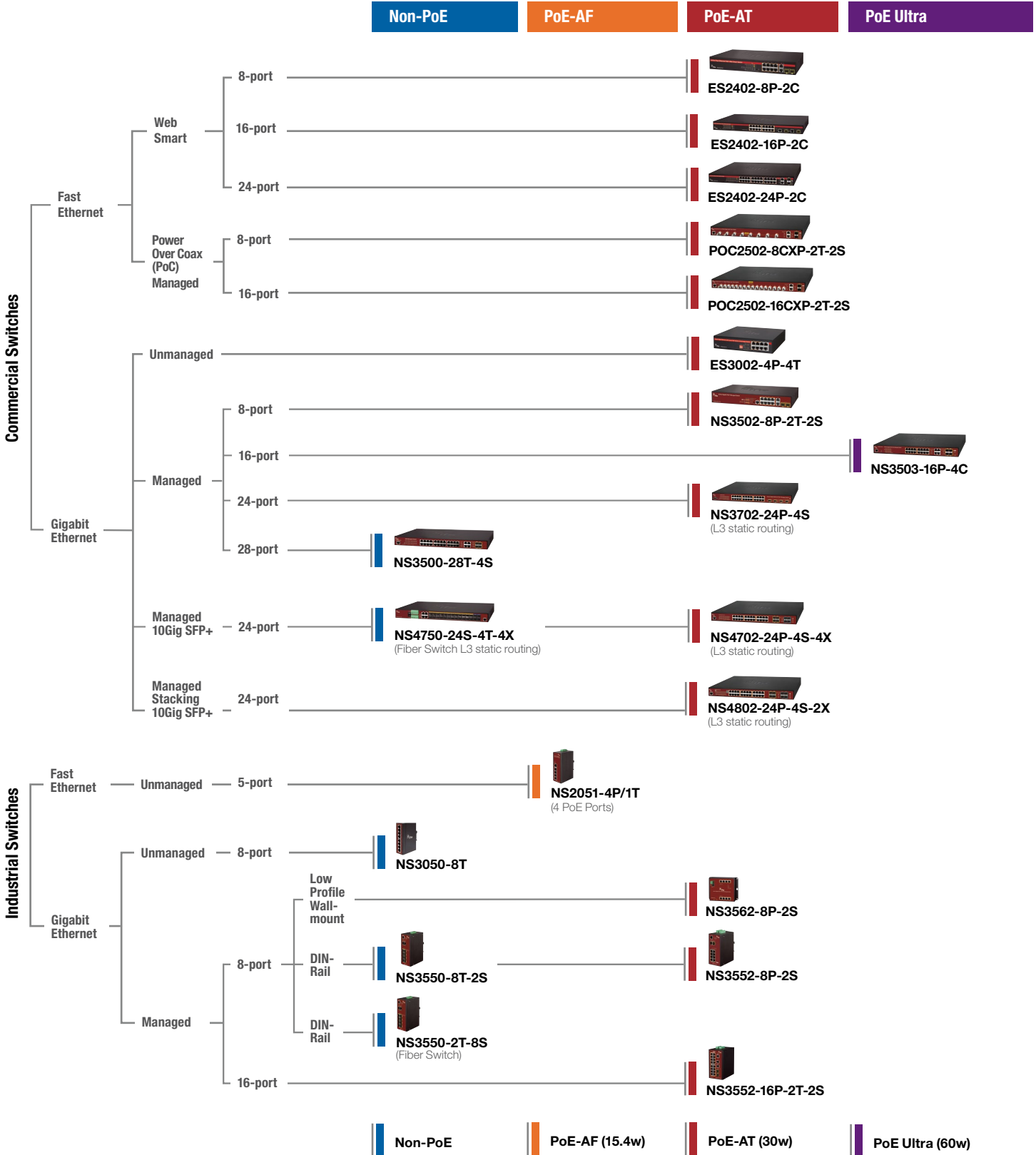

■ Non-PoE
 ■ PoE-AF (15.4w)
 ■ PoE-AT (30w)
 ■ PoE Ultra (60w)

Network Switches Comparison Matrix



Part Number	Port Type		Ports	PoE			Uplink Ports			Management				Environ.	Recommended Power Supply
	Fast Ethernet	Gigabit Ethernet		PoE (15.4w)	PoE+ (30.8w)	PoE Ultra (60w)	Uplink	SFP	SFP+	Unmanaged	Web Smart	Managed	L3 Static Routing		
Economy Switches															
ES3002-4P-4T		•	8	4	2					•					Built-in
ES2402-8P-2C	•		8	8	4		2 TP/SFP (Combo)	S20/S30 Series			•				Built-in
ES2402-16P-2C	•		16	16	7		2 TP/SFP (Combo)	S20/S30 Series			•				Built-in
ES2402-24P-2C	•		24	24	12		2 TP/SFP (Combo)	S20/S30 Series			•				Built-in
Network Switches															
NS3502-8P-2T-2S		•	8	8	5		2 SFP + 2 RJ45	S20/S30 Series				•			Built-in
NS3503-16P-4C		•	16	16	13	6	4 TP/SFP (Combo)	S20/S30 Series				•			Built-in
NS3500-28T-4S		•	28				4 SFP (Shared)	S20/S30 Series				•			Built-in
NS3702-24P-4S		•	24	24	12		4 SFP (Shared)	S20/S30 Series				•	•		Built-in
NS4702-24P-4S-4X		•	24	24	14		4 SFP 4 SFP+	S20/S30 Series	S30/S40 Series			•	•		Built-in
NS4802-24P-4S-2X		•	24	24	12		4SFP 2SFP+ 2 Stacking	S20/S30 Series	S30/S40 Series			•	•		Built-in
NS4750-24S-4T-4X		•	4 TP (Shared)				24 SFP 4 SFP+	S20/S30 Series	S30/S40 Series			•	•	•	Built-in or external DC Power Supply option (PS48VDC100W-DIN)
Industrial Switches															
NS2051-4P/1T	•		5	4			100Mbps (TP)	N/A			•			•	PS48VDC100W-DIN
NS3550-8T-2S		•	8				2 SFP	S20/S25 or S30/S35 Series				•		•	PS12VDC1.5A-U
NS3552-8P-2S		•	8	8	8		2 SFP	S20/S25 or S30/S35 Series				•		•	PS48VDC480W-DIN
NS3562-8P-2S		•	8	8	6		2 SFP	S20/S25 or S30/S35 Series				•		•	PS48VDC480W-DIN
NS3552-16P-2T-2S		•	16	16	13	6	2 RJ45/ 2 SFP	S20/S25 or S30/S35 Series				•		•	PS48VDC480W-DIN
NS3550-2T-8S		•	2				8 SFP	S20/S25 or S30/S35 Series				•		•	PS12VDC1.5A-U
NS3050-8T		•	8				1000Mbps (TP)	N/A			•			•	PS12VDC1.5A-U
Surge Protector															
ESP-300	•	•	1	Pass-through	Pass-through										N/A

Part Number	Fast Ethernet	BNC Ports	Power over Coax (36w)	Uplink	SFP	Managed	Power Supply
POC Switch							
POC2502-8CXP-2T-2S	•	8	•	2 RJ45/ 2 SFP	S20/S30 Series	•	Built-in
POC2502-16CXP-2T-2S	•	16	•	2 RJ45/ 2 SFP	S20/S30 Series	•	Built-in



interlogix.com/ifs

Specifications subject to change without notice.

© 2017 United Technologies Corporation.

All rights reserved.

All trademarks are the property of their respective owners.

Interlogix is part of UTC Climate, Controls & Security, a

unit of United Technologies Corporation.

2017/10 (GSP-2153)