

DATA SHEET

Compact Edge Cabinet



CECW4RUPL-M



Included Pivoting Panel Mount (Shown Installed)
Note: Patch Panel not included

Note: Knock outs shown pre-removed to demonstrate their location.
Knock outs will not be pre-removed on shipped cabinet.

Overview

The Compact Edge Cabinet (CEC) series wall-mount cabinet offer a unique versatile solution for edge computing, purpose built for equipment and application advancements all in a small form factor. The low-profile design positions rack mount equipment vertically, while allowing access for upgrades, refreshes and adds/drops. When opened the back-pan equipment and connectivity remain in place while the enclosure swings out maximizing accessibility and management. The CEC series cabinet is capable of housing a complete network, including up to 4RU of traditional rack mount equipment, power, thermal management and connectivity. Deploy the cabinet for a low-profile, edge solution that can support any application.

Features

- Wide Open Access: When opened the back-pan, equipment, and connectivity remain in place – While the enclosure swings out allowing unfettered accessibility and management.
- PCI Compliance: User access is controlled by an integrated swing handle with lock.
- Vertical Rack Mount: Enables low-profile mounting allowing for easy installation, access, and maintenance.
- Maximizing Space: Two pairs of 4 RU rails are supplied to mount a variety of network equipment, auxiliary equipment, power and panel. One Pivoting Panel Mounting Bracket Kit has been supplied to free up vertical space and improve access to the rear of installed patch panels. (Additional kits sold separately - CECPPM1RU)

Compact Edge Cabinets

Part Number	Height	Rail Type	Door Type	Load Rating	Description
CECW4RUPL-x	26.4 in	4 RU	Plexiglass	135 lbs**	Compact Edge Cabinet, 4 RU, Plexiglass Door
CECW4RUPD-x	26.4 in	4 RU	Perforated	135 lbs**	Compact Edge Cabinet, 4 RU, Perforated Door
CECW4RUSD-x	26.4 in	4 RU	Solid	135 lbs**	Compact Edge Cabinet, 4 RU, Solid Door

NOTE: Replace x with M (Magnesium), B (Black), W (White)

NOTE: ** Certified Load Rating per UL2416 is 135lbs total (125 per pair mounting rails and 10lbs on the door)

Accessories

Part Number	Description
CECPPM1RU	Pivoting Panel Mount Bracket Kit
VWMFKS-115	Single Fan Kit, 4-1/2 in Fan, 115V, 110 CFM, With Fan Guard, Power Cord, and Hardware

DATA SHEET

Compact Edge Cabinet


General Information

- **Installation:** Wall Mount
- **Product Series:** Compact Edge Cabinet
- **Type:** Wall Mount Enclosure
- **Door Type:**
 - Plexiglass: CECWM4RUPL-x
 - Perforated: CECWM4RUPD-x
 - Solid: CECWM4RUSD-x
- **x = Color:**
 - Magnesium: M
 - Black: B
 - White: W

Listing Agencies/Third Party Certifications




Certified Load Ratings Per UL 2416

 135 lb overall weight load capacity
125 lb capacity per pair of mounting rails
10 lb capacity on the door

Technical Information

- **Mounting Hardware Included:** No
- **Compatibility:**
 - 19 in EIA Rack Mount Equipment
 - PHDH 19 in Modular Panels
 - Clarity HDJ High Density Jacks
 - Infinium HDFM Fiber Modules
 - Infinium HDCA Fiber Cassettes
- **Integrated Swing Handle with Lock:** PCI Compliant
- **Fan Openings:** 4 x 4-1/2 in square with perforations
- **Hinge:**
 - Reversible / Removable Door Retention Cleat
 - Opens to 100° mounted to a smooth surface
- **Cable Management Included:**
 - Cable Knock Outs
- **Overall Dimensions:**
 - Height: 26.64 in
 - Width: 23.25 in
 - Depth: 7.91 in
- **Mounting Hole Center-to-Center:**
 - Width: 16 in

CECWM4RUxx

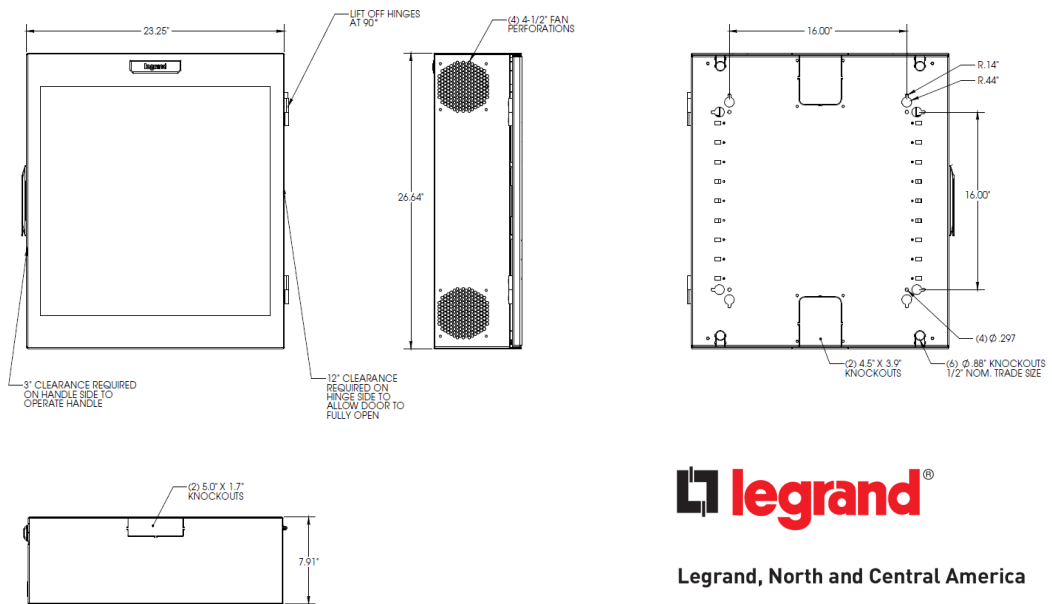

Legrand, North and Central America

60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us