

Milestone
HUSKY™ M10

Access anywhere



Milestone
Mobile



XProtect®
Web Client



XProtect®
Smart Client



An easy choice for entry-level surveillance

Combination of custom-designed hardware and easy-to-use software requires no training to set up or use

Product highlights

Simple to set up and easy to operate

Plug in and operate **within minutes**

Automatic camera discovery
detects and configures cameras

Simple to operate without any
training

User management capability for the
administration of multiple system
operators

Live video from all cameras in one
viewing interface on a network
computer**

**Not possible with a monitor connected directly to the NVR

Ideal for entry-level surveillance

Simple view and playback

Easy video export for forensic
evidence and investigations

Pan-tilt-zoom (PTZ) controls

Built-in **motion detection**

Choose from **more than 2,600**
native camera drivers

Industry's **best mobile app** for free

Includes **3-year hardware warranty**

Scalable solution using Milestone Interconnect™

Build a **multi-site solution** at a reduced
cost

Connect multiple Husky M10 NVRs for
unlimited scalability and cost
effectiveness

Create simpler solutions at remote
sites and still take advantage of the
premium XProtect® Corporate features
from a central location

Future-proof solution because the
system can be expanded as needed


*XProtect Smart Client has a defined feature set specifically for the
Husky M10

Milestone HUSKY™ M10

Front and rear panel



Front

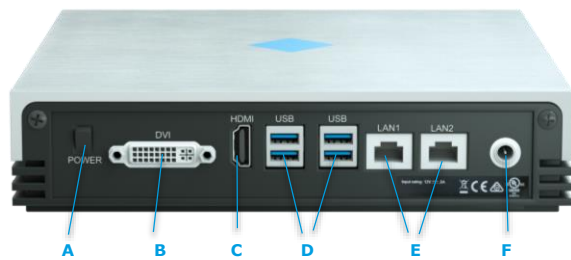

Rear interfaces

- A. 1 x Power switch
- B. 1 x DVI
- C. 1 x HDMI
- D. 4 x USB 3.0
- E. 2 x GbE RJ45
- F. 1 x Power input

Performance, 8 cameras

Resolution	FPS	Record always	Record motion 20%
1280x720	25	4 days	21 days
1280x720	10	10 days	50 days
1920x1080	10	5 days	25 days

Ordering information

SKU	Description
HM10-1T-8	1x1TB, 8 licenses, ATOM, 4GB RAM
HMCP-M10	1 year Care Plus

Specification

General	Detail
Form factor	Small, fanless
Type of deployment	Single unit
Dimensions	20(W) x 20(D) x 4.5(H) cm 7.9(W) x 7.9(D) x 1.8(H) in
Maximum number of cameras	8
Maximum recording rate	62 Mbit/s
Camera licenses included	8
Maximum number of users	Unlimited
Dual network interface cards	Yes
CPU	ATOM
Passmark	664
Operating system support	Linux
Memory	4GB
Storage system	Detail
Video storage	1TB
Drive type	Western Digital Purple Drives
Video management system	Detail
VMS preloaded	Milestone Arcus
Milestone Care Basic	Included
Milestone Care Plus	Optional
Hardware warranty	Three years included
Automatic camera discovery	Yes
Supports ONVIF cameras	Yes
Codec support	H.264, MJPEG, MPEG4, MxPEG
Pan-tilt-zoom (PTZ) support	Yes
Audio support	Yes, one-way ¹
Milestone Interconnect support	Yes
Customer Dashboard support	Yes, with Milestone Care Plus
Electrical	Detail
Power input	60W / 100~240V
Maximum power consumption	15.8W
Environmental	Detail
Operation temperature	0~40°C
Storage temperature	-20°C ~70°C
Humidity	10~90% relative humidity (non-condensing)
Other	Detail
Regulatory compliance	CE (class A), WEEE, FCC (class A), RCM, UL, PSE, VCCI, Mexico (CoC), South Africa (CoC), Singapore PSB

¹Only with exported video