

NEW

Milwaukee[®]

M18 FUEL[™]

DRIVEN TO OUTPERFORM.[™]



UP TO
500^{FT-LBS}
MAX FASTENING
TORQUE

UP TO
2X
MORE
RUN-TIME

UP TO
3X
MOTOR
DURABILITY

**7/16" Hex Utility
Impacting Drill**

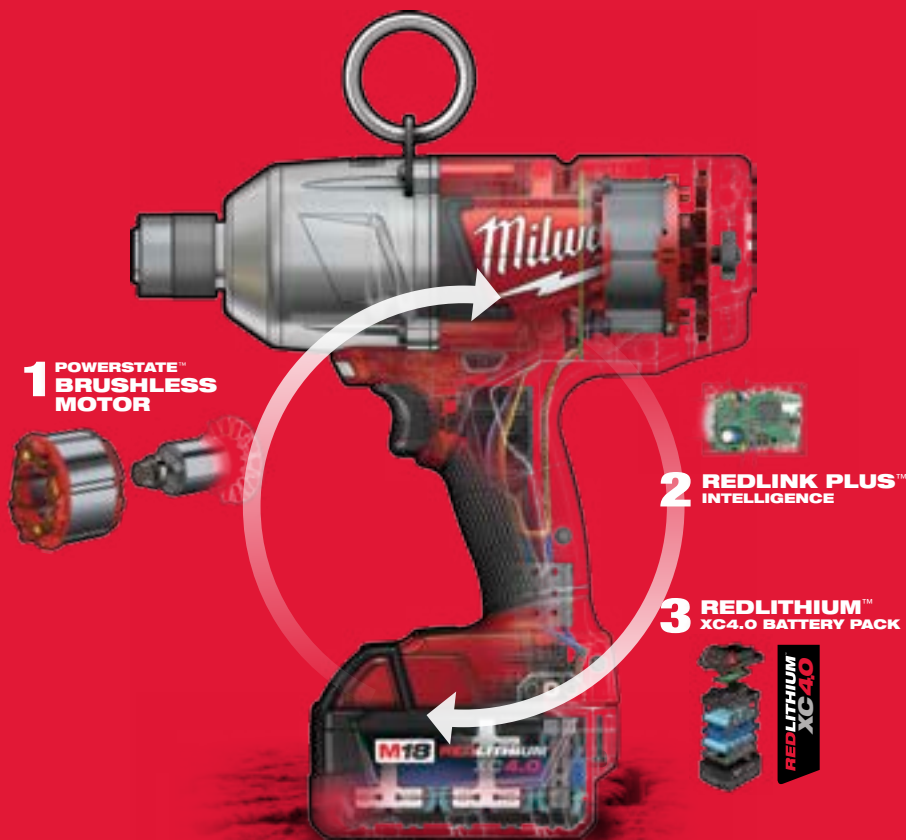
2765-22

REDLITHIUM[™]
XC4.0





UP TO
500 FT-LBS
MAX FASTENING
TORQUE

UP TO
2X
MORE
RUN-TIME

UP TO
3X
MOTOR
DURABILITY




M18 FUEL™ 2765-22 VS COMPETITORS

	Milwaukee®	Milwaukee®	Bosch	Makita
				
	2765-22	2665-22	HTH182-01	LXWT01
Motor	POWERSTATE™ Brushless	4-Pole Neo	Can	2-Pole Ferrite
Max Fastening Torque	500 ft.-lbs.	350 ft.-lbs.	500 ft.-lbs.	300 ft.-lbs.
Impacts Per Minute	0 – 2,300	0 – 2,200	0 – 2,100	0 – 2,200
Length	9-1/4"	9-1/2"	10-3/4"	10-3/4"
Drive-Control™	Yes	No	No	No
LED Light	Yes	No	Yes	Yes
Powered By	REDLITHIUM™ XC4.0	REDLITHIUM™	Li-ion	Li-ion

PROPRIETARY 2-MODE DRIVE CONTROL™

2765	MODE 1	MODE 2
No Load Speed (RPM/IPM)	0 – 1,200 / 0 – 1,700	0 – 1,700 / 0 – 2,300
Max Fastening Torque	300 ft.-lbs.	500 ft.-lbs.

AVAILABLE ACCESSORIES

SHIP AUGER BITS 	
48-13-5680	11/16" x 18"
48-13-5810	13/16" x 18"
48-13-5930	15/16" x 18"
48-13-6010	1-1/16" x 18"



M18 FUEL™ 7/16" Hex Utility Impacting Drill (Tool-Only)
2765-20

Includes: 2765-20 M18 FUEL™ 7/16" Hex Utility Impacting Drill



M18 FUEL™ 7/16" Hex Utility Impacting Drill (Kit - 2 Batteries)
2765-22

Includes: 2765-20 M18 FUEL™ 7/16" Hex Utility Impacting Drill, (2) M18™ REDLITHIUM™ XC4.0 Extended Capacity Battery Packs, M18™ AC/DC Charger, and Contractor Bag