

**NEW**

*Milwaukee*<sup>®</sup>

# **M18** FUEL™

**DRIVEN TO OUTPERFORM.™**



UP TO  
**700**<sup>FT-LBS</sup>  
MAX FASTENING  
TORQUE

UP TO  
**1100**<sup>FT-LBS</sup>  
NUT-BUSTING  
TORQUE

UP TO  
**2X**  
MORE  
RUN-TIME

**1/2" High Torque Impact  
Wrench with Friction Ring**

2763-22

**REDLITHIUM™  
XC4.0**


**1/2" HIGH TORQUE IMPACT WRENCH WITH FRICTION RING**

**M18 FUEL™**





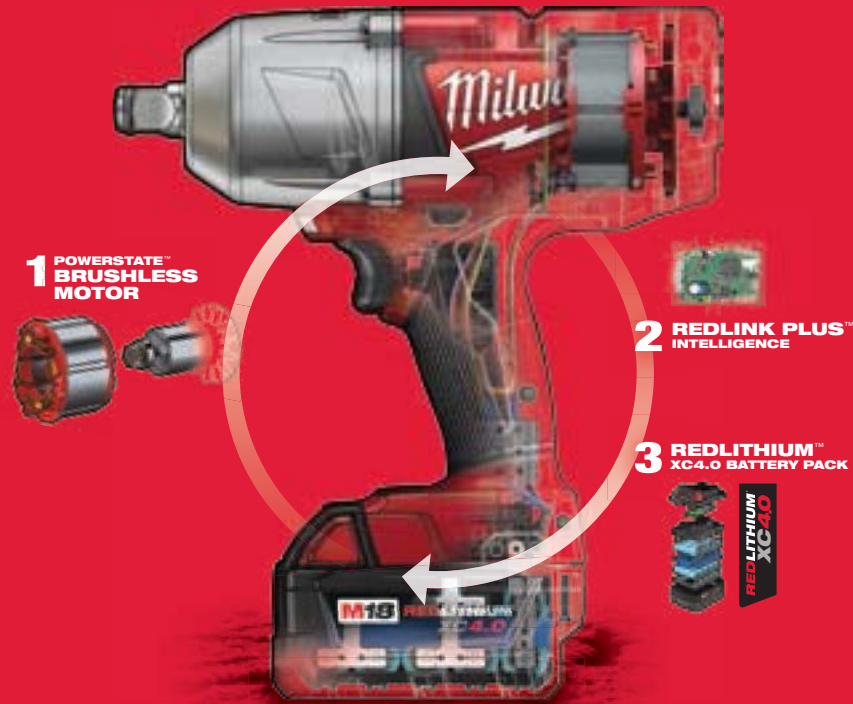

UP TO  
**700**<sup>FT-LBS</sup>  
MAX FASTENING  
TORQUE

UP TO  
**1100**<sup>FT-LBS</sup>  
NUT-BUSTING  
TORQUE

UP TO  
**2X**  
MORE  
RUN-TIME



**M18 FUEL™ 2763-22 vs COMPETITORS**

	Milwaukee®	Milwaukee®	Ingersoll	Ingersoll	Snap-On	Bosch
						
	<b>2763-22</b>	2663-22	2135TIMAX	W17150	CT7850	HTH181-01
Motor	POWERSTATE™ Brushless	4-Pole Neo	Air	Can	Can	Can
Impacts Per Minute	0 – 2,300	0 – 2,200	0 – 1,250	0 – 2,300	0 – 2,100	0 – 2,100
Max Fastening Torque	700 ft.-lbs.	450 ft.-lbs.	550 ft.-lbs.	650 ft.-lbs.	450 ft.-lbs.	500 ft.-lbs.
Nut-Busting Torque	1,100 ft.-lbs.	700 ft.-lbs.	1,100 ft.-lbs.	1,100 ft.-lbs.	700 ft.-lbs.	500 ft.-lbs.
Length	9"	8-7/8"	8-3/8"	9-1/2"	9-1/4"	9-1/4"
Drive-Control™	Yes	No	No	No	No	No
Variable Speed	Yes	Yes	Yes	Yes	Yes	Yes
LED Light	Yes	No	No	No	Yes	Yes
Powered By	REDLITHIUM™ XC4.0	REDLITHIUM™	Compressor	Li-ion	Li-ion	Li-ion

**PROPRIETARY 2-MODE DRIVE CONTROL™**

2763	MODE 1	MODE 2
No Load Speed (RPM/IPM)	0 – 325 / 0 – 450	0 – 1,700 / 0 – 2,300
Max Fastening Torque	100 ft.-lbs.	700 ft.-lbs.



**M18 FUEL™ 1/2" High Torque Impact Wrench w/ Friction Ring (Tool-Only)**  
2763-20

Includes: 2763-20 M18 FUEL™ 1/2" High Torque Impact Wrench w/ Friction Ring



**M18 FUEL™ 1/2" High Torque Impact Wrench w/ Friction Ring (Kit - 2 Batteries)**  
2763-22

Includes: 2763-20 M18 FUEL™ 1/2" High Torque Impact Wrench w/ Friction Ring, (2) M18™ REDLITHIUM™ XC4.0 Extended Capacity Battery Packs, M12™ & M18™ Multi-Voltage Charger, and Carrying Case