

## Fiber Optic Tray Cables and Patch Cords

### BE-Series Cables

**D JACKET: -40°C TO +85°C, SUN, OIL, & FUNGUS RESISTANT**

FIBER COUNT	OM1 MULTI-MODE (62.5/125)	OM3 MULTI-MODE (50/125)	OS2 SINGLE MODE
2	BE002DWLS9KR	BE002DALT9KR	BE002DSLX9KR
6	BE006DWLS9KR	BE006DALT9KR	BE006DSLX9KR
12	BE012DWLS9KR	BE012DALT9KR	BE012DSLX9KR
24	BE024DWLS9KR	BE024DALT9KR	BE024DSLX9KR

**Z JACKET: LOW SMOKE ZERO HALOGEN, SUN, & FUNGUS RESISTANT**


FIBER COUNT	OM1 MULTI-MODE (62.5/125)	OM3 MULTI-MODE (50/125)	OS2 SINGLE MODE
2	BE002ZWLS9KR	BE002ZALT9KR	BE002ZSLX9KR
6	BE006ZWLS9KR	BE006ZALT9KR	BE006ZSLX9KR
12	BE012ZWLS9KR	BE012ZALT9KR	BE012ZSLX9KR
24	BE024ZWLS9KR	BE024ZALT9KR	BE024ZSLX9KR

**J JACKET: -50°C TO +75°C & OIL RESISTANT, SUN, & FUNGUS RESISTANT**


FIBER COUNT	OM1 MULTI-MODE (62.5/125)	OM3 MULTI-MODE (50/125)	OS2 SINGLE MODE
2	BE002JWLS9KR	BE002JALT9KR	BE002JSLX9KR
6	BE006JWLS9KR	BE006JALT9KR	BE006JSLX9KR
12	BE012JWLS9KR	BE012JALT9KR	BE012JSLX9KR
24	BE024JWLS9KR	BE024JALT9KR	BE024JSLX9KR

### Patch Cord Configurator


**Level 1 Construction**

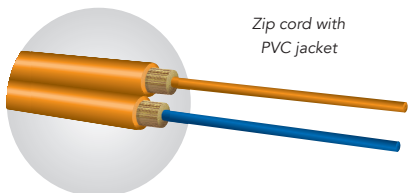

**Level 2 Construction**

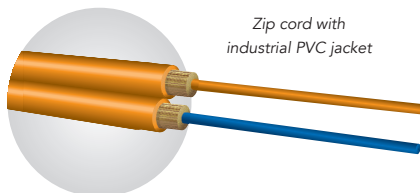

**Level 3 Construction**

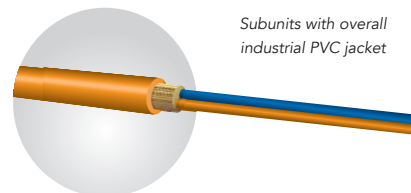


Ex:

L1	-	1	-	OS2	-	05	-	LC	-	LC	-	025
<b>LEVEL</b>		<b>FIBERS</b>		<b>FIBER</b>		<b>COLOR</b>		<b>CONNECTOR 1</b>		<b>CONNECTOR 2</b>		<b>FOOTAGE FT</b>
L1		1		OM1		08 - ORANGE		LC		LC		ANY
L2		2		OM3		16 - AQUA		ST		ST		
L3				OS2		05 - YELLOW		SC		SC		
								LCV1 (L3)		LCV1 (L3)		

**Example:**

L1-1-OS2-05-LC-LC-025 = Level 1, 1 Fiber, Single Mode, Yellow, LC, LC, 25 Feet

L1-2-OS2-05-LC-LC-025 = Level 1, 2 Fiber, Single Mode, Yellow, LC, LC, 25 Feet

 Connectivity, Enclosures, and Adapter Plates


## Pre-Polished Fiber Optic Connectivity

### XPRESS ULTRA SC CONNECTORS WITH 2.0mm BOOT

PART NUMBER	PART DESCRIPTION
RFC-SC6-2MM-12	FIBER CONN, PRE-POLISHED, SC, 62.5, 2MM, 12 PACK WITH TOOL (OM1)
RFC-SC5G-2MM-12	FIBER CONN, PRE-POLISHED SC, OM3/OM4, 2MM, 12 PACK WITH TOOL (OM 3/4)
RFC-SC8-2MM-12	FIBER CONN, PRE-POLISHED, SC, SM, 2MM, 12 PACK WITH TOOL (OS2)
RFC-SCAPC-2MM-12	FIBER CONN, PRE-POLISHED, SC, APC, 2MM, 12 PACK WITH TOOL (OS2)

### XPRESS ULTRA LC CONNECTORS WITH 2.0mm BOOT

PART NUMBER	PART DESCRIPTION
RFC-LC6-2MM-12	FIBER CONN, PRE-POLISHED, LC, 62.5, 2MM, 12 PACK WITH TOOL (OM1)
RFC-LC5G-2MM-12	FIBER CONN, PRE-POLISHED, LC, OM3/OM4, 2MM, 12 PACK WITH TOOL (OM 3/4)
RFC-LC8-2MM-12	FIBER CONN, PRE-POLISHED, LC, SM, 2MM, 12 PACK WITH TOOL (OS2)
RFC-LCAPC-2MM-12	FIBER CONN, PRE-POLISHED, LC, APC, 2MM, 12 PACK WITH TOOL (OS2)

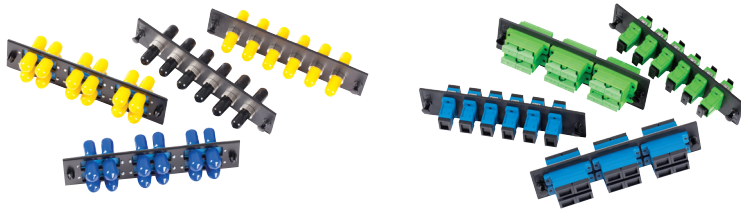

## Fiber Optic Adapter Plates

PART NUMBER	PART DESCRIPTION
616SC50G	6-PORT ADAPTER PLATE, MULTIMODE, SC 50 MICRON (OM3/4)
616SMSC	ADAPTER PLATE W/6- SC SIMPLEX CERAMIC ADAPTERS
616MMSC	ADAPTER PLATE W/6-SC SIMPLEX BRONZE ADAPTERS
6112SMDSC	ADAPTER PLATE W/6-SC DUPLEX BRONZE ADAPTERS
6112MMDSC	ADAPTER PLATE W/6-SC DUPLEX BRONZE ADAPTERS
6112DSC50G	12-PORT ADAPTER PLATE, MULTI-MODE, DUAL SC 50 MICRON (OM3/4)
616SMST	ADAPTER PLATE W/6-ST SIMPLEX CERAMIC ADAPTERS
616MMST	ADAPTER PLATE W/6-ST SIMPLEX BRONZE ADAPTERS
6112DST	12-PORT ADAPTER PLATE, DUAL ST (OM1)
6112SMST	12-PORT ADAPTER PLATE, SINGLE MODE, ST (OS2)
616DLC	6-PORT ADAPTER PLATE, SINGLE MODE, DUAL LC (OS2)
616DLC50G	6-PORT ADAPTER PLATE, MULTI-MODE, DUAL LC, 50 MICRON (OM3/4)
616MMDLC	ADAPTER PLATE W/6-LC DUPLEX BRONZE ADAPTERS
6112SMDLC	ADAPTER PLATE W/6-LC DUPLEX CERAMIC ADAPTERS
6112MMDLC	ADAPTER PLATE W/6-LC DUPLEX BRONZE ADAPTERS
6112DLC50G	12-PORT ADAPTER PLATE, MULTI-MODE, DUAL LC, 50 MICRON (OM3/4)



### CORPORATE HEADQUARTERS

5290 Concourse Drive | Roanoke, VA 24019 | USA

Phone: +1-540-265-0690 | 800-622-7711

Fax: +1-540-265-0724

## Industrial Enclosures



### DIN-RAIL SYSTEM ENCLOSURES

PART NUMBER	PART DESCRIPTION
DTC1AP	DIN RAIL HOLDS 1 ADAPTER PLATE
DTC2AP	DIN RAIL HOLDS 2 ADAPTER PLATES



### WTC SERIES CABINETS

PART NUMBER	PART DESCRIPTION
ZDMB6B	WALL MOUNT BOX HOLDS 1 ADAPTER PLATE
WTC12/24X	WALL MOUNT CABINET HOLDS UP TO 4 ADAPTER PLATES
WTC48X	WALL MOUNT CABINET HOLDS UP TO 8 ADAPTER PLATES



### RTC AND RTS SERIES – RACK MOUNT FIBER ENCLOSURES

PART NUMBER	PART DESCRIPTION
RTS1U-3APB	RACK MOUNT SLIDING, 1RU, HOLDS UP TO 3 ADAPTER PLATES
RTS2U-6APB	RACK MOUNT SLIDING, 2RU, HOLDS UP TO 6 ADAPTER PLATES
RTC1U-3APB	RACK MOUNT FIXED, 1RU, HOLDS UP TO 3 ADAPTER PLATES
RTC2U-6APB	RACK MOUNT FIXED, 1RU, HOLDS UP TO 6 ADAPTER PLATES