

# → Hospitality Collection Catalog

AUDIO VISUAL SOLUTIONS FOR HOSPITALITY APPLICATIONS



# Make your guest's experience one-of-a-kind

Peerless-AV® has provided innovation in hospitality for over 50 years. We understand the service industry and the importance of creating that one-of-a-kind guest experience. Keeping guests entertained and informed is paramount to staying competitive and Peerless-AV has the industry's most comprehensive line of solutions for outfitting the entire hotel facility, including solutions for digital signage advertising, wayfinding, interactive and outdoor displays and kiosks.

- Our Custom Solutions Team can help you solve even the most complex design and technology integration challenges.
- Peerless-AV products give guests the experience they want, with the décor and aesthetics you demand.
- We work closely with hotel owners and designers, as well as technology providers and display manufacturers to stay on the cutting edge of the industry.
- Call a dedicated Peerless-AV sales representative who can answer all of your hospitality questions, making sure you Get It Right.



# Outdoor Displays

The unique design of the Peerless-AV® Xtreme™ Display and UltraView™ TV are perfect for outdoor applications. These displays are an all-in-one solution for hospitality installations including hotel, pool decks, restaurant patios, and more.



Accessories ..... page 15



WEATHER RESISTANT



Xtreme™ Outdoor Daylight Readable Displays

Landscape / Portrait\*



\*CLP models contain polarized glass for optimal viewing with polarized sunglasses

CL-42PLC68-OB / CLP-42PLC68-OB	CL-47PLC68-OB / CLP-47PLC68-OB	CL-55PLC68-OB / CLP-55PLC68-OB
Display Size 42" Diagonal	Display Size 47" Diagonal	Display Size 55" Diagonal
Resolution 1920 x 1080		
Operating Temperature -40°F to 140°F		

- Daylight Readable Full HD 1080p resolution for bright, crisp picture
- Fully-sealed design prevents water, dust or insects from entering the display
- Patented Dynamic Thermal Transfer™ system keeps internal components safely warmed in extreme cold and properly cooled in extreme heat
- Ambient light sensor automatically adjusts brightness to best match the lighting conditions



UltraView™ Outdoor TV



UV491	UV551	UV651
TV Size 49" Diagonal	TV Size 55" Diagonal	TV Size 65" Diagonal
Resolution 1920 x 1080		
Operating Temperature -24°F to 122°F		

- LED backlight and full HD 1080p resolution for a bright, crisp picture



Outdoor Universal Tilt Wall Mount



EPT650	ESA763PU
Display Size 32" to 75"	Display Size 32" to 80"
Max Load 175lb (79kg)	Max Load 200lb (90.7kg)
Mounting Pattern 738 x 405mm (29.04"W x 15.95"H)	Mounting Pattern 730 x 405mm (28.74"W x 15.95"H)

- Made of corrosion resistant materials for weather resistance
- One-Touch™ tilt allows adjustment of +15°/-5°

# Universal Pull-Out Swivel, Pivot & Articulating Wall Mounts

Peerless-AV® pull-out swivel, pivot and articulating mounts are versatile and sleek. The pull-out swivel mounts are perfect for on-wall or recessed/in-furniture applications, while the pivot and articulating mounts allow for viewing in any part of the room.



Pull-Out Pivot Wall Mount	<b>SMARTMOUNT.</b> Pull-Out Pivot Wall Mount with Tilt	Pull-Out Pivot Wall Mount	DesignerSeries™ Universal Ultra Slim Articulating Wall Mount	DesignerSeries™ Universal Ultra Slim Articulating Wall Mount	<b>SMARTMOUNT.</b> Pivoting Wall Mount	<b>SMARTMOUNT.</b> Articulating Wall Mount	<b>SMARTMOUNT.</b> Pivoting Wall Mount	<b>SMARTMOUNT.</b> Articulating Wall Mount
HPF650	SP840	FPS-1000	SUA747PU	SUA761PU	SP730P	SA730P	SP740P	SA740P
Display Size 32" to 55"		Display Size 26" to 60"	Display Size 32" to 50" Ultra-thin TVs less than 3" (76mm) deep	Display Size 37" to 65" Ultra-thin TVs less than 3" (76mm) deep	Display Size 10" to 29"	Display Size 10" to 29"	Display Size 22" to 40"	Display Size 22" to 40"
Max Load 60lb (27kg)		Max Load 150lb (68kg)	Max Load 60lb (27kg)	Max Load 80lb (36kg)	Max Load 25lb (11kg)	Max Load 25lb (11kg)	Max Load 80lb (36kg)	Max Load 80lb (36kg)
VESA® Pattern 200 x 200 to 400 x 400mm		VESA® Pattern 100 x 100 and 200 x 100mm <i>Non-VESA® compliant displays require display-specific adaptor to be purchased separately.</i>	Mounting Pattern 400 x 400mm (15.75"W x 15.75"H)	Mounting Pattern 600 x 400mm (23.62"W x 15.75"H)	VESA® Pattern 75 x 75 and 100 x 100mm	VESA® Pattern 75 x 75 and 100 x 100mm	VESA® Pattern 100 x 100, 200 x 100 and 200 x 200mm	VESA® Pattern 100 x 100, 200 x 100 and 200 x 200mm
<ul style="list-style-type: none"> <li>Lightweight design and in-furniture application make mount well suited for use with today's LEDs</li> </ul>	<ul style="list-style-type: none"> <li>Essential for on-the-wall, low-profile, single or multi-display video wall installations or hospitality recessed applications</li> </ul>	<ul style="list-style-type: none"> <li>Up to ±90° of side-to-side swivel</li> <li>One-Touch™ tilt offers +15°/-5° of viewing angle adjustment</li> <li>Up to ±0.5" (13mm) of vertical adjustment for post-installation leveling and height adjustment fine-tuning</li> <li>Internal cable management provides clean, professional installation finish</li> </ul>	<ul style="list-style-type: none"> <li>±90° of pivot allows for perfect TV positioning</li> <li>One-Touch™ tilt offers ±35° of viewing angle adjustment</li> <li>Internal cable management provides clean, professional installation finish</li> </ul>	<ul style="list-style-type: none"> <li>±90° of pivot allows for perfect TV positioning</li> <li>One-Touch™ tilt offers +15°/-5° of viewing angle adjustment</li> <li>Up to ±0.5" (13mm) of vertical adjustment for post-installation leveling and height adjustment fine-tuning</li> <li>Internal cable management provides clean, professional installation finish</li> </ul>				

# SmartMount® Universal Flat & Tilt Wall Mounts

With Peerless-AV's line of SmartMount® flat and tilt wall mounts, you'll get versatile and easy to install solutions. The flat wall mounts offer a low-profile design that complement today's ultra slim displays while the tilt wall mounts are designed to create the optimal viewing angle.



Accessories ..... page 15



**SMARTMOUNT.**  
Flat Wall Mount



**SMARTMOUNT.**  
Universal Flat Wall Mount



**SMARTMOUNT.**  
Universal Flat Wall Mount



**SMARTMOUNT.**  
Universal Flat Wall Mount



**SMARTMOUNT.**  
Tilt Wall Mount



**SMARTMOUNT.**  
Universal Tilt Wall Mount



**SMARTMOUNT.**  
Universal Tilt Wall Mount



**SMARTMOUNT.**  
Universal Tilt Wall Mount

<b>SF632</b>	<b>SF640</b>	<b>SF650</b>	<b>SF660</b>	<b>ST632</b>	<b>ST640</b>	<b>ST650</b>	<b>ST660</b>
Display Size 22" to 40"	Display Size 32" to 50"	Display Size 39" to 75"	Display Size 39" to 80"	Display Size 22" to 40"	Display Size 32" to 50"	Display Size 39" to 75"	Display Size 39" to 80"
Max Load 115lb (52kg)	Max Load 150lb (68kg)	Max Load 175lb (79kg)	Max Load 200lb (91kg)	Max Load 115lb (52kg)	Max Load 150lb (68kg)	Max Load 175lb (79kg)	Max Load 200lb (91kg)
VESA® Pattern 75, 100, 200 x 100 and 200 x 200mm	Mounting Pattern 450 x 405mm (17.72"W x 15.95"H)	Mounting Pattern 742 x 405mm (29.21"W x 15.95"H)	Mounting Pattern 824 x 405mm (32.44"W x 15.95"H)	VESA® Pattern 75, 100, 200 x 100 and 200 x 200mm	Mounting Pattern 458 x 405mm (18.02"W x 15.95"H)	Mounting Pattern 742 x 405mm (29.21"W x 15.95"H)	Mounting Pattern 824 x 405mm (32.44"W x 15.95"H)

- Low-profile design holds display 1.02" (25mm) away from the wall

- Open wall plate design allows for total wall access, increasing electrical and cable management options

- Low-profile design holds display only 1.20" (30mm) from the wall

- Up to 0.25" (6mm) of vertical adjustment on each universal display adaptor bracket for post-installation leveling and height adjustment fine-tuning

- +15°/-5° tilt adjustment without the use of tools

- Open wall plate design allows for total wall access, increasing electrical and cable management options

- Adjustable up to 15° of forward tilt and -5° backward tilt for optimal viewing angle

- Up to 0.25" (6mm) of vertical adjustment on each universal display adaptor bracket for post-installation leveling and height adjustment fine-tuning

# Desktop Swivel Mounts & Security Solutions

Peerless-AV® Desktop Swivel Mounts offer a secure, functional and sleek desktop surface mount for hospitality applications. These mounts seamlessly connect to a variety of flat panel displays, with easy access to cable input connections and provide discreet security that doesn't get in the way of viewing enjoyment.



Accessories ..... page 15

RoHS



Desktop Swivel Mount

HP432-002

Display Size  
26" to 37"

Max Load  
80lb (36.4kg)

VESA® Pattern  
100 x 100, 200 x 100  
or 200 x 200mm



Desktop Swivel Mount

HP447

Display Size  
32" to 47"

Max Load  
75lb (34.1kg)

VESA® Pattern  
200 x 100, 200 x 200mm




Universal Desktop Swivel Mount

HP455

Display Size  
32" to 55"

Max Load  
75lb (34.1kg)

VESA® Pattern  
200 x 200, 200 x 400,  
300 x 300 and 400 x 400mm

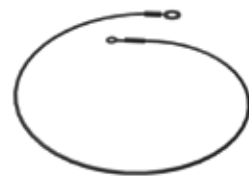

Display Base Lock-down Security Kit

HLC-KIT(-Q10)

Max Load  
100lb (45.3kg)

VESA® Pattern  
Compliant with all VESA®  
mounting hole patterns

- Base plate bolts down for safety and security

- Built-in swivel up to 360° allows for optimum viewing angle

- Optional slope nuts included for added security

- Easily installs to virtually any wood surface

# Stands & Carts

When mounting to a wall is not an option or when mobility is key, Peerless-AV® flat panel stands and carts provide a complete solution. Maneuverability is made easy with swivel casters on the carts, while the stand provides versatility and security.



Accessories ..... page 15

RoHS



Flat Panel Floor Stand

FPZ-600

Display Size  
Up to 75"

Max Load  
200lb (90.7kg) per display  
up to four displays

VESA® Pattern  
100, 200 x 100  
and 200 x 200mm  
Supports additional VESA®  
patterns with PLP display adaptor,  
sold separately

- Fits single or back-to-back displays (up to four with additional dual-display cartridge)



Flat Panel Cart

SR560M

Display Size  
32" to 75"

Max Load  
150lb (68.2kg) for the display  
25lb (11.4kg) per shelf

VESA® Pattern  
200 x 200 to 600 x 400mm

- The pre-assembled base and UL® certification ensure quick assembly while providing a ridged, but attractive, structure that fits into any décor



Full Featured Flat Panel Cart

SR575M



Cart for use with the Microsoft® Surface™ Hub 55" or 84"

SR598-HUB

Display Size  
55" to 98"

Max Load  
300lb (136.1kg) for the display

VESA® Pattern  
200 x 200 up to 1200 x 600mm

- The cart sits at Microsoft's recommended viewing height, and offers vertical adjustment so the display can be positioned at any height up to 60" from the floor



Flat Panel Video Conference Cart

SR555E

Display Size  
(2) 40" to 55"

Max Load  
150lb (68.2kg)  
75lb (34.1kg) per display

VESA® Pattern  
up to 400 x 400mm  
for each display

- (2) 2RU rack mount locations provide ample space for rack mountable components

# Kiosk Solutions

Choose from a versatile array of sleek, slim and attractive kiosk enclosures for virtually any application. Our kiosks are customizable in every way—from the choice of technology to custom paint and vinyl wraps. If you can envision it, we can make it happen. Visit our online KioskBuilder™ to create a custom kiosk that fits your technology needs - kiosks.peerless-av.com



**NEW!**

### Floor Standing Portrait Kiosk

For 40", 42" 46", 47", 48", 49", 50", 55" displays up to 3" thick

*KIPC548 shown with custom color and integrated web camera*



### Floor Standing Portrait Kiosk

For 40", 42", 46", 47", 48", 55" displays up to 4" thick

*KIP542 shown with vinyl wrap*



**NEW!**

### Floor Standing Landscape Kiosk

For 40", 42" 46", 47", 48", 55" displays up to 4.00" thick

*KILH542 shown in black*



### Floor Standing Landscape Kiosk

For 40", 42" 46", 47", 48", 55" displays up to 3.24" thick

*KIL548 shown in black*



### In-Wall Kiosk, Portrait & Landscape models

For 40", 42", 46", 47", 48", 55" displays up to 2.00" thick

*KIP746-S shown in silver*



### Wall Kiosk, Portrait & Landscape models

For 40", 42" 46", 47", 48", 55" displays up to 3.10" thick

*KIL655 shown with custom color*



**NEW!**

### Ultra Stretch Portrait Kiosk

For the LG 86BH5C Ultra Stretch Signage Display(s)

*KIP586-4LG shown in black*



### Don't see a design or size you're looking for?

Contact our dedicated Kiosk design team to develop a solution that perfectly matches your vision at 800-865-2112 or info@peerless-av.com

In addition, count on Peerless-AV® enclosures for:

- Fast screen set-up
- Range of sizes—from tablet to 90" screens\*
- Easy accessibility to components for maintenance and upgrades
- Optional fan-cooling systems to extend component life
- Additional add-ons include speakers, amplifier, interactive technology, screen protection, antimicrobial paint finishes, power management, and more
- Security features such as key-locked or combination locked doors

\* Some sizes may require custom design

# Wireless Solutions

Stream HD content wirelessly throughout conference and meeting rooms with Peerless-AV's PeerAir™ Pro and Wireless Flat Panel Display Cart.



peerAir™ | PRO

Wireless AV Multi-Display System Powered by HD Flow™ 3



## HDS300

Wireless Distance  
210ft (64m)

Signal Support  
1080p (60Hz) (24/30 fps)

Wireless Protocol 802.11n	Compression Standard h.264 Encoding	Content Protection HDCP Compliant
------------------------------	--	--------------------------------------

Multicast up to six PeerAir Pro Wireless Receivers\*  
\*Requires additional receiver units

- Transmits through walls, floors, and ceilings for multi-room streaming
- Plug-and-play setup requires no software or driver installation



Wireless Flat Panel Display Cart



## WL-SR560M-300

Wireless Distance  
210ft (64m)

Signal Support  
1080p (60Hz) (24/30 fps)

Display Size 32" to 75"	Max Load 150lb (68.2kg) for the display 25lb (11.4kg) per shelf	VESA® Pattern 200 x 200 to 600 x 400mm
----------------------------	---	--

- Includes everything needed to stream wireless Full HD 1080p and passive 3D content to the mounted display through walls, floors or ceilings
- Built-in 3-tap grounded outlet for wireless components and display power, allowing for only one power cable to be routed to the power outlet

# AV Racks

Peerless-AV's Preconfigured Racks are designed to help manage components, while giving an organized, polished look to any AV installation. These racks are ideal for security system components, in-room entertainment systems, and more.



Enclosed Racks

## AV18

18 Space Rack

Max Load  
500lb (226.8kg)  
50lb (22.7kg)  
per 2U shelf

## AV27

27 Space Rack

Max Load  
750lb (340.2kg)  
50lb (22.7kg)  
per 2U shelf

## AV42

42 Space Rack

Max Load  
1100lb (500kg)  
50lb (22.7kg) per 2U shelf  
100lb (45.4kg) per 5U shelf

- Racks come fully assembled, eliminating time-consuming installation costs
- One complete SKU fulfills all your rack needs, making ordering simple

# Accessories



ACC-HPF650  
In-furniture accessory bracket




IBA-3AC(-W)  
Recessed Cable Management and Power Storage Accessory Box\*  
\*Works with most displays 42" and larger without being visible from behind when used with the HPF650. Verify dimensions for confirmation of compatibility.



IBA2(-W)  
In-Wall Accessories Box



IBA2AC(-W)  
In-Wall Accessories Box with 125V Duplex Power Receptacle

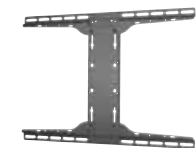

PLP-UNL  
Universal Adaptor Bracket for 32" to 90" Displays



ACC316  
Safety Belt



ACC320  
Electrical Outlet Strip with Cord Wrap

Visit [peerless-av.com](http://peerless-av.com) for a complete line of accessories.



With 75 years of experience in the audio visual industry, our commitment to the creation of cutting-edge technology and industry standard solutions have empowered us to become an innovative leader in the industry. From well-designed, quality-built products, to unmatched customer service, to outstanding custom project capabilities, Peerless-AV continues to help you and your business thrive with best-in-class AV.

peerless-AV®




ALSO AVAILABLE:



Kiosk Solutions



Outdoor Digital Kiosks

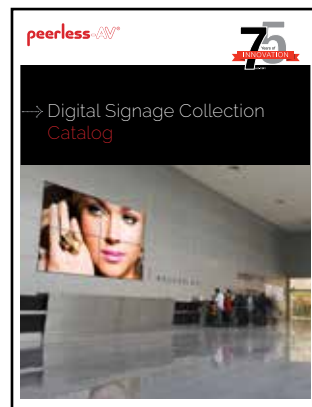

Digital Signage  
Collection Catalog

**peerless-av.com**  
**800-865-2112**