

# PowR-Teck™ MC CABLE CONNECTORS

## For Jacketed MC and Teck Cable

Made in the USA, Remke PowR-Teck MC Cable Connectors feature an exclusive one-piece design. Other manufacturers give you 4 or 5 pieces to assemble and if you lose one you're out of luck. But not with Remke!

## Choose Remke PowR-Teck Connectors:

- Featuring exclusive PowR-Lock grounding seal with stainless steel tines that ground the connector to the MC cable.
- No disassembly required meaning fast & easy installations. Just push the cable through, tighten the connector and you're done!
- Designed to form a watertight seal around jacketed metal cable and at the enclosure entry
- Rated NEMA 4 and IP 65
- Available in 1/2" to 4" sizes in aluminum, nickel-plated aluminum and stainless steel.

## Specifications & Dimensions

### Material

- Aluminum
- Nickel-Plated Aluminum
- Type 304 Stainless Steel
- Embedded Viton O-Ring

### Certifications

- NEMA 4
- IP 65
- CSA – File # 28985

### Flammability Rating


- UL 94V-2

### Temperature Range

- Aluminum: -40°F to +300°F (-40°C to +149°C)
- Stainless Steel: -60°F to +1000°F (-51°C to +537°C)



## DIMENSIONAL INFORMATION

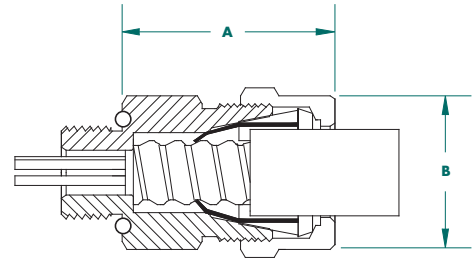

Hub Size	Dimension A (IN.)	Dimension B (IN.)
1/2"	2.10	1.53
3/4"	2.45	2.20
1"	2.45	2.47
1 1/4"	3.35	2.97
1 1/2"	3.70	3.50
2"	4.05	4.15
2.5"	4.10	4.60
3"	4.50	5.68
3.5"	4.60	6.02
4"	4.75	6.52



CSA STANDARD: C22.2 NO.18-98  
FILE NUMBER: 28985  
RATINGS: NEMA 4, IP65  
PATENT PENDING



made  
in USA

# REMKE