

# REMKE RSSS SERIES STAINLESS STEEL, CORROSION RESISTANT CORD CONNECTORS


## American-Made In Sizes from 3/8" to 3" With or Without Wire Mesh

Made in the USA, Remke RSSS Stainless Steel Cord Connectors provide the greatest durability against corrosion, harsh climatic conditions, harmful environmental influences and high humidity.

### Remke Stainless Steel Cord Connectors:

- Feature a body and compression nut made of Type 304 stainless steel (standard) with Type 316 available upon request
- Available with or without stainless steel wire mesh
- Embedded Buna-A O-Ring
- Combination tightening surface features unique design that provides a large wrenching area for easy installation.
- Knurl section offers an extra gripping surface for initial hand tightening.
- Recommended for use in washdowns or high moisture environments

### Dimensions:

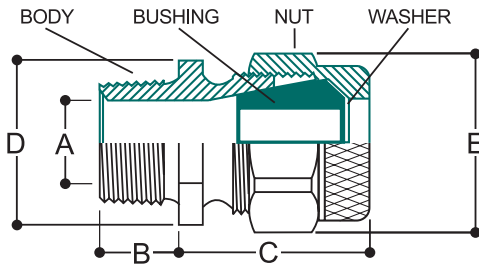

### STAINLESS STEEL

Conduit Size	Form Size	A Inside Body Dia.	B	C	D Body Hex	E Nut Dia.
3/8"	1	0.47	0.44	0.56	0.94	0.88
1/2"	2	0.62	0.56	0.69	1.12	1.26
3/4"	3	0.81	0.56	0.85	1.37	1.37
1"	4	1.00	0.63	0.94	1.56	1.56



### Specifications

#### Material

- Standard – Type 304 Stainless Steel
- Available – Type 316 Stainless Steel

#### Certifications

- UL Listed – File # E53599
- CSA – File # 28985
- ROHS and WEE Compliant

#### Flammability Rating

- Fitting UL94V-2, Mesh Grip UL94HG
- Temperature Range
- -60°F to +1000°F (-51°C to +537°C)

#### IP Rating

- IP 54/NEMA 3 and 3R
- IP 65/NEMA 4
- IP 56/NEMA 4X
- IP 67/NEMA 6
- IP 52/NEMA 12



# REMKE