

# FiberNOW™

The fiber cabling solutions you need, shipped in 5 days or less



## Available now. Ready to ship.

Hardly what you're used to hearing when it comes to high-performance fiber cabling, right? But that's exactly what the FiberNOW program delivers. Backed by Siemon's innovative manufacturing processes and optimized logistics, FiberNOW delivers the industry's shortest lead times on select fiber cabling and connectivity, with both standard and custom-configured products **shipped in 5 days or less**. Contact your local Siemon representative for more information, or call (1) 860.945.4200.

An example BOM supported by one-week lead time would include up to 25 fiber enclosures, 50 (12 fiber) MTP trunks, 100 (12 fiber) cassettes and 200 jumpers. Lead times on larger orders may be longer. Terms and conditions apply, program Available in US, Canada & Mexico Only, see below for information.

## Rack-Mount Fiber Enclosures

Max quantity to ship in 5 days after received order: 25 Pieces


Siemon Base Part Number	Size	Description
FCP3-DWR-4A	1U	High-Density, Sliding Drawer, Supports 4 PPM/PEM Modules/Adapters
FCP3-DWR	1U	Standard Density, Sliding Drawer, Supports 3 RIC/PP2 Modules/Adapters
RIC3-36-01	2U	Standard Density, Sliding Drawer, Supports 6 RIC/PP2 Modules/Adapters
RIC3-72-01	4U	Standard Density, Sliding Drawer, Supports 12 RIC/PP2 Modules/Adapters



## LC Fiber Adapter Plates

Max quantity to ship in 5 days after received order: RIC - 150 pieces, PPM - 25 pieces

Siemon Base Part Number	Fiber Count	Description
RIC-F-LCQ12-01C	12	RIC/FCP3 Footprint, LC, Aqua Adapters, Ceramic Sleeve
RIC-F-LCU12-01C	12	RIC/FCP3 Footprint, LC UPC, Blue Adapters, Ceramic Sleeve
RIC-F-LCQ24-01C	24	RIC/FCP3 Footprint, LC, Aqua Adapters, Ceramic Sleeve
RIC-F-LCU24-01C	24	RIC/FCP3 Footprint, LC UPC, Blue Adapters, Ceramic Sleeve
PPM-F-LCQ12-01	12	FCP3-4A Footprint, LC, Aqua Adapters, Ceramic Sleeve
PPM-F-LCU12-01	12	FCP3-4A Footprint, LC UPC, Blue Adapters, Ceramic Sleeve
PPM-F-LCQ24-01	24	FCP3-4A Footprint, LC, Aqua Adapters, Ceramic Sleeve
PPM-F-LCU24-01	24	FCP3-4A Footprint, LC UPC, Blue Adapters, Ceramic Sleeve

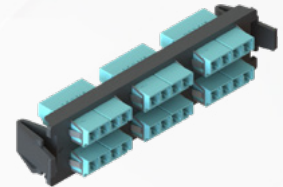

## Fiber Cassettes

Max quantity to ship in 5 days after received order: 12F - 100 pieces, 24F - 50 pieces

Siemon Base Part Number	Fiber Count	Fiber Type	Description
PP2F12LS5V01LB1	12F	OM4	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B1, Ultra Low Loss
PP2F12LS5V01LB2	12F	OM4	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B2, Ultra Low Loss
PP2F-12LSSM01B1	12F	OS2	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B1, Std. Loss
PP2F-12LSSM01B2	12F	OS2	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B2, Std. Loss
PP2F24LS5V01LB1	24F	OM4	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B1, Ultra Low Loss
PP2F24LS5V01LB2	24F	OM4	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B2, Ultra Low Loss
PP2F-24LSSM01B1	24F	OS2	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B1, Std. Loss
PP2F-24LSSM01B2	24F	OS2	Std. Density, RIC/FCP3 Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B2, Std. Loss
PPMF24LS5V01LB1	24F	OM4	HD, FCP3-4A Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B1, Low Loss
PPMF24LS5V01LB2	24F	OM4	HD, FCP3-4A Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B2, Low Loss
PPMF-24LSSM01B1	24F	OS2	HD, FCP3-4A Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B1, Std. Loss
PPMF-24LSSM01B2	24F	OS2	HD, FCP3-4A Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B2, Std. Loss
PEMF24-LSLV-B1A	24F	OM4	HD, Base8, FCP3-4A Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B1, Low Loss
PEMF24-LSLV-B2A	24F	OM4	HD, Base8, FCP3-4A Footprint, Shuttered LC (Aqua)-to-MTP-F (Gray), Polarity B2, Low Loss
PEMF24-LSSA-B1A	24F	OS2	HD, Base8, FCP3-4A Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B1, Std. Loss
PEMF24-LSSA-B2A	24F	OS2	HD, Base8, FCP3-4A Footprint, Shuttered LC (Blue)-to-MTP-F (Black), Polarity B2, Std. Loss



## BladePatch® LC-LC Duplex Jumpers

Max quantity to ship in 5 days after received order: 200 pieces

Siemon Base Part Number	Fiber Count	Fiber Type	Description
LBP-LCLC5V-01AQ	2	OM4	BladePatch LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 1 meter
LBP-LCLC5V-02AQ	2	OM4	BladePatch LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 2 meter
LBP-LCLC5V-03AQ	2	OM4	BladePatch LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 3 meter
LBP-LCULCUL-01	2	OS2	BladePatch LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 1 meter
LBP-LCULCUL-02	2	OS2	BladePatch LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 2 meter
LBP-LCULCUL-03	2	OS2	BladePatch LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 3 meter



## Duplex LC-LC Jumpers

Max quantity to ship in 5 days after received order: 200 pieces

Siemon Base Part Number	Fiber Count	Fiber Type	Description
FJ2-LCLC5V-01AQ	2	OM4	LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 1 meter
FJ2-LCLC5V-02AQ	2	OM4	LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 2 meter
FJ2-LCLC5V-03AQ	2	OM4	LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 3 meter
FJ2-LCLC5V-05AQ	2	OM4	LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 5 meter
FJ2-LCLC5V-10AQ	2	OM4	LC-LC, Duplex, Aqua Jacket, Aqua Connector, Riser (OFNR), 10 meter
FJ2-LCULCUL-01	2	OS2	LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 1 meter
FJ2-LCULCUL-02	2	OS2	LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 2 meter
FJ2-LCULCUL-03	2	OS2	LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 3 meter
FJ2-LCULCUL-05	2	OS2	LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 5 meter
FJ2-LCULCUL-10	2	OS2	LC-LC, Duplex, Yellow Jacket, Blue Connector, Riser (OFNR), 10 meter



## MTP-LC Equipment Cords

Max quantity to ship in 5 days after received order: 50 pieces

Siemon Base Part Number	Fiber Count	Fiber Type	Description
TL2NCVPPF1(ZZ)(XXX)(Y)	8	OM4	MTP-LC BladePatch Equipment Cord, Plenum (OFNP)
TF2NCAPF1(ZZ)(XXX)(Y)	8	OS2	MTP-LC BladePatch Equipment Cord, Plenum (OFNP)



ZZ = LC Fiber Position: (LB) Reversed or (BL) Continuous  
 XXX = Length: in 3 digits. Ex. 003M = 3 meters, 010F = 10 feet  
 Y = (M) meters or (F) feet

## Plug-n-Play Base12 MTP-MTP Fiber Trunks

Base 12 MTP-MTP RazorCore Fiber trunks, Plenum

Max quantity to ship in 5 days after received order: 100 x MTP Connectors. Ex. 50 x 12F MTP-MTP Trunks or 25 x 24F MTP-MTP Trunks

F(X)(XX)(X)-(XX)P(XXX)(X)-(X)

### Configuration

**R** = Standard Loss  
**L** = Ultra Low Loss (OM4 Only)

### Fiber Count

**12** = 12  
**24** = 24  
**48** = 48\*  
**96** = 96\*  
**144** = 144\*

### Gender

**Blank** = Female  
**M** = Male\*\* (recommended)

### Polarity Method

**A** = Method A  
**B** = Method B (recommended)  
**C** = Method C

### Length Unit


**F** = Feet  
**M** = Meters

### Length

Must be 3 digits  
**Example: 003** = 3m  
**010** = 10ft

### Fiber Type

**5V** = OM4, XGLO 550 50/125 Multimode Aqua  
**SM** = OS1/OS2, Singlemode Yellow

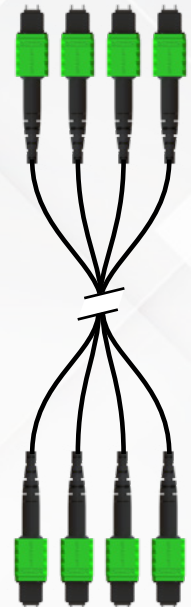

\* Singlemode Only

\*\* 144 Fiber Count Trunks with Male MTP Connectors Please Use Following Configurator F(X)144M-(XX)P(XXX)(X)(X)

## Plug-n-Play Base8 MTP-MTP Fiber Trunks

Base 8 MTP-MTP RazorCore Fiber trunks, Plenum

Max quantity to ship in 5 days after received order: 100 x MTP Connectors. Ex. 50 x 8F MTP-MTP trunks or 16 x 24F MTP-MTP trunks

G(X)(XXX)(X)(XX)P(XXX)(X)-(X)

### Performance

**R** = Standard Loss  
**L** = Ultra Low Loss (OM4 Only)

### Fiber Count

**8** = 8  
**16** = 16  
**24** = 24  
**48** = 48\*  
**96** = 96\*  
**144** = 144\*

### Gender

**-** = Female  
**M** = Male (recommended)

### Polarity Method

**A** = Method A  
**B** = Method B (recommended)  
**C** = Method C

### Length Unit

**F** = Feet  
**M** = Meters

### Length

Must be 3 digits  
**Example: 003** = 3m  
**010** = 10ft

### Fiber Type

**5V** = OM4, XGLO 550 50/125 Multimode Aqua  
**SM** = OS1/OS2, Singlemode Yellow



\* Singlemode Only

## 8F Base8 MTP-MTP Jumpers using MTP Pro connectors

Base 8 MTP PRO-MTP PRO RazorCore Fiber Jumpers, 2mm (0.079 in.), Plenum  
 Max quantity to ship in 5 days after received order: 50 pieces

GJ(X)P(X)P(X)(X)-(XXX)(X)-(X)

### Performance

**S** = Standard Loss  
**L** = Low Loss OM4 Only

### Polarity Method

**A** = Method A  
**B** = Method B  
**C** = Method C

### Fiber Type

**V** = OM4, XGLO 550 50/125 Multimode Aqua  
**A** = OS1/OS2, Singlemode Yellow

### Side A

**M** = Male  
**F** = Female (recommended)

### Side B

**M** = Male  
**F** = Female (recommended)

### Length Unit

**F** = Feet  
**M** = Meters

### Length

Must be 3 digits  
**Example: 003** = 3m  
**010** = 10ft



## LC to LC Fiber Trunks

LC Duplex to LC Duplex RazorCore Fiber Trunks, Plenum.

Max quantity to ship in 5 days after received order: 240 x Simplex Connectors. Ex. 10 x 12F LC-LC Trunks or 5 x 24F LC-LC Trunks

TFU(X)(X)(X)P(X)(X)(X)(X)(XXX)(X)

### Fiber Count

**C** = 12      **J** = 96\*  
**E** = 24      **K** = 144\*  
**G** = 48\*

### Length Unit

**F** = Feet  
**M** = Meters

### Pulling Eye

**A** = Side A      **C** = Side A&B  
**B** = Side B      **D** = None

### Length

Must be 3 digits  
**Example: 003** = 3m  
**010** = 10ft

### Fiber Type

**V** = OM4, XGLO 550 50/125 Multimode Aqua  
**A** = OS1/OS2, Singlemode Yellow

### LEG Construction (Side A)

**B** = Duplex 2.0mm  
**C** = Uni-Tube Duplex 2.4mm  
 LC BladePatch Only

### LEG Construction (Side B)


**B** = Duplex 2.0mm  
**C** = Uni-Tube Duplex 2.4mm  
 LC BladePatch Only

### Connector Type (Side A)

**A** = LC Multimode  
**B** = LC UPC Singlemode  
**C** = LC APC Singlemode  
**D** = LC BladePatch Multimode  
**E** = LC BladePatch UPC  
 Singlemode RFP Polarity

### Connector Type (Side B)

**A** = LC Multimode  
**B** = LC UPC Singlemode  
**C** = LC APC Singlemode  
**D** = LC BladePatch Multimode  
**E** = LC BladePatch UPC  
 Singlemode RFP Polarity

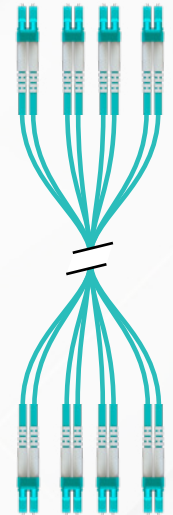

\* Singlemode Only

### Terms and Conditions

- US, Canada and Mexico only.
- PO must be received by 2PM Eastern Time Zone.
- PO must state FIBER NOW.
- Standard freight policy applies.
- Ships within 5 days of booking of PO by Siemon customer service.
- Shipment can be drop-shipped directly to customer location (for US deliveries only).
- Targeted to ship max order quantities within 5 days after customer submits purchase order. Lead time may vary based on availability. Customer Service will advise lead times.

Because we continuously improve our products, Siemon reserves the right to change specifications and availability without prior notice.

**North America**  
 P: (1) 860 945 4200

**Asia Pacific**  
 P: (61) 2 8977 7500

**Latin America**  
 P: (571) 657 1950/51/52

**Europe**  
 P: (44) 0 1932 571771

**China**  
 P: (86) 215385 0303

**India, Middle East & Africa**  
 P: (971) 4 3689743

**Siemon Interconnect Solutions**  
 P: (1) 860 945 4213  
 www.siemon.com/SIS