


<b>CVC5725DNV</b>	4 - 9mm auto iris varifocal lens, black housing
<b>CVC5725DNVW</b>	4 - 9mm auto iris varifocal lens, white housing
<b>CVC5825DNV</b>	2.8 - 12mm auto iris varifocal lens, black housing
<b>CVC5825DNVW</b>	2.8 - 12mm auto iris varifocal lens, white housing
<b>CVC5925DNV</b>	9 - 22mm auto iris varifocal lens, black housing
<b>CVC5925DNVW</b>	9 - 22mm auto iris varifocal lens, white housing

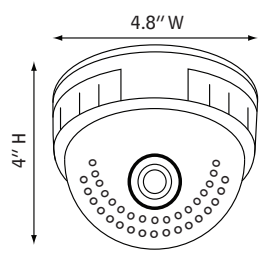

**Features**

- 1/3" Sony Super-HAD II™ CCD
- 3D-DNR (Sense-up) - sharp image under ultra low light level
- Intense-IR function - no saturation image, vivid image
- Defect function - elimination of white spots
- HSBLC (High Light Suppression BLC)
- Privacy zone
- Third-Generation DSP chip
- ICR - removable IR cut filter
- Convenient On-Screen Display (OSD) function controls
- 12VDC / 24VAC dual voltage operation
- 5 year warranty

**Specifications**

Image Sensor .....	1/3" Sony Super-HAD II™ CCD
Resolution.....	600 TV lines
Minimum Illumination.....	0.000006 lux (IR LEDs on)
Total Pixels .....	811 (H) x 508 (V)
Number of IR LEDs .....	33
IR Range .....	Up To 65'
White Balance .....	ATW / AWB / Manual / AWC - Set
Gain Control .....	High / Middle / Low / Off
S/N Ratio .....	52dB (AGC off, Weight on)
Backlight Compensation.....	BLC / HSBLC / Off
Effective Pixels .....	768 (H) x 494 (V)
Electronic Shutter Speed.....	Auto (1/50, 1/60 sec. - 1/100,000 sec.)
OSD.....	Built-In
3 DNR.....	On / Off (0-100 levels adjustable)
D-WDR .....	Indoor / Outdoor / Off
Sharpness .....	0-31' (level adjustable)
Privacy.....	On / Off (8 zones)
Scanning System.....	2:1 interlace
Synchronization .....	Internal / Line-Lock
Motion Detection.....	On / Off (4 zones)
Sense-Up.....	Off / Auto (selectable limit x2 - x256)

Mirror .....	Off / Mirror / V-Rev / Rotate
Freeze .....	On / Off
Day & Night .....	Color / BW / Auto / EXT
Digital Zoom: .....	On (32x) / Off
Blemish Compensation.....	Auto: 128 point / Manual: 4 point
Power Supply .....	12VDC / 24VAC (dual voltage) (power supply not included)
Power Consumption .....	12VDC, 250mA (CDS off) 12VDC, 700mA (CDS on) 24VAC, 100mA (CDS off) 24VAC, 250mA (CDS on)
Operating Temperature/	
Humidity.....	14° F - 122° F / RH 95% max.
Storage Temperature/	
Humidity.....	-4° F - 140° F / RH 95% max.
Dimensions.....	4.8" (W) x 4" (H) x 4.8" (Dia.)
Weight .....	1.2 lbs.

**Optional Accessories**



Speco Technologies is constantly developing and improving products. We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 1/17/12