




See Color In Almost Complete Darkness Without IR LEDs

HTINTB8	2.8 - 12mm auto iris varifocal lens, dark grey housing
HTINTB8W	2.8 - 12mm auto iris varifocal lens, white housing
HTINTB9	5 - 50mm auto iris varifocal lens, dark grey housing
HTINTB9W	5 - 50mm auto iris varifocal lens, white housing
HTINTB10	9 - 22mm auto iris varifocal lens, dark grey housing
HTINTB10W	9 - 22mm auto iris varifocal lens, white housing

Features

- 650 lines of color resolution
- Amplify existing light with no distance limitations
- No problems caused by objects that reflect or absorb IR light sources
- Minimum illumination 0.00002 lux (Intensifier3™ @ 512x)
- 12VDC / 24VAC dual voltage operation
- Full OSD operation
- External controls for zoom & focus
- S/N Ratio more than 52dB (weight on)
- Weather resistant operation
- EZ mount system simplifies installation
- IP66 compliant
- 5 year warranty

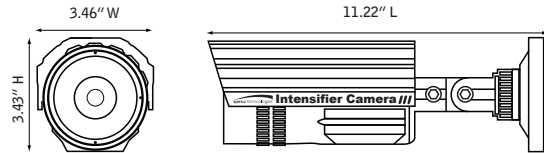


Now with Presets:
 Outdoor, Indoor, Elevator,
 Lobby, Hallway & Dark

Specifications

Image Sensor	1/3" Sony Super-HAD II™ CCD
Resolution.....	650 TV lines
Minimum Illumination.....	CDS off: 0.15 lux CDS on: 0.00002 lux
Total Pixels	811 (H) x 508 (V)
Effective Pixels	768 (H) x 494 (V)
TV System.....	NTSC, PAL
Scanning Frequency.....	15.734kHz (H) & 59.94Hz (V)
Scanning System.....	2:1 interlace
Synchronization	Internal
S/N Ratio	More than 52dB
Video Output.....	CVBS: 1.0Vp-p / 75 Ohm
Electronic Shutter Speed.....	1/60 sec. - 1/120,000 sec.
OSD.....	Available
WDR	On / Off (level adjustable)
Backlight Compensation.....	BLC / HLC / Off
Day & Night	Color / BW / Auto
Gain Control	High / Low / Off
White Balance	ATW / Outdoor / Indoor / Manual / AWC (1,700°K - 11,000°K)

Intensifier3™	Auto / Off (selectable 2x - 512x)
Motion Detection.....	On / Off (8 programmable zones)
Privacy Masking	On / Off (12 programmable zones)
Speco DNR.....	On / Off (level adjustable)
Digital Zoom	On / Off (1x - 16x)
DIS.....	On / Off
Sharpness	On / Off (level adjustable)
Flip / Mirror	On / Off
Power Consumption	12VDC, 250mA / 24VAC, 100mA
Power Supply	12VDC / 24VAC (dual voltage) (power supply not included)
Operating Temperature.....	14° F - 122° F
Storage Temperature.....	- 4° F - 140° F
Dimensions.....	3.46" (W) x 3.43" (H) x 11.22" (L)
Weight	3 lbs.

Optional Accessories

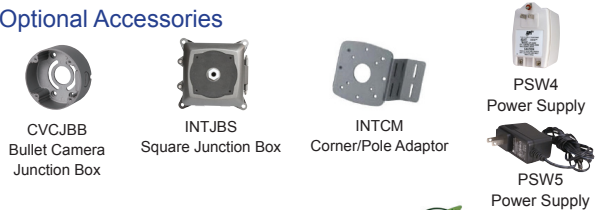

Speco Technologies is constantly developing and improving products.

We reserve the right to modify product design and specifications without notice and without incurring any obligation.



Rev. 2/1/12

For more information contact Speco Technologies

200 New Highway, Amityville, NY 11701 • Toll Free: 1-800-645-5516 • Fax: 631-957-9142 or 631-957-3880
 www.specotech.com