



## USB Type-C™ Adapters, Docking Stations, Hubs and Cables

Complete every connection with Tripp Lite's wide selection of USB-C™ solutions.

60 New Models!



Thunderbolt™ 3 Compatible

Introduction	2
Video Adapters	3
Video Adapter Cables	3
Docking Stations	4-5
Hubs	6
Hub/Adapters	6
Data/Charging Cables & Adapters	7
Network Adapters	8
Charging Solutions	8
Memory Card Readers	8
Drive Solutions	8

## USB-C: Universal Connectivity

The USB Type-C connector (also called USB-C) has become commonplace on electronic devices we use every day, including laptops, tablets, smartphones and even desktop computers. Like previous generations of USB, USB-C connectors can transfer data and power. But they're smaller, reversible, support faster speeds and deliver more power, opening up many new applications. With USB-C, a laptop or tablet can recharge, output ultra-high-definition (UHD) video, connect old or new peripherals, and transfer files at speeds up to 10 Gbps—all through one tiny port. Tripp Lite USB-C solutions make the most of your device's USB-C ports, providing powerful functionality and convenient portability.

## Quick Guide to Key Features

### Power Delivery (PD)

Power delivery (PD) technology passes through up to 60W or 100W (depending on model) from a USB-C charger to a connected laptop or other device. This is especially helpful for devices with only one USB-C port.

### DP Alt Mode Video Output

DisplayPort Alternate Mode (DP Alt Mode) allows a compatible device to output HD (1080p) or UHD (4K) video through a USB-C adapter, adapter cable or docking station to an external television, monitor or projector without installing special software drivers.

### Audio Support

Adapters with HDMI output also deliver digital audio. Some docking stations also include a separate 3.5 mm audio output.

### Thunderbolt 3

Thunderbolt is a signaling standard developed by Apple® and Intel®. Tripp Lite's USB-C solutions are compatible with Thunderbolt 3 ports.\*

\*Applies to devices like computers, tablets or smartphones, not separate displays.

### Extra USB Ports

Adapters, docking stations and hubs with extra USB ports can connect peripherals and other devices, such as printers, external drives and smartphones.

### USB 3.1 Gen 1/Gen 2


USB 3.1 Gen 1 is equivalent to the USB 3.0 standard, supporting data transfer speeds up to 5 Gbps. USB 3.1 Gen 2 supports speeds up to 10 Gbps.

### Gigabit Ethernet (GbE)

A Gigabit Ethernet port provides network connectivity when a faster connection than Wi-Fi is desired, or Wi-Fi is simply unavailable.

#### PERFECT FOR THE LATEST DEVICES WITH USB-C OR THUNDERBOLT 3 PORTS:

MacBook® • MacBook Pro® • iMac® • iMac® Pro • Chromebook™ Pixel™ • HTC® U11/U12+  
Samsung® Galaxy® • Nintendo® Switch® • HP® Spectre® • Dell® XPS® • Lenovo® ThinkPad®

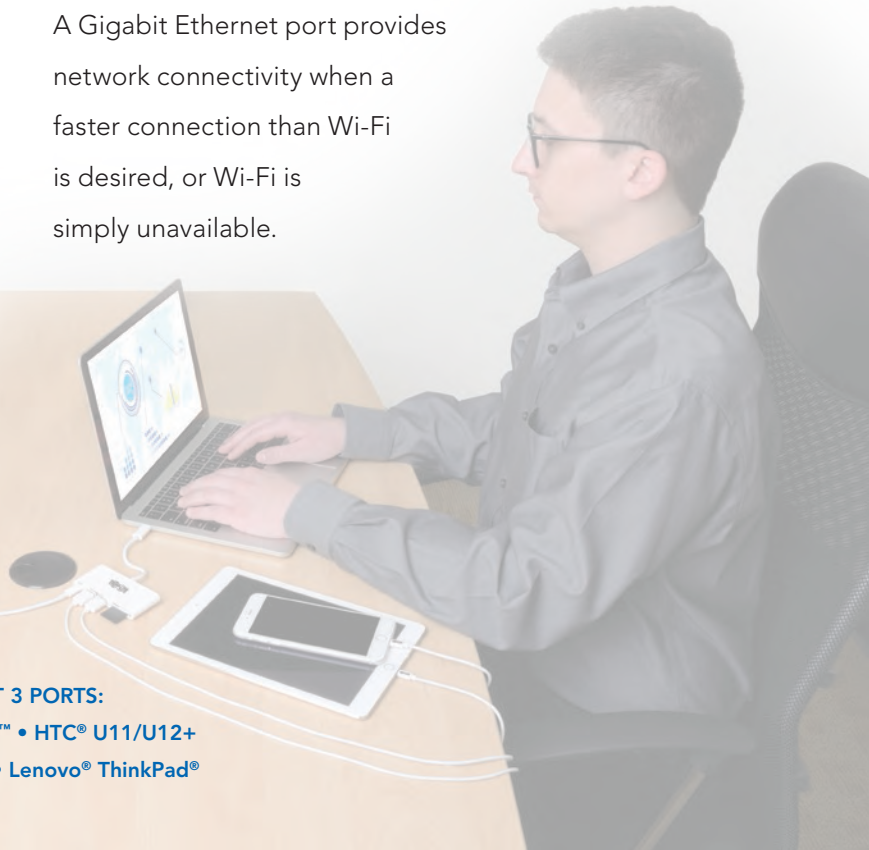

## USB-C Video Adapters & Adapter Cables

- HD (1080p) or UHD (4K) video, with or without USB-C power delivery port
- 3-year limited warranty



Looking for video with additional ports? See pages 4 and 5 for more options.

### SPECIFICATIONS

Model	Description	Cord	Color	Maximum Resolution	DP Alt Mode	Power Delivery
<b>USB-C VIDEO ADAPTERS</b>						
<b>U444-06N-D-C</b>	USB-C Video Adapter, USB-C to DVI (M/F), PD	< 6 in.	White	1920x1080, 60Hz	Yes	60W
<b>U444-06N-DB-C</b>	USB-C Video Adapter, USB-C to DVI (M/F), PD	< 6 in.	Black	1920x1080, 60Hz	Yes	60W
<b>U444-06N-DP-AM</b>	USB-C Video Adapter, USB-C to 4K DisplayPort (M/F)	< 6 in.	White	3840x2160 <sup>(1)</sup> , 60Hz	Yes	No
<b>U444-06N-DP-C</b>	USB-C Video Adapter, USB-C to 4K DisplayPort (M/F), PD	< 6 in.	White	3840x2160, 60Hz	Yes	60W
<b>U444-06N-DP4K6B</b>	USB-C Video Adapter, USB-C to 4K DisplayPort (M/F)	< 6 in.	Black	3840x2160, 60Hz	Yes	No
<b>U444-06N-DP4K6W</b>	USB-C Video Adapter, USB-C to 4K DisplayPort (M/F)	< 6 in.	White	3840x2160, 60Hz	Yes	No
<b>U444-06N-DVI-AM</b>	USB-C Video Adapter, USB-C to DVI (M/F)	< 6 in.	White	1920x1080, 60Hz	Yes	No
<b>U444-06N-DVIBAM</b>	USB-C Video Adapter, USB-C to DVI (M/F)	< 6 in.	Black	1920x1080, 60Hz	Yes	No
<b>U444-06N-H4-C</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F), PD	< 6 in.	White	3840x2160, 30Hz	Yes	60W
<b>U444-06N-H4B-C</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F), PD	< 6 in.	Black	3840x2160, 30Hz	Yes	60W
<b>U444-06N-H4K6WC</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F), PD	< 6 in.	White	3840x2160, 60Hz	Yes	60W
<b>U444-06N-H4K6BC</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F), PD	< 6 in.	Black	3840x2160, 60Hz	Yes	60W
<b>U444-06N-HD</b>	USB-C Video Adapter, USB-C to HDMI (M/F)	< 6 in.	White	2048x1152, 60Hz	No	No
<b>U444-06N-HD-AM</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F)	< 6 in.	White	3840x2160, 30Hz	Yes	No
<b>U444-06N-HD4K6B</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F)	< 6 in.	Black	4096x2160, 60Hz	Yes	No
<b>U444-06N-HD4K6W</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F)	< 6 in.	White	3840x2160, 60Hz	Yes	No
<b>U444-06N-HDB-AM</b>	USB-C Video Adapter, USB-C to 4K HDMI (M/F)	< 6 in.	Black	3840x2160, 30Hz	Yes	No
<b>U444-06N-HDV4K</b>	USB-C Video Adapter, USB-C to 4K HDMI/DVI/VGA (M/F)	< 6 in.	White	3840x2160, 30Hz	Yes	No
<b>U444-06N-HDV4KB</b>	USB-C Video Adapter, USB-C to 4K HDMI/DVI/VGA (M/F)	< 6 in.	Black	3840x2160, 30Hz	Yes	No
<b>U444-06N-HV4K</b>	USB-C Video Adapter, USB-C to 4K HDMI/VGA (M/F)	< 6 in.	White	3840x2160, 30Hz	Yes	No
<b>U444-06N-V-C</b>	USB-C Video Adapter, USB-C to VGA (M/F), PD	< 6 in.	White	1920x1080, 60Hz	Yes	60W
<b>U444-06N-VB-AM</b>	USB-C Video Adapter, USB-C to VGA (M/F)	< 6 in.	Black	1920x1200, 60Hz	Yes	No
<b>U444-06N-VB-C</b>	USB-C Video Adapter, USB-C to VGA (M/F), PD	< 6 in.	Black	1920x1080, 60Hz	Yes	60W
<b>U444-06N-VGA</b>	USB-C Video Adapter, USB-C to VGA (M/F)	< 6 in.	White	2048x1152, 60Hz	No	No
<b>U444-06N-VGA-AM</b>	USB-C Video Adapter, USB-C to VGA (M/F)	< 6 in.	White	1920x1200, 60Hz	Yes	No
<b>USB-C VIDEO ADAPTER CABLES</b>						
<b>U444-003-D</b>	USB-C Video Adapter Cable, USB-C to DVI (M/M)	3 ft.	Black	1920x1080, 60Hz	Yes	No
<b>U444-003-DP</b>	USB-C Video Adapter Cable, USB-C to DisplayPort (M/M)	3 ft.	Black	3840x2160, 60Hz	Yes	No
<b>U444-003-H</b>	USB-C Video Adapter Cable, USB-C to 4K HDMI (M/M)	3 ft.	Black	3840x2160, 30Hz	Yes	No
<b>U444-003-V</b>	USB-C Video Adapter Cable, USB-C to VGA (M/M)	3 ft.	Black	1920x1200, 60Hz	Yes	No
<b>U444-006-D</b>	USB-C Video Adapter Cable, USB-C to DVI (M/M)	6 ft.	Black	1920x1080, 60Hz	Yes	No
<b>U444-006-DP</b>	USB-C Video Adapter Cable, USB-C to DisplayPort (M/M)	6 ft.	Black	3840x2160, 60Hz	Yes	No
<b>U444-006-H</b>	USB-C Video Adapter Cable, USB-C to 4K HDMI (M/M)	6 ft.	Black	3840x2160, 30Hz	Yes	No
<b>U444-006-MDP</b>	USB-C Video Adapter Cable, USB-C to Mini DisplayPort (M/M)	6 ft.	Black	3840x2160, 60Hz	Yes	No
<b>U444-006-V</b>	USB-C Video Adapter Cable, USB-C to VGA (M/M)	6 ft.	Black	1920x1200, 60Hz	Yes	No
<b>U444-010-DP</b>	USB-C Video Adapter Cable, USB-C to DisplayPort (M/M)	10 ft.	Black	3840x2160, 60Hz	Yes	No
<b>U444-016-D</b>	USB-C Video Adapter Cable, USB-C to DVI (M/M)	16 ft.	Black	1920x1080, 60Hz	Yes	No
<b>U444-016-H</b>	USB-C Video Adapter Cable, USB-C to 4K HDMI (M/M)	16 ft.	Black	3840x2160, 30Hz	Yes	No
<b>U444-016-V</b>	USB-C Video Adapter Cable, USB-C to VGA (M/M)	16 ft.	Black	1920x1200, 60Hz	Yes	No

Note: HDMI connections include audio; other connections do not. (1) 3840x2600, 60Hz supported in Single-Stream Transport (SST) mode.






For more information, including complete specifications and the latest updates, go to [www.triplite.com/usb-c](http://www.triplite.com/usb-c).



## USB-C Docking Stations

- DP Alt Mode HD (1080p) or UHD (4K) video, with or without audio
- USB-A port(s) with USB 3.1 Gen 1 (5 Gbps) speeds
- Additional port types, such as Gigabit Ethernet (GbE)
- USB-C power delivery port • 3-year limited warranty

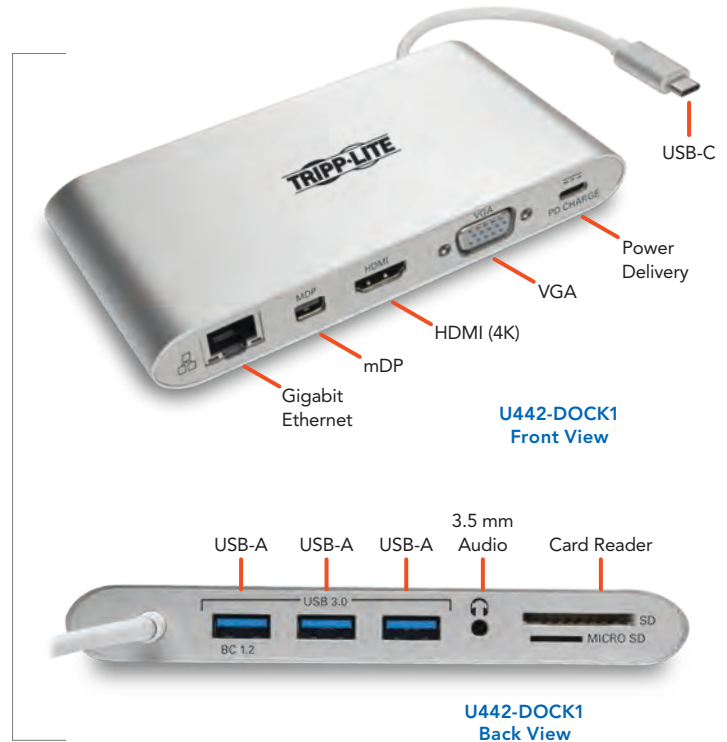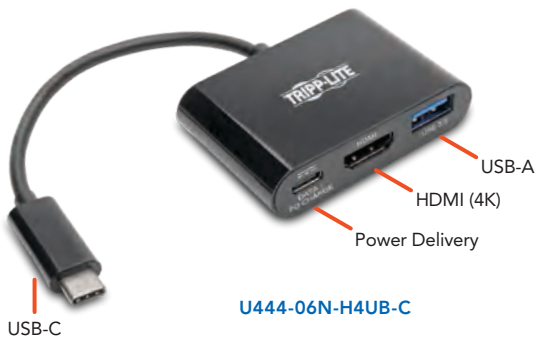

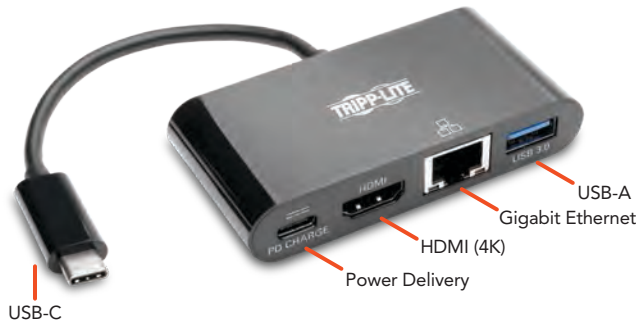

**U444-06N-H4GUBC**



**U442-DOCK12-S**

## SPECIFICATIONS

Model	Description	Cord	Color	Video Type	DP Alt Mode	Maximum Resolution	GbE	PD	USB <sup>(5)</sup>
<b>USB-C DOCKING STATIONS</b>									
<b>U442-DOCK1</b>	USB-C to 4K HDMI, mDP <sup>(1)</sup> , VGA, USB-A, GbE, 3.5 mm Audio, Card Reader <sup>(2)</sup> , PD	< 6 in.	Silver	HDMI, mDP <sup>(1)</sup> , VGA, DP <sup>(1,4)</sup> , DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	3 USB-A
<b>U442-DOCK1-B</b>	USB-C to 4K HDMI, mDP <sup>(1)</sup> , VGA, USB-A, GbE, 3.5 mm Audio, Card Reader <sup>(2)</sup> , PD	< 6 in.	Black	HDMI, mDP <sup>(1)</sup> , VGA, DP <sup>(1,4)</sup> , DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	3 USB-A
<b>NEW U442-DOCK10-S</b>	USB-C to 4K HDMI, USB-A, Micro SD Card Reader, PD	< 6 in.	Silver	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	No	60W	2 USB-A
<b>NEW U442-DOCK11-S</b>	USB-C to 4K HDMI, USB-A, Card Reader <sup>(2)</sup> , PD, Optional External Power <sup>(3)</sup>	< 6 in.	Silver	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	2 USB-A
<b>NEW U442-DOCK12-S</b>	USB-C to 2 x HDMI, VGA, USB-A, PD	< 6 in.	Silver	HDMI, VGA, DVI <sup>(4)</sup>	Yes	1920x1200, 60Hz	No	60W	1 USB-A
<b>NEW U442-DOCK13-S</b>	USB-C to 4K HDMI, USB-A, USB-C, GbE, Optional External Power <sup>(3)</sup>	< 6 in.	Silver	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	No	1 USB-A, 1 USB-C
<b>NEW U442-DOCK2-S</b>	USB-C to 4K HDMI, mDP <sup>(1)</sup> , VGA, USB-A, GbE, 3.5 mm Audio, Card Reader <sup>(2)</sup> , PD	< 6 in.	Silver	HDMI, mDP, VGA, DP <sup>(1,4)</sup> , DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	3 USB-A
<b>NEW U442-DOCK3-B</b>	USB-C to 4K HDMI, VGA, USB-A, USB-C, GbE, Card Reader <sup>(2)</sup> , PD	< 6 in.	Black	HDMI, VGA, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	2 USB-A, 1 USB-C
<b>NEW U442-DOCK4-S</b>	USB-C to 4K HDMI, DP <sup>(1)</sup> , VGA, USB-A, USB-C, GbE, 3.5 mm Audio, PD, 72W External Power Supply Included	12 in.	Silver	HDMI, DP <sup>(1)</sup> , VGA, mDP <sup>(1,4)</sup> , DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	100W	4 USB-A, 1 USB-C
<b>U444-06N-DGU-C</b>	USB-C to DVI, USB-A, GbE, PD	< 6 in.	White	DVI	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-DGUB-C</b>	USB-C to DVI, USB-A, GbE, PD	< 6 in.	Black	DVI	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-DU-C</b>	USB-C to DVI, USB-A, PD	< 6 in.	White	DVI	Yes	1920x1080, 60Hz	No	60W	1 USB-A
<b>U444-06N-DUB-C</b>	USB-C to DVI, USB-A, PD	< 6 in.	Black	DVI	Yes	1920x1080, 60Hz	No	60W	1 USB-A
<b>U444-06N-H4GU-C</b>	USB-C to 4K HDMI, USB-A, GbE, PD	< 6 in.	White	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	1 USB-A
<b>U444-06N-H4GUBC</b>	USB-C to 4K HDMI, USB-A, GbE, PD	< 6 in.	Black	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	1 USB-A
<b>NEW U444-T6N-H4GUBC</b>	USB-C to 4K HDMI, USB-A, GbE, PD	< 6 in.	Black	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	100W	1 USB-A
<b>U444-06N-H4U-C</b>	USB-C to 4K HDMI, USB-A, PD	< 6 in.	White	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	No	60W	1 USB-A
<b>NEW U444-06N-H4UB-C</b>	USB-C to 4K HDMI, USB-A, PD	< 6 in.	Black	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	No	60W	1 USB-A
<b>NEW U444-T6N-H4UBC</b>	USB-C to 4K HDMI, USB-A, PD	< 6 in.	Black	HDMI, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	No	100W	1 USB-A
<b>U444-06N-HGU-C</b>	USB-C to HDMI, USB-A, GbE, PD	< 6 in.	White	HDMI, DVI <sup>(4)</sup>	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-HGUB-C</b>	USB-C to HDMI, USB-A, GbE, PD	< 6 in.	Black	HDMI, DVI <sup>(4)</sup>	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-HU-C</b>	USB-C to HDMI, USB-A, PD	< 6 in.	White	HDMI, DVI <sup>(4)</sup>	Yes	1920x1080, 60Hz	No	60W	1 USB-A
<b>NEW U444-06N-HV4GU</b>	USB-C to 4K HDMI, VGA, USB-A, PD	< 6 in.	White	HDMI, VGA, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	1 USB-A
<b>NEW U444-06N-HV4GUB</b>	USB-C to 4K HDMI, VGA, USB-A, PD	< 6 in.	Black	HDMI, VGA, DVI <sup>(4)</sup>	Yes	3840x2160, 30Hz	Yes	60W	1 USB-A
<b>U444-06N-VGU-C</b>	USB-C to VGA, USB-A, GbE, PD	< 6 in.	White	VGA	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-VGUB-C</b>	USB-C to VGA, USB-A, GbE, PD	< 6 in.	Black	VGA	Yes	1920x1080, 60Hz	Yes	60W	1 USB-A
<b>U444-06N-VU-C</b>	USB-C to VGA, USB-A, PD	< 6 in.	White	VGA	Yes	1920x1080, 60Hz	No	60W	1 USB-A
<b>NEW U444-06N-VUB-C</b>	USB-C to VGA, USB-A, PD	< 6 in.	Black	VGA	Yes	1920x1080, 60Hz	No	60W	1 USB-A
<b>NEW U444-T6N-VUBC</b>	USB-C to VGA, USB-A, PD	< 6 in.	Black	VGA	Yes	1920x1200, 60Hz	No	100W	1 USB-A


**Note:** HDMI connections include audio; other connections do not unless specified. (1) DP=DisplayPort; mDP=Mini DisplayPort. (2) Supports MicroSD/SD/SDHC/SDXC and MMC memory cards. (3) Power inlet connects to optional 5V DC power supply. (4) Requires optional adapter, sold separately. (5) USB 3.1 Gen 1 (5 Gbps). USB-C total does not include PD port.



For more information, including complete specifications and the latest updates, go to [www.trippelite.com/usb-c](http://www.trippelite.com/usb-c).

## USB-C Hubs & Hub/Adapters

- Multiple USB ports with 5 or 10 Gbps speeds and device charging
- With or without Gigabit Ethernet and/or USB-C power delivery port
- 3-year limited warranty

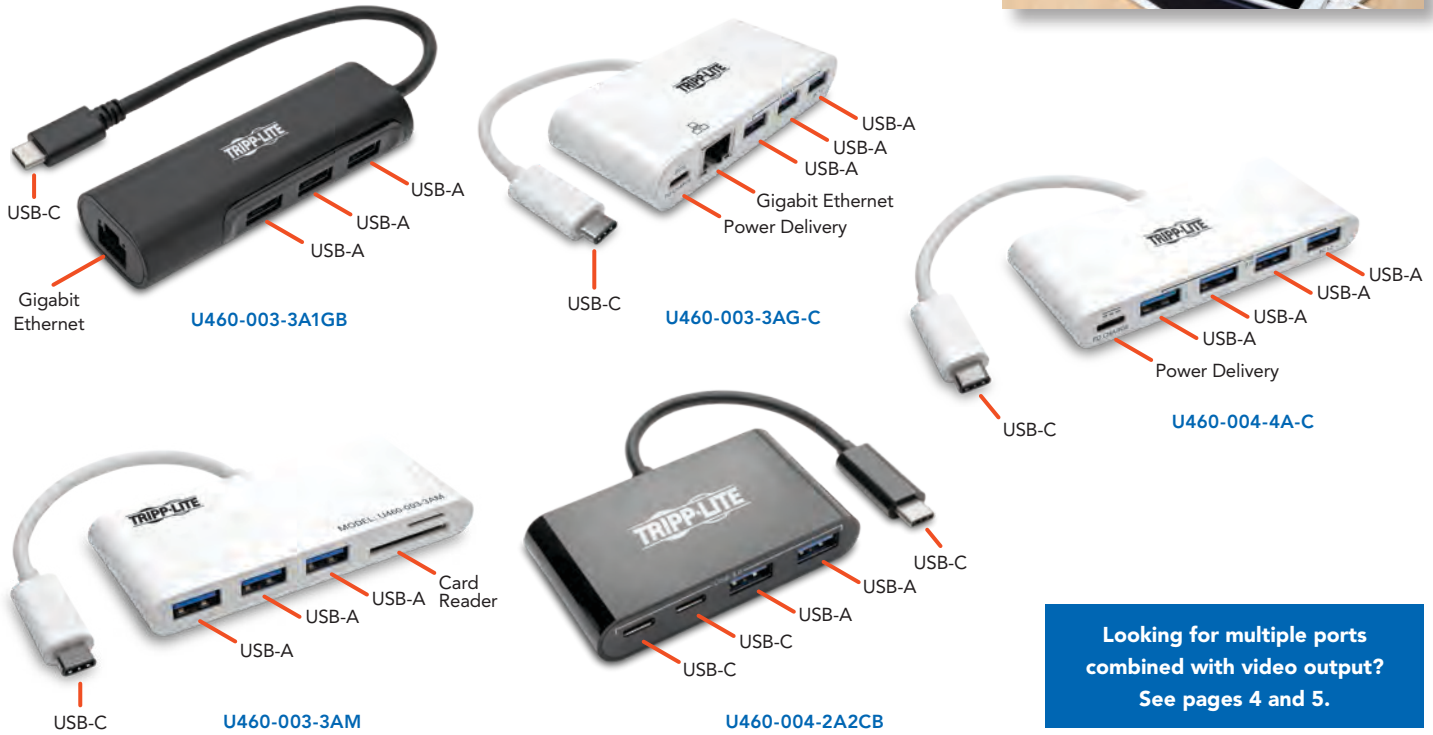

Looking for multiple ports combined with video output? See pages 4 and 5.

### SPECIFICATIONS

Model	Description	Cord	Color	GbE	PD	USB Ports	Max Speed <sup>(3)</sup>
<b>USB-C HUBS</b>							
<b>U460-004-2A2C</b>	4-Port Hub, USB-C to 2xUSB-C and 2xUSB-A	<6 in.	White	No	No	2 USB-A, 2 USB-C	5 Gbps
<b>NEW U460-T04-2A2C-1</b>	4-Port Hub, USB-C to 2xUSB-C and 2xUSB-A, PD	<6 in.	Black	No	100W	2 USB-A, 2 USB-C	5 Gbps
<b>NEW U460-T04-2A2C-2</b>	4-Port Hub, USB-C to 2xUSB-C and 2xUSB-A, PD	<6 in.	Black	No	100W	2 USB-A, 2 USB-C	10 Gbps
<b>U460-004-2A2CB</b>	4-Port Hub, USB-C to 2xUSB-C and 2xUSB-A	<6 in.	Black	No	No	2 USB-A, 2 USB-C	5 Gbps
<b>U460-004-4A</b>	4-Port Hub, USB-C to 4xUSB-A, Optional External Power <sup>(1)</sup>	<6 in.	Silver	No	No	4 USB-A	5 Gbps
<b>U460-004-4A-C</b>	4-Port Hub, USB-C to 4xUSB-A, PD	<6 in.	White	No	60W	4 USB-A	5 Gbps
<b>NEW U460-004-4AB</b>	4-Port Hub, USB-C to 4xUSB-A	<6 in.	Black	No	No	4 USB-A	5 Gbps
<b>U460-004-4AB-C</b>	4-Port Hub, USB-C to 4xUSB-A, PD	<6 in.	Black	No	60W	4 USB-A	5 Gbps
<b>USB-C HUB/ADAPTERS</b>							
<b>U460-002-2AM-C</b>	2-Port Hub/Adapter, USB-C to 2xUSB-A, Card Reader <sup>(2)</sup> , PD	<6 in.	White	No	60W	2 USB-A	5 Gbps
<b>U460-003-3A1G</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, GbE	<6 in.	Silver	Yes	No	3 USB-A	5 Gbps
<b>NEW U460-003-3A1GB</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, GbE	<6 in.	Black	Yes	No	3 USB-A	5 Gbps
<b>U460-003-3AG</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, GbE	<6 in.	White	Yes	No	3 USB-A	5 Gbps
<b>U460-003-3AG-C</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, GbE, PD	<6 in.	White	Yes	60W	3 USB-A	5 Gbps
<b>U460-003-3AGB-C</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, GbE, PD	<6 in.	Black	Yes	60W	3 USB-A	5 Gbps
<b>U460-003-3AM</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, Card Reader <sup>(2)</sup>	<6 in.	White	No	No	3 USB-A	5 Gbps
<b>U460-003-3AMB</b>	3-Port Hub/Adapter, USB-C to 3xUSB-A, Card Reader <sup>(2)</sup>	<6 in.	Black	No	No	3 USB-A	5 Gbps

(1) USB Micro-B port connects to optional power adapter. (2) MicroSD/SD/SDHC/SDXC and MMC. (3) Supports USB 3.1 Gen 1 (5 Gbps) or USB 3.1 Gen 1 (10 Gbps) data transfer speeds.



For more information, including complete specifications and the latest updates, go to [www.triplite.com/usb-c](http://www.triplite.com/usb-c).



## USB-C Data/Charging Cables & Adapters

- Variety of lengths, connectors and data transfer speeds
- Most models also support charging

### SPECIFICATIONS

Model	Description	Cord	Color	USB Standard (Maximum Speed)	Limited Warranty	
<b>USB-C CABLES (USB 2.0)</b>						
	<b>U038-003</b>	USB 2.0 Cable, USB-C to USB-A (M/M)	3 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>NEW</b>	<b>U038-003-CRA</b>	USB 2.0 Cable, Right-Angle USB-C to USB-A (M/M)	3 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
	<b>U038-006</b>	USB 2.0 Cable, USB-C to USB-A (M/M)	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>NEW</b>	<b>U038-006-CRA</b>	USB 2.0 Cable, Right-Angle USB-C to USB-A (M/M)	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>NEW</b>	<b>U038-C13</b>	USB 2.0 Cable, USB-C to USB-A (M/M), USB-IF Certified, 3A Charging <sup>(1)</sup>	13 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
	<b>U040-003-C-5A</b>	USB 2.0 Cable, USB-C to USB-C (M/M), 5A Charging <sup>(2)</sup>	3 ft.	Black	USB 2.0 (480 Mbps)	3 Years
	<b>U040-006</b>	USB 2.0 Cable, USB-B to USB-C (M/M)	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
	<b>U040-006-C</b>	USB 2.0 Cable, USB-C to USB-C (M/M), 3A Charging <sup>(1)</sup>	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
	<b>U040-006-C-5A</b>	USB 2.0 Cable, USB-C to USB-C (M/M), 5A Charging <sup>(2)</sup>	6 ft.	Black	USB 2.0 (480 Mbps)	3 Years
	<b>U040-006-MICRO</b>	USB 2.0 Cable, USB-C to USB Micro-B (M/M)	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
	<b>U040-006-MINI</b>	USB 2.0 Cable, USB-C to USB Mini-B (M/M)	6 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>NEW</b>	<b>U040-C03-C</b>	USB 2.0 Cable, USB-C to USB-C (M/M), USB-IF Certified, 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>NEW</b>	<b>U040-C13-C-5A</b>	USB 2.0 Cable, USB-C to USB-C (M/M), USB-IF Certified, 5A Charging <sup>(2)</sup>	13 ft.	Black	USB 2.0 (480 Mbps)	3 Years
<b>USB-C CABLES (USB 3.1)</b>						
	<b>U420-003</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>NEW</b>	<b>U420-003-5A</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), 5A Charging <sup>(2)</sup>	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
	<b>U420-003-G2</b>	USB 3.1 Gen 2 Cable, USB-C to USB-C (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
	<b>U420-003-G2-5A</b>	USB 3.1 Gen 2 Cable, USB-C to USB-C (M/M), 5A Charging <sup>(2)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>NEW</b>	<b>U420-006</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), 3A Charging <sup>(1)</sup>	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>NEW</b>	<b>U420-006-5A</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), 5A Charging <sup>(2)</sup>	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>NEW</b>	<b>U420-010</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), 3A Charging <sup>(1)</sup>	10 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>NEW</b>	<b>U420-C03-G2-5A</b>	USB 3.1 Gen 2 Cable, USB-C to USB-C (M/M), USB-IF Certified, 5A Charging <sup>(2)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>NEW</b>	<b>U420-C06</b>	USB 3.1 Gen 1 Cable, USB-C to USB-C (M/M), USB-IF Certified, 3A Charging <sup>(1)</sup>	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
	<b>U422-003</b>	USB 3.1 Gen 1 Cable, USB-C to USB 3.0 Type-B (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U422-003-G2</b>	USB 3.1 Gen 2 Cable, USB-C to USB 3.0 Type-B (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	Lifetime
<b>NEW</b>	<b>U422-006</b>	USB 3.1 Gen 1 Cable, USB-C to USB 3.0 Type-B (M/M), 3A Charging <sup>(1)</sup>	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U426-003</b>	USB 3.1 Gen 1 Cable, USB-C to USB 3.0 Micro-B (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U426-003-G2</b>	USB 3.1 Gen 2 Cable, USB-C to USB 3.0 Micro-B (M/M), 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	Lifetime
<b>NEW</b>	<b>U426-006</b>	USB 3.1 Gen 1 Cable, USB-C to USB 3.0 Micro-B (M/M), 3A Charging <sup>(1)</sup>	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U428-003</b>	USB 3.1 Gen 1 Cable, USB-C to USB-A (M/M)	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
<b>NEW</b>	<b>U428-003-CRA</b>	USB 3.1 Gen 1 Cable, Right-Angle USB-C to USB-A (M/M)	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U428-003-G2</b>	USB 3.1 Gen 2 Cable, USB-C to USB-A (M/M)	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	Lifetime
<b>NEW</b>	<b>U428-006</b>	USB 3.1 Gen 1 Cable, USB-C to USB-A (M/M)	6 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
<b>NEW</b>	<b>U428-C03-G2</b>	USB 3.1 Gen 2 Cable, USB-C to USB-A (M/M), USB-IF Certified, 3A Charging <sup>(1)</sup>	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	Lifetime
<b>USB-C ADAPTERS (USB 2.0)</b>						
	<b>U040-000-MIC-F</b>	USB 2.0 Adapter, USB-C to USB Micro-B (M/F)	None	Silver	USB 2.0 (480 Mbps)	Lifetime
	<b>U040-06N-MIC-F</b>	USB 2.0 Adapter, USB-C to USB Micro-B (M/F)	6 in.	Black	USB 2.0 (480 Mbps)	Lifetime
<b>USB-C ADAPTERS (USB 3.0)</b>						
<b>NEW</b>	<b>U329-000</b>	USB 3.0 Adapter, USB-A to USB-C (M/F)	None	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>USB-C ADAPTERS (USB 3.1)</b>						
<b>NEW</b>	<b>U420-000-F-UD</b>	USB 3.1 Gen 2 Adapter, USB-C to Right-Angle USB-C (M/F), 3A Charging <sup>(1)</sup>	None	Black	USB 3.1 Gen 2 (10 Gbps)	Lifetime
	<b>U428-000-F</b>	USB 3.1 Gen 1 Adapter, USB-C to USB-A (M/F), 3A Charging <sup>(1)</sup>	None	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
	<b>U428-06N-F</b>	USB 3.1 Gen 1 Adapter, USB-C to USB-A (M/F), 3A Charging <sup>(1)</sup>	6 in.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
<b>NEW</b>	<b>U428-06N-F-CRA</b>	USB 3.1 Gen 1 Adapter, Right-Angle USB-C to USB-A (M/F), 3A Charging <sup>(1)</sup>	6 in.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
<b>NEW</b>	<b>U428-C6N-F</b>	USB 3.1 Gen 1 Adapter, USB-C to USB-A (M/F), USB-IF Certified, 3A Charging <sup>(1)</sup>	6 in.	Black	USB 3.1 Gen 1 (5 Gbps)	Lifetime
<b>USB-C SERIAL ADAPTER CABLES</b>						
	<b>U209-005-C</b>	USB to Serial Adapter Cable, USB-C to DB9 (M/M)	5 ft.	Black	RS-232 Serial (230 Kbps)	3 Years
<b>NEW</b>	<b>USA-19HS-C</b>	Keyspan® USB to Serial Adapter Cable, USB-C to DB9 (M/M)	3 ft.	Black	RS-232 Serial (230 Kbps)	3 Years

(1) Supports up to 60W (20V x 3A) power delivery (PD) charging. (2) Supports up to 100W (20V x 5A) power delivery (PD) charging.



For more information, including complete specifications and the latest updates, go to [www.trippelite.com/usb-c](http://www.trippelite.com/usb-c).

## USB-C Network Adapters

- Gigabit Ethernet, with or without power delivery port



## USB-C Charging Solutions

- USB-C and USB-A charging ports



### SPECIFICATIONS

Model	Description	Cord	Color	Speed	Limited Warranty
<b>USB-C NETWORK ADAPTERS</b>					
<b>U436-06N-G-C</b>	USB-C Network Adapter, USB-C to RJ45 (M/F), PD	< 6 in.	White	Gigabit Ethernet	3 Years
<b>U436-06N-GB</b>	USB-C Network Adapter, USB-C to RJ45 (M/F)	< 6 in.	Black	Gigabit Ethernet	3 Years
<b>U436-06N-GB-C</b>	USB-C Network Adapter, USB-C to RJ45 (M/F), PD	< 6 in.	Black	Gigabit Ethernet	3 Years
<b>U436-06N-GBW</b>	USB-C Network Adapter, USB-C to RJ45 (M/F)	< 6 in.	White	Gigabit Ethernet	3 Years
<b>USB-C CHARGING SOLUTIONS</b>					
<b>NEW TLP648USBC</b>	Desk-Clamp Surge Protector with USB Charging, 6 AC Outlets, 1080 Joules, 1 x USB-C (15W), 2 x USB-A (2.4A Total), UL 1363/1449	8 ft.	Gray	Not Applicable	Lifetime
<b>U280-004-WS3C1</b>	USB Charger, 1 x USB-C (60W), 3 x USB-A (2.4A Total), UL 60950	4 ft.	Black	Not Applicable	2 Years
<b>NEW U280-C02-C1A1</b>	USB Car Charger, 1 x USB-C (27W), 1 x USB-A (1A), UL 2089	None	White	Not Applicable	2 Years
<b>NEW U280-W02-A1C1</b>	USB Wall Charger, Portable Design with Folding Plug for Travel, 1 x USB-C (39W), 1 x USB-A (2.4A), UL 60950	None	Black	Not Applicable	2 Years
<b>USB-C MEMORY CARD READERS</b>					
<b>U452-000-SD-A</b>	USB-C and USB-A to MicroSD, SD, SDHC, SDXC, MMC	< 6 in.	White	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>U452-003</b>	USB-C to MicroSD/SD/SDHC/SDXC, MMC, CompactFlash (CF)	< 6 in.	Silver	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>USB-C DRIVE SOLUTIONS</b>					
<b>U438-06N-G1-W</b>	Drive Adapter, USB-C to SATA III with UASP for 2.5 in. HDD/SSD	< 6 in.	White	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>U438-06N-G2-W</b>	Drive Adapter, USB-C to SATA III with UASP for 2.5 in. HDD/SSD	< 6 in.	White	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>NEW U438-CF-SATA-5G</b>	Drive Adapter/Card Reader, USB-C to SATA III with UASP for 2.5 in. HDD/SSD, CFast 2.0 Card Reader	< 6 in.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>U439-001</b>	Drive Dock, USB-C to SATA III with UASP for 2.5 or 3.5 in. HDD/SSD	3 ft.	Black	USB 3.1 Gen 1 (5 Gbps)	3 Years
<b>NEW U439-001-CG2</b>	Drive Dock, USB-C to SATA III with UASP for 2.5 or 3.5 in. HDD/SSD	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>NEW U439-002-CG2</b>	Dual-Bay Drive Dock with Cloning, USB-C to 2 x SATA III with UASP for 2.5 or 3.5 in. HDD/SSD, Standalone Drive Duplication	3 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>U457-025-CG2</b>	Drive Enclosure, USB-C to SATA for 2.5 in. HDD/SSD	2 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>U457-025-SATAG2</b>	Premium Drive Enclosure, USB-C to SATA for 2.5 in. HDD/SSD	2 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years
<b>U457-1M2-SATAG2</b>	Drive Enclosure, USB-C to M.2 SATA SSD	2 ft.	Black	USB 3.1 Gen 2 (10 Gbps)	3 Years

 For more information, including complete specifications and the latest updates, go to [www.tripplite.com/usb-c](http://www.tripplite.com/usb-c).

Tripp Lite manufactures 4,000+ IT products.  
See the full selection at [www.tripplite.com](http://www.tripplite.com).

Copyright © 2018 Tripp Lite. USB Type-C™ and USB-C™ are trademarks of USB Implementers Forum. All other trademarks are the sole property of their respective owners. Photos may differ slightly from actual products. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Go to [www.tripplite.com](http://www.tripplite.com) for more information, including complete warranty terms and conditions.



1111 W. 35th Street, Chicago, IL 60609 USA  
773.869.1773 • [www.tripplite.com](http://www.tripplite.com)

