


Powering and Connecting
Your World

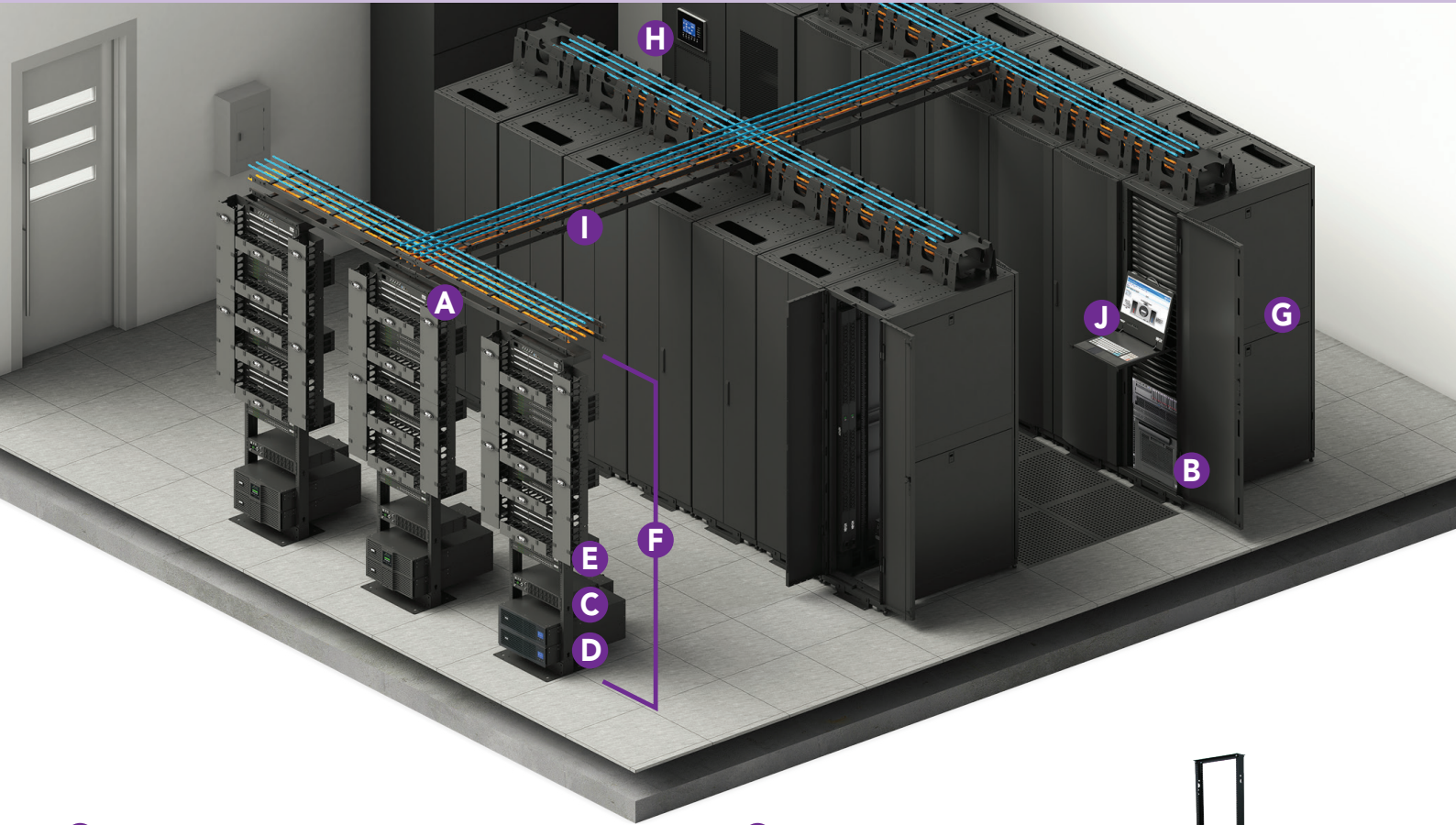

A IP Console Servers

- Provide a secure gateway for in-band and out-of-band remote access to serial- and network-connected devices



B Rack-Mount Cooling

- Keep rack equipment cool with a self-contained air conditioning unit



C Switched PDUs

- Distribute reliable power with horizontally or vertically mounted units
- Individual outlet control via network interface
- Send automated alerts to help prevent accidental overloads, power loss and downtime



D Unity Power Factor UPS

- * Provide 5 or 6kVA of reliable power with internal batteries in just 3U of rack space
- * Best-in-class power density saves more space for revenue-generating equipment



E Patch Panels

- Provide reliable network interconnections in minimal rack space
- Copper or fiber panels, 1U or 2U and up to 48 ports



F Open Frame Racks

- Organise and secure 2U to 58U network rack equipment



G Rack Enclosure Cabinets

- Organise and secure 2U to 48U network rack equipment
- Locking, ventilated steel cabinets



 
H 3-Phase UPS Systems

- Provide up to 210kVA of reliable, efficient power from a centralized, stand-alone unit
- Expandable battery backup and built-in N+1 redundancy



I Cable Managers

- Organise and secure large quantities of network patch cables outside of racks



J KVM Switches

- Control multiple servers from a single console
- Available features include IP remote access, Cat5 cabling, multiuser access, LCD consoles and NIAP-certified security



SEE REVERSE FOR TOP-SELLING
DATA CENTRE SOLUTIONS

TOP-SELLING TRIPP LITE SKUS BY CATEGORY



UPS SYSTEMS

Model
SU5KRT3UG
SU5KRT3UHW
SU5KRT3UX
SU5KRT3UGMB
SU5KRT3UHWMB
SU6KRT3UG
SU6KRT3UHW
SU6KRT3UX
SU6KRT3UGMB
SU6KRT3UHWMB
SU6KRT3UXMB

3-PHASE UPS SYSTEMS

Model
SVT20KX
SVT10KX
SUTX40K
S3M100KX
SVT30KX
SUTX20K
S3M40KX
S3M30KX
S3M120KX
S3M160KX
S3M60KX
SVX60KL
S3M80KX
SVX90KL

RACKS

Model
SR42UB
SR25UB
SR12UB
SR24UB
SR2400
SR18UB
SR48UB
SR2000
SR42UBG
SR42UBEXP
SR25UBSD3
SRX42UB
SRX42UBDPWD
SRX47UBEXP
SRX47UBDPWD
SRX47UB
SRX47UBWD
SRX42UBWD
SRX47UBDP
SRX42UBDP

PDUS

Model
PDU3XMV6G20
PDU3XEVS6G32B
PDU3XEVS6G20
PDU3XEVN6G20
PDUMH20HVATNET
PDUMV32HVNETLX
PDUMV20HVNETLX
PDUMH32HVATNET
PDUMH15HVNET
PDUMH20HV
PDUMH20HVNET
PDUMH15HVATNET
PDUMH20HVAT
PDUMV32HV
PDUMV20HV
PDUNV
PDUH20DV
PDU12IEC
PDUMNV32HV2LX
PDUMNH20HV
PDUMNV20HVLX

COOLING

Model
SRXCOOL12KB
SRXCOOL7KRM

ROBOTIC FIBER PANEL SYSTEM

Model
NRFP-500MM-CP
NRFP-500SM-CP

KVM / CONSOLE

Model
B020-U08-19-K
B020-008-17
B021-000-19
B040-008-19
B030-008-17-IP
B021-000-19-HD2
B070-016-19-IP
B078-101-USB-8
B070-016-19-IP2
B020-U08-19-IP
B020-U16-19-K
B070-008-19-IP
B078-101-USB-1
B020-U16-19-IP
B021-000-17
B040-016-19
B021-000-19-HD
B020-016-17
B070-008-19

POWER CORDS

Model
P018-006
P005-006
P018-010
P018-003
P004-006
P005-010
P005-003
P036-010
P036-006
P004-003
P018-006-ARD
P047-006

CABLES

Model
N222-01K-BL
N201-010-BL
N222-01K-GY
N201-007-BL
N201-003-BL
N201-005-BL
N201-001-BL
N022-01K-BL
N201-025-BL
N224-01K-BL
N201-015-BL
N201-010-BK
N222-01K-WH
N201-007-BK
N286-10GSR-MDLC
N201-006-BL
N238-025-WH
N238-025-BL
N201-015-BK
N201-003-BK
N222-01K-BK
N201-001-BL50BP
N201-005-BK
N001-007-BL
N820-03M
N820-02M
N820-03M-OM4
N370-03M
N820-02M-OM4
N370-02M
N370-01M
N820-01M
N820-05M
N820-10M-OM4
N820-10M
N820-01M-OM4
N820-15M
N820-05M-OM4
N820-07M
N820-15M-OM4
N370-05M
N458-001-62
N370-10M
N820-20M-OM4
N320-03M
N252-048
N252-024
N254-024
N254-048-SH-6A
N052-024
N254-024-SH-6A
N052-048
N48K-15M8L60-B
N252-048-1U

Contact your local Tripp Lite Representative for more information:

Tripp Lite Asia Pacific
+972 54 530 4120 | salesint@tripplite.com



Powering and Connecting
Your World



Alliance Partner