



FULL HD
1080P

ULISSE COMPACT **HD**



The High Definition Generation



HD network cameras provide higher resolution compared to SD cameras, with a number of benefits that enhance efficiency of video surveillance applications.

A higher resolution makes it possible to capture more details of a scene. This means better possibilities for reliable identification. Furthermore HD cameras offer a larger area coverage without resolution loss and the maximum of colour fidelity, which means a better image quality.

The Evolution of Video Surveillance: ULISSE COMPACT **HD**



**THE FIELD PROVEN AND RELIABLE OUTDOOR ULISSE COMPACT PTZ
IS NOW FULL HD AND OFFERS UNRIVALLED FEATURES!**



CAMERA

1080p, 20x at 30 ips, 2.0 MPx, 20x Optical Zoom, up to four independent streams depending on the configuration.



LED ILLUMINATOR

UC-HD features an onboard LED illuminator to deliver clear images of the area even in low light conditions.



WIPER

Thanks to the built-in wiper, the images are always perfectly clear. Wide choice of tanks with washer pump.



HIGH SPEED

Accurate positioning with speed range up to 200°/sec. The UC-HD response to operator commands is immediate.



ONVIF Profile S, H264

Compliance with ONVIF Profile S ensures open architecture for maximum integration with third party systems.



-40°C to +50°C (-40°F/+122°F)

The UC-HD can operate in the most severe environmental conditions and in a wide temperature range, with its sophisticated de-icing functions.

The ULISSE COMPACT HD is an IP66 Full HD network PTZ camera that delivers excellent high-definition picture quality. The Full HD Day/Night camera incorporates a 20x optical zoom lens and is able to accurately identify specific details of a scene, with a wider area coverage.

The flexible operator control of Pan/Tilt/Zoom functions allows the transmission of images over Ethernet using H.264/AVC and MJPEG compression, certified ONVIF, Profile S.

The unit can deliver from 2 to 4 H.264/AVC or MJPEG streams simultaneously. The PTZ configuration and control is made through a standard Web browser. The ULISSE COMPACT HD response to operator commands is immediate.

The camera has Day/Night functionality for high image quality in low light conditions. Moreover the integrated LED illuminator ensures around the clock clear pictures of the monitored area.


Thanks to the built-in wiper, the images are always perfectly clear; a wide choice of tanks with washer pump is available with different capacities and delivery heights.

ULISSE COMPACT HD is designed for continuous duty in any outdoor environment and can withstand difficult external conditions, ensuring high speed and accurate target detection at any time, with zero maintenance.

Thanks to its characteristics of reliability, robustness and accuracy, this positioning unit is the ideal solution for a variety of demanding security applications, including: traffic and highways control, borders, stadiums and industrial surveillance, prisons, military installation and perimeter surveillance.



ULISSE COMPACT **HD**
High **Q**uality, High **S**peed, High **S**ecurity.

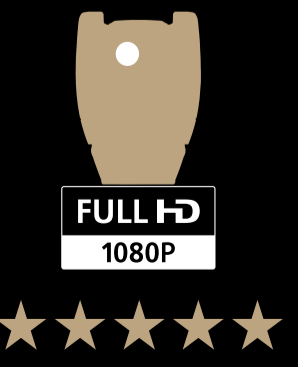



CCTV PRODUCTS
www.videotec.com

HEADQUARTERS ITALY

VIDEOTEC S.p.A.

Via Friuli, 6 - I-36015 Schio (VI) Italy
Tel. +39 0445 697411 - Fax +39 0445 697414
Email: info@videotec.com

FRANCE

VIDEOTEC FRANCE S.à.r.l.

Voie du Futur - Zac des Portes - 27100 Val de Reuil, France
Tel. +33 2 32094900 - Fax +33 2 32094901
Email: info.fr@videotec.com

AMERICAS

VIDEOTEC SECURITY, Inc.

Gateway Industrial Park - 35, Gateway Drive - Suite 100
Plattsburgh, NY 12901 - U.S.A.
Tel. +1 518 825 0020 - Fax +1 518 825 0022
Email: info.usa@videotec.com - www.videotec.us

ASIA PACIFIC

VIDEOTEC (HK) Ltd

Flat 8, 19/F., On Dak Industrial Building, No. 2-6 Wah Sing Street,
Kwai Chung, New Territories, Hong Kong
Tel. +852 2333 0601 - Fax +852 2311 0026
Email: info.hk@videotec.com



Made in Italy, since 1986