



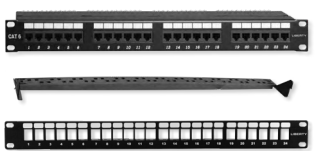


Connectivity							
Faceplates & Back Boxes	Features	Vendor Item #	Anixter Part #	Product Description	Country	Colour	
 <p><b>FR</b></p> <ul style="list-style-type: none"> <li>UL 1863 Safety Listed</li> <li>UL 94 V.0 Fire Retardant Plastic</li> <li>Has ID Window/Label (ID models)</li> </ul> <p><b>NORD</b></p> <ul style="list-style-type: none"> <li>Compatible with all Liberty series of Jacks/Inserts/Couplers</li> </ul> <p><b>UK</b></p>		LFFP1WH	10256998	Faceplate 1 position 80X80 mm	France	White <input type="radio"/>	
		LFB1WHID	10256996	Bezel 1port 45X45 mm ID	France	White <input type="radio"/>	
		LFB2WHID	10256997	Bezel 2port 45X45 mm ID	France	White <input type="radio"/>	
		LFBBSGWH	10256999	Back Box 80X80 mm	France	White <input type="radio"/>	
		LNFP1WHID	10256993	Faceplate 1port ID 84X84 mm	Nordic	White <input type="radio"/>	
		LNFP2WHID	10256994	Faceplate 2port ID 84X84 mm	Nordic	White <input type="radio"/>	
		LUKFP1WHID	10256991	Faceplate 1port ID 86X86 mm	UK	White <input type="radio"/>	
		LUKFP2WHID	10256990	Faceplate 2port ID 86X86 mm	UK	White <input type="radio"/>	
		LUKBBSGWH	10256992	Back Box 86X86 mm	UK	White <input type="radio"/>	
Keystone Jack	Features	Vendor Item #	Anixter Part #	Product Description	Spec	Colour	
 <p>Keystone Jacks</p> <ul style="list-style-type: none"> <li>ISO/IEC 11801-1 Category 6</li> <li>Compatible with Liberty Faceplates / Surface Mount Boxes / Modular Patch Panels.</li> </ul> <p>Coupler</p> <ul style="list-style-type: none"> <li>Compatible with Liberty Faceplates, Surface Mount Boxes and Modular Patch Panels</li> </ul>		LJK6WHHD	10257005	Cat 6 Jack White HD 180	Cat 6	White <input type="radio"/>	
		LJK6BKHD	10285493	Cat 6 Jack Black HD 180	Cat 6	Black <input type="radio"/>	
		LJK6CPLRWH	10257011	Cat 6 White Keystone Coupler	Cat 6	White <input type="radio"/>	
		LJK6CPLRBK	10257010	Cat 6 Black Keystone Coupler	Cat 6	Black <input type="radio"/>	
Tool	Features	Vendor Item #	Anixter Part #	Product Description	Spec	Colour	
 <ul style="list-style-type: none"> <li>One Punch HD Jack Termination Tool</li> <li>Terminates all 8 wires with one motion</li> <li>Compatible with all Liberty HD series jacks</li> </ul>		LJKCRIMPHD	10257009	Liberty HD Jack Crimp Tool	180	Yellow <input type="radio"/>	
Surface Mount Box	Features	Vendor Item #	Anixter Part #	Product Description	Ports	Colour	
 <ul style="list-style-type: none"> <li>UL 1863 Safety Listed</li> <li>UL 94V.0 fire retardant plastic</li> <li>ANSI/TIA 606 Compliant</li> </ul>		LSMB1WH	10257000	Surface Mount Box 1 port	1	White <input type="radio"/>	
		LSMB2WH	10257001	Surface Mount Box 2 port	2	White <input type="radio"/>	
		LSMB4WH	10257002	Surface Mount Box 4 port	4	White <input type="radio"/>	
Patch Panel	Features	Vendor Item #	Anixter Part #	Product Description	Ports	Spec	
 <ul style="list-style-type: none"> <li>For 19" Relay Rack &amp; Wall mount brackets</li> <li>Includes Rear Cable Mgmt Bar &amp; Rack mount screws</li> <li>Fully Loaded - ISO 11801-1 CAT 6</li> </ul> <ul style="list-style-type: none"> <li>For 19" Relay Rack &amp; Wall mount brackets</li> <li>Modular Option - Compatible with all Liberty Series of Jacks/Inserts/Couplers</li> <li>Includes Rear Cable Mgmt Bar &amp; Rack mount screws</li> </ul>		LPP624P	10257014	Patch Panel Cat 6 24 port	24	CAT6	
		LPPMOD24P	10257017	Modular Patch Panel 24 ports	24	Modular	


## Category Cable

Cat 6	Features	Vendor Item #	Anixter Part #	Product Description	CPR-UKCA	Length	Colour
 <ul style="list-style-type: none"> <li>• IEC 61156-5 Cat 6 (550 MHz)</li> <li>• ISO/IEC 11801-1</li> <li>• LSZH CPR Euroclass Cca (L6UZC)</li> <li>• LSZH CPR Euroclass Dca (L6UZD)</li> <li>• Made in the EU</li> </ul>							
		L6UZCWH1BX	10257024	23-4p UTP LSZH Cat 6 Cca	Cca	305 M	White ○
		L6UZDWH1BX	10257023	23-4p UTP LSZH Cat 6 Dca	Dca	305 M	White ○

## Patch Cords

Cat 6	Features	Vendor Item #	Anixter Part #	Product Description	Connector	Length	Colour
 <ul style="list-style-type: none"> <li>• Cat 6 UTP LSZH</li> <li>• For ISO/IEC 11801-1 Class E UTP &amp; PoE applications</li> <li>• Offered in Multiple Lengths</li> </ul>							
		LPC6UZ0.3MWH	10257669	Cat 6E PATCH CORD LSZH	M-M	0.3 M	White ○
		LPC6UZ0.5MWH	10257687	Cat 6E PATCH CORD LSZH	M-M	0.5 M	White ○
		LPC6UZ01MWH	10257689	Cat 6E PATCH CORD LSZH	M-M	1.0 M	White ○
		LPC6UZ03MWH	10257691	Cat 6E PATCH CORD LSZH	M-M	3.0 M	White ○
		LPC6UZ05MWH	10257693	Cat 6E PATCH CORD LSZH	M-M	5.0 M	White ○

## Low Voltage Cable

Multi Conductor	Features	Vendor Item #	Anixter Part #	Product Description	CPR-UKCA	Length	Colour
 <p>Cables certified to:</p> <ul style="list-style-type: none"> <li>• EN50399, EN60332-1-2, EN60754-2, EN60134-2</li> <li>• Euro Class Cca, UKCA</li> <li>• EU CE Label</li> </ul>							
		L1908-703C-091M	10315129	<b>8 Core Alarm Cable</b> 16-2C STR BC OAS	Cca	100 M	Grey ●
		L1602-110C-091M	10315135	<b>Speaker and Access Control Lock Cable</b> 16-2C STR BC OAS	Cca	100 M	Grey ●
		L1802-110C-091M	10315136	<b>Speaker and Access Control Lock Cable</b> 18-2C STR BC OAS	Cca	100 M	Grey ●
		L2202-224C-091M	10315137	<b>2 x Pair Data Bus RS422/485 and OSDP Reader Cable</b> 22-2PR STR TC EPS & Drn	Cca	100 M	Grey ●
		L2204-214C-091M	10315139	<b>4 Pair Data Cable Used In Wiegand Access Control Reader</b> 22-4PR STR TC OAS & Drn	Cca	100 M	Grey ●