


PRODUCT SOLUTIONS BRIEF HIKVISION

HEALTHCARE FACILITY RISK MANAGEMENT

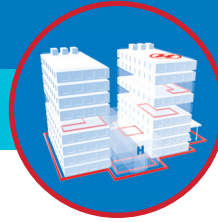

Through our strong global partnerships and alliances with manufacturers such as Hikvision, we are able to present you with the following offering to meet your specific healthcare requirements.

PanoVu Outdoor Network Dome Camera (DS-2CD6924F-IS)

Hikvision's DS-2CD6924F-IS PanoVu Outdoor Network Dome Camera Series offers a full 180-degree view stitched together from four 2 MP cameras. Features include four 4 mm lenses with 1/2.8" progressive scan CMOS sensors for a total of 4096x1800 resolution at 30 fps.



Hikvision's PanoVu Network Dome Cameras offer 4096x1800 resolution at 30 fps in panorama mode.

CHALLENGE SOLVERS

- H.265+ ensures high video compression to save bandwidth and storage costs.
- Four IR LEDs provide a 66 ft. (20 m) range.
- Hikvision's DarkFighter Series of ultra-lowlight smart cameras are able to capture high-quality color images in dim light environments.

THE ANIXTER APPROACH

- **Property Perimeter**
Determine vulnerability areas around the property edge to deter external threats.
- **Reception and Registration Area**
Control the flow of visitors and patients to the facility and validate various levels of staff authorization.
- **Specialty Units**
Protect patients and comply with privacy regulations with attention to complex specialty units.
- **Emergency Room**
Improve staff safety and care through effective management of high-stress and high-traffic emergency settings.
- **Pharmaceutical Assets**
Achieve regulatory compliance and loss prevention by monitoring access and intrusion to pharmaceutical zones.
- **Biomedical and Diagnostics**
Protect valuable equipment and potentially harmful materials in biomedical and diagnostic areas.



WHAT WE HEAR

Healthcare stakeholders are dealing with a variety of challenges:



Creating **SAFE** environments for patients and staff



Preventing **THEFT** of medicine and radiological materials



Achieving **REGULATORY COMPLIANCE**



Preventing **CYBER THREATS** to patient records



Limiting physical building and network **ACCESSIBILITY**

THE HIKVISION SOLUTION

FIELD OF VIEW

Horizontal: 180°
Vertical: 86.7°

ANALYTICS

6-behavior analyses
Audio exception detection
Face detection

MOUNT OPTIONS

Wall
Pendant
Vertical pole
Corner

anixter.com/shophikvision

**Infrastructure
as a Platform**
by Anixter

Infrastructure as a Platform by Anixter provides a practical, configurable and integrated approach to deploy physical security infrastructure into your healthcare environment.

CONFIGURE

We help you discover and map your specific needs to the best solution.

- Monitoring software
- Environmental sensors
- Video analytics software

BUNDLE

Your validated, preconfigured solutions are packaged and site ready.

- Installation kits
- Surface-mount kits
- Software controls

DEPLOY


Controlled, repeatable solutions are delivered on time and under budget.

- Custom packaging and labeling
- Time-sensitive delivery options
- Staged project shipping
- Tailored last-mile delivery

HIKVISION PANOBU OUTDOOR NETWORK DOME CAMERA FEATURES

PROVIDES A SAFE CARE FACILITY

- IP67-rated
- 4096x1800 at 30 fps in panorama mode
- Six behavior analyses, audio exception detection and face detection
- Audio and alarm input and output options

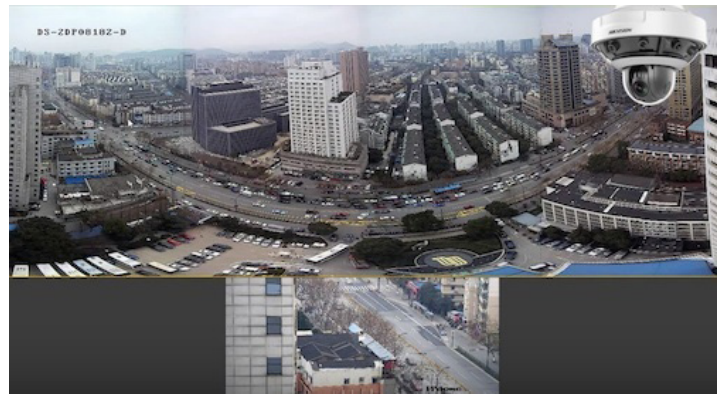

The PanoVu Outdoor Network Dome Camera Series offers a full 180-degree view stitched together from four 2 MP cameras.

 **FOR MORE DETAILS VISIT [ANIXTER.COM/SHOPHIKVISION](https://www.anixter.com/shop/hikvision)**

About Anixter: [anixter.com/aboutus](https://www.anixter.com/aboutus)

Legal Statement: [anixter.com/legalstatement](https://www.anixter.com/legalstatement)

At Anixter, we enable the connected world. By building, connecting, protecting and powering valuable assets and critical infrastructures, we help to sustain and grow businesses and communities worldwide. We accomplish this by offering full-line solutions, technical intelligence, supply chain expertise and an unmatched global distribution network.

1.800.ANIXTER | [anixter.com](https://www.anixter.com)



18T0451GL © 2018 Anixter Inc.

Products. Technology. Services. Delivered Globally.