


PRODUCT SOLUTIONS BRIEF
TRIPP LITE

HEALTHCARE FACILITY POWER OPTIMIZATION

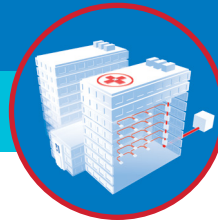

PS-415-HG-OEM power strips

Through our strong global partnerships and alliances with manufacturers such as Tripp Lite, we are able to present you with the following offering to meet your specific healthcare requirements.

Medical-Grade Power Strips

Tripp Lite's Medical-Grade Power Strips supply power to movable plug-connected components mounted to a rack, table or pedestal in operating rooms, patient-care vicinities, therapy rooms, imaging environments and administrative areas. Compliant with UL 1363A specifications, this 120 V, 50/60 Hz power strip features a NEMA 5-15P-HG hospital-grade plug and four NEMA 5-15R-HG hospital-grade outlets.

CHALLENGE SOLVERS

- Two built-in resettable 15 A circuit breakers control power to all outlets and protect the power strip against overloads. Switchless design prevents the unit from being accidentally shut off. The 15-ft. power cord provides ample reach to the power source.
- Mounting tabs and flanges let you install the PS-415-HG-OEM on a wide variety of surfaces, such as IV poles, mobile carts, crash carts and mobile medical workstations. The all-metal housing ensures safety and is guaranteed to last a long time in demanding environments.
- Power strips offer flexibility of power distribution anywhere in any medical facility and are ideal for use in operating rooms, patient-care vicinities, therapy rooms, imaging environments and administrative areas.
- Built-in mounting tabs and flanges make the PS-415-HG-OEM easy to install on a variety of surfaces, which means the power strip is ready to use right out of the box.
- Exclusive, patented anti-microbial coating - 99.9% effective in inhibiting bacteria and viruses.

THE ANIXTER APPROACH

- **Conditioned Power**
 Maintain continuous voltage and protect against surges with conditioning technology.

THE TRIPP LITE SOLUTION

APPLICATION	STANDARD COMPLIANCE	ACCESSORIES
Patient care rooms Mobile applications Administrative areas	UL 60601-1 UL 1363 UL 1363A UL 1449	Mounting clamps Hospital-grade power cords Medical-grade UPS

anixter.com/shoptriplite



WHAT WE HEAR

Healthcare stakeholders are dealing with a variety of challenges:



Meeting **ENERGY EFFICIENT** goals



PREVENTING accidental outages



Ensuring an **ALWAYS ON** environment



Reducing **UTILITY COSTS**



Restrictions of **LEGACY ELECTRICAL INFRASTRUCTURE**

Infrastructure as a Platform
 by Anixter

Infrastructure as a Platform by Anixter provides a practical, configurable and integrated approach to retrofitting or building a critical power chain in your healthcare environment.

CONFIGURE

We help you discover and map your specific needs to the best solution.

- Number of outlets
- Cord length
- Outlet orientation
- Voltage compatibility

BUNDLE

Your validated, preconfigured solutions are packaged and site ready.

- UPS systems
- Outlet covers
- Mounting clamps
- Power cords

DEPLOY

Controlled, repeatable solutions are delivered on time and under budget.

- Custom packaging and labeling
- Time-sensitive delivery options
- Staged project shipping
- Tailored last-mile delivery

TRIPP LITE MEDICAL-GRADE POWER STRIP FEATURES

✓ PREVENTS ACCIDENTAL OUTAGES

- Rugged, all-metal housing for long life in demanding environments
- Dual, resettable built-in 15 A circuit breakers to protect against dangerous overloads
- Switchless design to prevent accidental shut-off
- Four locking outlet covers that require a tool to remove

✓ ENSURES AN ALWAYS-ON ENVIRONMENT

- Four NEMA 5-15R-HG hospital-grade outlets that provide consistent power
- Built-in mounting tabs and flanges that make the PS-415-HG-OEM easy to install
- For use on IV poles, mobile carts, crash carts and mobile workstations
- 120 V, 50/60 Hz power strip that complies with UL 1363A specifications
- Circuit breaker that resets itself once fault threat is gone



PS-615-HG-OEM power strips

> FOR MORE DETAILS VISIT [ANIXTER.COM/SHOPTRIPLITE](https://www.anixter.com/shoptriplite)

About Anixter: [anixter.com/aboutus](https://www.anixter.com/aboutus)
Legal Statement: [anixter.com/legalstatement](https://www.anixter.com/legalstatement)

At Anixter, we enable the connected world. By building, connecting, protecting and powering valuable assets and critical infrastructures, we help to sustain and grow businesses and communities worldwide. We accomplish this by offering full-line solutions, technical intelligence, supply chain expertise and an unmatched global distribution network.

1.800.ANIXTER | [anixter.com](https://www.anixter.com)



18T0454NA © 2018 Anixter Inc.

Products. Technology. Services. Delivered Globally.