


## UTG SOLUTIONS BRIEF

# AXIS COMMUNICATIONS

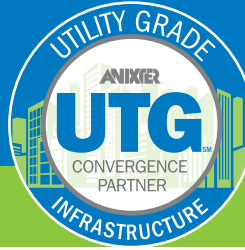

## VIDEO SURVEILLANCE

The Utility Grade INFRASTRUCTURE (UTG<sup>SM</sup>) program has been developed alongside world-class global Technology Alliance Partners<sup>SM</sup>. These UTG-recommended components from Axis Communications enable you to support the rapid evolution of technology in today's building environments.

### PRODUCT OVERVIEW

UTG solutions from Axis Communications are UL Verified for extended distance when pairing Axis Network Cameras with UTG-rated cable infrastructure as part of a common infrastructure platform. The below Axis Communications Network Camera recommendations complement a full UTG solution.

As part of the UTG connected architecture the following convergence zones identify the most common environments video surveillance will be utilized within and around the building.

### INTRA-BUILDING | CONNECTED CEILING | BUILDING-EDGE | EXTENDED-EDGE

### VERIFICATION AND PERFORMANCE

- Extended distance performance of Axis Network Cameras beyond Anixter UTG10 and UTG20 Framework 1.0.
- Total channel length of 185 meters which includes 170 meters of horizontal cable and up to 15 meters of patch cords.
- UTG10 and UTG20 cable utilizing one 10/100 Mb 802.3at compliant switch capable of sourcing 30W maximum for Type1/Type 2 PoE application (see product part number list).

### FEATURES AND BENEFITS

- 4K UHD with Type 2 PoE 30 Watts at 185m/606 ft.
- 85% longer reach over standards
- Full color video in near darkness with Axis Lightfinder technology
- Lower bandwidth and storage requirements with Axis Zipstream technology
- Native IoT support with MQTT protocol
- Cyber Secure with AXIS Device Manager
- Accurate real-time occupancy levels with AXIS Occupancy Estimator
- Guaranteed performance and interoperability
- Maximize your infrastructure investment (ROI)

Anixter Part #	Axis Part #	Description
***Axis Network Cameras UL Verified up to at least 185 m***		
9957062	AXIS M1134	AXIS M1134, HDTV 720p, indoor, box camera
9957047	AXIS M1135	AXIS M1135, HDTV 1080p, indoor, box camera
968927	AXIS M3057-PLVE	AXIS M3057-PLVE, 6MP, 360/180, outdoor, dome camera
970642	AXIS M3058-PLVE	AXIS M3058-PLVE, 12MP, 360/180, outdoor, dome camera
10001487	AXIS M3064-V	AXIS M3064-V, HDTV 720p, indoor, dome camera
10001488	AXIS M3065-V	AXIS M3065-V, HDTV 1080p, indoor, dome camera
10001490	AXIS M3066-V	AXIS M3066-V, 4MP, indoor, dome camera
10001489	AXIS M3075-V	AXIS M3075-V, HDTV 1080p, indoor, dome camera
9950236	AXIS M3205-LVE	AXIS M3205-LVE, HDTV 1080p, outdoor, dome camera
9952491	AXIS M3206-LVE	AXIS M3206-LVE, 4MP, outdoor, dome camera
9798358	AXIS P1375	AXIS P1375, HDTV 1080p, indoor, box camera
9790455	AXIS P1375-E	AXIS P1375-E, HDTV 1080p, outdoor, box camera
9992224	AXIS P1377	AXIS P1377, 5MP, indoor, box camera
9992230	AXIS P1378	AXIS P1378, 4K resolution, indoor, box camera
992037	AXIS P1445-LE	AXIS P1445-LE, HDTV 1080p, outdoor, bullet camera
960551	AXIS P1447-LE	AXIS P1447-LE, 5MP, outdoor, bullet camera
960552	AXIS P1448-LE	AXIS P1448-LE, 4K resolution, outdoor, bullet camera
902624	AXIS P3227-LV	AXIS P3227-LV, 5MP, indoor, dome camera
902669	AXIS P3227-LVE	AXIS P3227-LVE, 5MP, outdoor, dome camera
902823	AXIS P3228-LV	AXIS P3228-LV, 4K resolution, indoor, dome camera
902827	AXIS P3228-LVE	AXIS P3228-LVE, 4K resolution, outdoor, dome camera
9868554	AXIS P3245-LV	AXIS P3245-LV, HDTV 1080p, indoor, dome camera
9867945	AXIS P3245-LVE	AXIS P3245-LVE, HDTV 1080p, outdoor, dome camera
9867942	AXIS P3245-V	AXIS P3245-V, HDTV 1080p, indoor, dome camera

Anixter Part #	Axis Part #	Description
***Axis Network Cameras UL Verified up to at least 185 m***		
9868552	AXIS P3245-VE	AXIS P3245-VE, HDTV 1080p, outdoor, dome camera
1009332	AXIS P3807-PVE	AXIS P3807-PVE, 8MP, outdoor, multisensor camera
10036551	AXIS P5654-E 60HZ	AXIS P5654-E 60HZ AXIS P5654-E, HDTV 720p, outdoor, PTZ camera
9842655	AXIS P5655-E 60HZ	AXIS P5655-E, HDTV 1080p, outdoor, PTZ camera
963589	AXIS Q1645	AXIS Q1645, HDTV 1080p, indoor, box camera
903150	AXIS Q1647	AXIS Q1647, 5MP, indoor, box camera
9842514	AXIS Q1700-LE	AXIS Q1700, 2MP, outdoor, license plate capture camera
1022879	AXIS Q1785-LE	AXIS Q1785-LE, HDTV 1080p, outdoor, bullet camera
1022880	AXIS Q1786-LE	AXIS Q1786-LE, 4MP, outdoor, bullet camera
961687	AXIS Q3515-LV 9MM	AXIS Q3515-LV, HDTV 1080p, indoor, dome camera
961965	AXIS Q3515-LVE 9MM	AXIS Q3515-LVE, HDTV 1080p, outdoor, dome camera
918950	AXIS Q3517-LV	AXIS Q3517-LV, 5MP, indoor, dome camera
918951	AXIS Q3517-LVE	AXIS Q3517-LVE, 5MP, outdoor, dome camera
992038	AXIS Q3518-LVE	AXIS Q3518-LVE, 4K resolution, outdoor, dome camera
1035776	AXIS Q3527-LVE	AXIS Q3527-LVE, 5MP, outdoor, dome camera
9880177	AXIS Q6074 60HZ	AXIS Q6074, HDTV 1080p, indoor, PTZ camera
9872403	AXIS Q6075 60HZ	AXIS Q6075, HDTV 1080p, indoor, PTZ camera
10012804	AXIS Q9216-SLV	AXIS Q9216-SLV, 4MP, indoor, stainless steel corner mount camera
Anixter Part #	Axis Part #	Description
***Axis Network Cameras UL Verified up to at least 175 m***		
10061042	AXIS P3715-PLVE	AXIS P3715-PLVE, 2X2 MP, 360 IR, multidirectional dome camera
1004923	AXIS P3717-PLE	AXIS P3717-PLE, 8MP, 360 IR, outdoor, multidirectional dome camera
9816470	AXIS P3719-PLE	AXIS P3719-PLE, 15MP, 360 IR, outdoor, multidirectional dome camera

**FOR MORE DETAILS, VISIT [ANIXTER.COM/UTG](https://www.anixter.com/UTG)**

**About Anixter:** [anixter.com/aboutus](https://www.anixter.com/aboutus)  
**Legal Statement:** [anixter.com/legalstatement](https://www.anixter.com/legalstatement)

At Anixter, we enable the connected world. By building, connecting, powering and protecting valuable assets and critical infrastructures, we help to sustain and grow businesses and communities worldwide. We accomplish this by offering full-line solutions, technical intelligence, supply chain expertise and an unmatched global distribution network.

1.800.ANIXTER | [anixter.com](https://www.anixter.com)

19X0225GL © 2021 Anixter Inc. 01/21



**Build. Connect. Power. Protect. Services. Worldwide.**