



INSTA-REEL

Reduce labor costs and the risk of injury to your staff by using the INSTA-REEL by Anixter.

The INSTA-REEL consists of a standard wooden reel that has oversized flanges attached to both sides and becomes a payout stand when chocked in place.


The inner reel spins independently of the outer flanges, creating a reel with a built-in payout stand. Just roll the INSTA-REEL into place, chock the flanges and start pulling your cable.

INSTA-REELS are pre-loaded with the cable of your choice and delivered completely assembled. After use, the INSTA-REEL is returned to Anixter, making it an eco-friendly as well as cost-efficient product.

By paralleling and phase taping multiple conductors on the same reel, you can further reduce your labor costs and time. Additionally, pulling eyes can be installed on single-conductor cables.

Features and benefits:


- Easily rolls into your pull position
- Turns easily with independently spinning outer flanges
- Reduces the time and injury risk of locating and setting up jack stands
- Can be pulled directly from the shipping cradle if desired
- Is returnable, which eliminates disposal costs and lessens the environmental impact of standard wooden reels
- Gives the option of multiple conductors being paralleled onto the reel
- Allows for pulling eyes to be installed on single-conductor cables

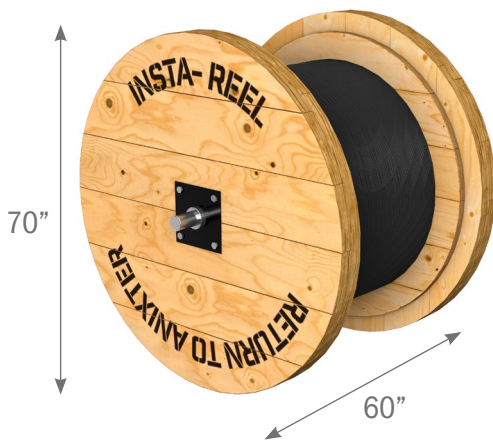

14RR-INSTA-70-60W

Approx. Empty Weight – 965 lbs


Our 70" high by 60" wide reel accommodates long lengths of medium voltage cables and large Industrial cables. Its large drum allows for the minimum bending radius of large cables.

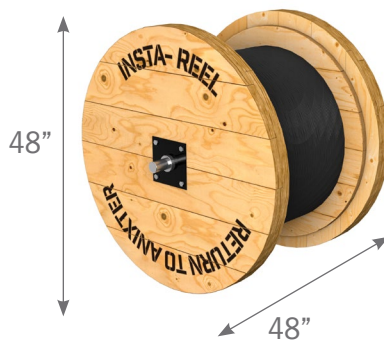

14RR-INSTA-48-48W

Approx. Empty Weight – 412 lbs

Our 48" high by 48" wide reel is designed to handle many types of cables, including medium-voltage, tray, control, instrumentation, fiber and telecommunication exchange cables as well as building wire. It has a large drum to allow for large minimum bending radiuses.

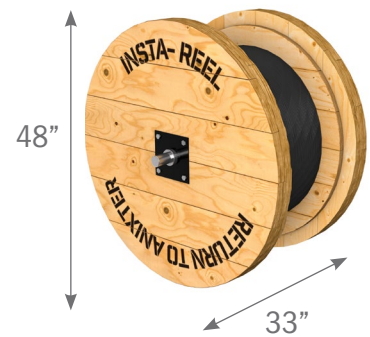

14RR-INSTA-48-33W

Approx. Empty Weight – 370 lbs

The 48" high by 33" wide reel allows for maneuvering through standard 36-inch doorways. It is targeted for indoor use on cables such as building wire and control and instrumentation cables.

				INSTA-REEL 14RR-INSTA-48-33W 33-Inch Width 42 X 17 X 16		INSTA-REEL 14RR-INSTA-48-48W 48-Inch Wide 42 X 28 X 22		INSTA-REEL 14RR-INSTA-70-60W 60-Inch Width 64 X 36 X 35	
Teck 1kV 7TK	AWG	Ground Size	CABLE OD (in.)	Feet	Meters	Feet	Meters	Feet	Meters
2/0		6	1.729	-		-		1,664	508
3/0		4	1.835	-		-		1,478	451
4/0		4	1.925	-		-		1,343	410
250		4	2.250	-		-		983	300
300		4	2.367	-		-		888	271
350		3	2.462	-		-		821	250
RW90 6CL	AWG	STRANDS	CABLE OD (in.)						
				81,303	24,797	101,715	31,023	-	-
12		1	0.14	70,103	21,381	87,704	26,750	-	-
10		1	0.16	53,672	16,370	67,148	20,480	-	-
14		7	0.13	81,303	24,797	101,715	31,023	-	-
12		7	0.15	61,067	18,625	76,400	23,302	-	-
10		7	0.18	42,408	12,934	53,055	16,182	-	-
8		7	0.23	25,974	7,922	32,495	9,911	-	-
6		7	0.27	18,848	5,749	23,580	7,192	-	-
4		7	0.32	13,418	4,092	16,787	5,120	-	-
3		7	0.34	11,886	3,625	14,870	4,535	-	-
2		7	0.37	10,037	3,061	12,557	3,830	-	-
1		19	0.43	7,431	2,266	9,297	2,836	-	-
1/0		19	0.47	6,220	1,897	7,782	2,374	-	-
2/0		19	0.51	5,283	1,611	6,609	2,016	-	-
3/0		19	0.56	4,381	1,336	5,481	1,672	-	-
4/0		19	0.61	3,693	1,126	4,620	1,409	-	-
250		37	0.68	2,971	906	3,718	1,134	-	-
300		37	0.74	2,509	765	3,139	957	-	-
350		37	0.78	2,258	689	2,825	862	-	-
400		37	0.84	1,947	594	2,436	743	-	-
500		37	0.92	1,623	495	2,031	619	-	-
600		61	1.02	1,321	403	1,652	504	-	-
750		61	1.13	1,076	328	1,346	411	-	-
1000		61	1.28	839	256	1,049	320	-	-

For more information, please contact your Anixter sales representative or visit anixter.com.

About Anixter: anixter.com/aboutus
Legal Statement: anixter.com/legalstatement

16D7189 © 2018 Anixter Inc. · 2/18

Anixter Inc. World Headquarters
 2301 Patriot Boulevard
 Glenview, Illinois 60026
 224.521.8000

Toronto Regional Distribution Center
 200 Foster Crescent
 Mississauga, Ontario L5R 3Y5
 905.568.8999

1.877.ANIXTER | anixter.ca



Products. Technology. Services. Delivered Globally.